


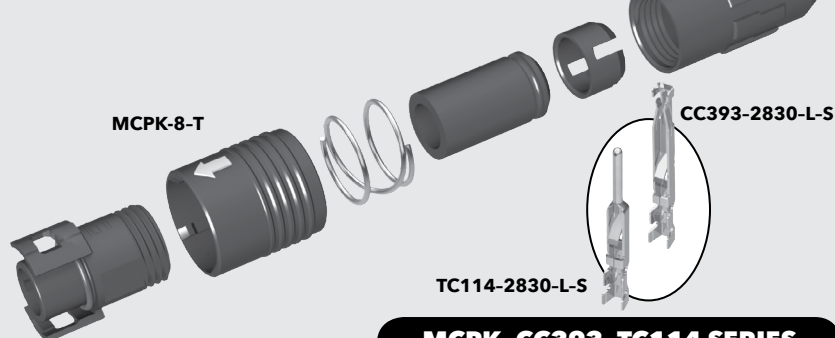

MCPK, CC393, TC114 SERIES

8 SERIES IP67 FIELD TERMINATION KIT

Mates with:
MCR(K), MCP(K)

SPECIFICATIONS

For complete specifications
see www.samtec.com?MCPK

Insulator Material:
PPS

Terminal Material:
Phosphor Bronze

Contact Material:
Phosphor Bronze

Operating Temp Range:
-20 °C to +80 °C

Gasket Material:
Silicone

Spring Material:
Stainless Steel

Coupling Ring Spacer:
PBT

Cable Clamp:
POM

RoHS Compliant:
Yes

DUST CAPS

- -S (Socket) = DCA-MCR-8
- -T (Terminal) = DCA-MCP-8

Visit sealedio.samtec.com for a
complete list of sealed systems

Note: Samtec's MCPK Series
is dual sourced by Hirose
Electric Co., LTD.


MCPK

8


GENDER

- T = Terminal (12 positions)

- S = Socket (12 positions)

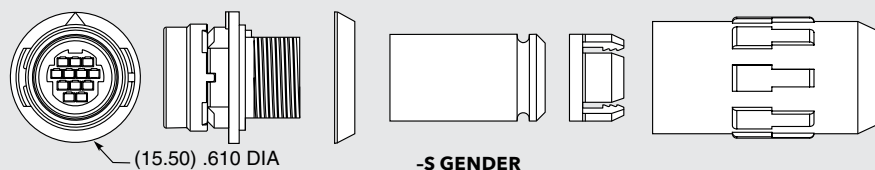

-S GENDER

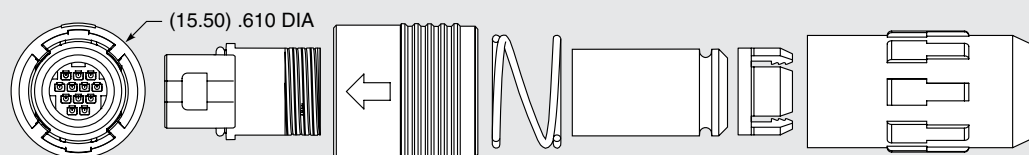

-T GENDER

SPECIFICATIONS

For complete specifications
see www.samtec.com?CC393
or www.samtec.com?TC114

Plating:
10 μ" (0.25 μm) Gold on contact

TOOLING

- Hand Tool:
CAT-HT-393-2430-13
- Mini Applicator
(28-30 AWG):
CAT-MC-393-2830-XX-01
- Extraction Tool:
CAT-EX-MCX-8-01

TYPE

LEAD STYLE

L

PACKING
OPTIONCC393
= ContactTC114
= Terminal-2830
= 28 to 30 AWG-S
= Strip


(15 contacts or terminals)

-M
= Mini Reel


(1,000 - 5,000 contacts or terminals)

-R
= Reel

(30,000 contacts or terminals)

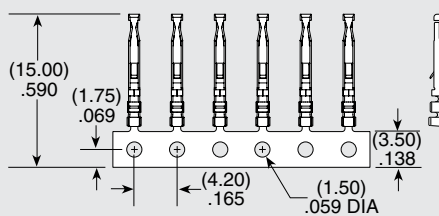

-CC393

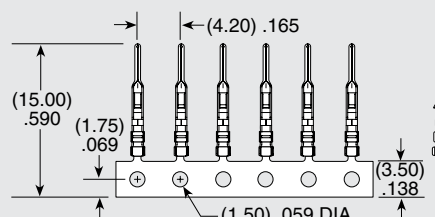

-TC114