




(2.54 mm) .100"

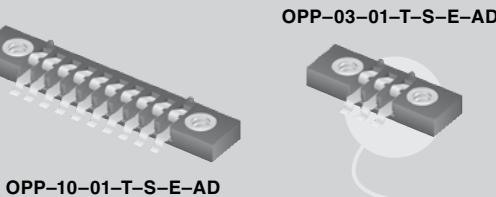

Opp-10-01-T-S-E-AD

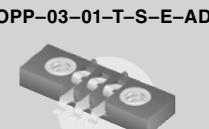

 Opp-03-01-T-S-E-AD



Opp-07-01-T-S-AD

Opp Series

ONE-PIECE POWER INTERFACE

SPECIFICATIONS

For complete specifications and recommended PCB layouts see www.samtec.com?Opp

Insulator Material:

Black Liquid Crystal Polymer

Contact Material:

BeCu

Plating:
Sn over 50 μ " (1.27 μ m) Ni
Operating Temp Range:

-55 °C to +105 °C

Current Rating:

9.6 A per pin

(1 pin powered)

Voltage Rating:

280 VAC/396 VDC

RoHS Compliant:

Yes

Processing:
Lead-Free Solderable:

Yes

SMT Lead Coplanarity:

(0.15 mm) .006" max

RECOGNITIONS



 



For complete scope of recognitions see www.samtec.com/quality



FILE NO. E111594

ALSO AVAILABLE (MOQ Required)

- Alternative alignment pin available
- Contact Samtec.

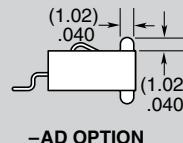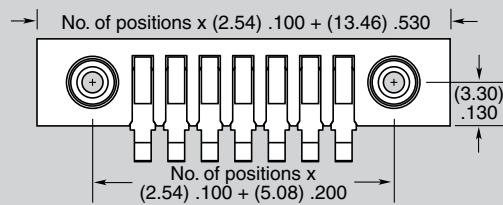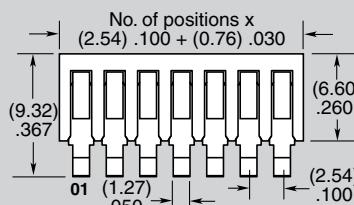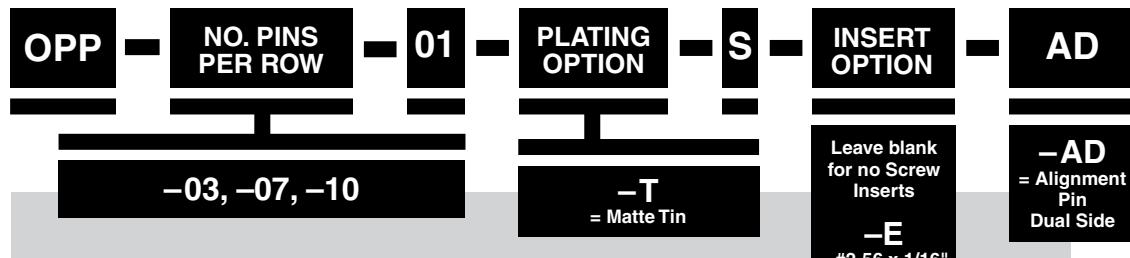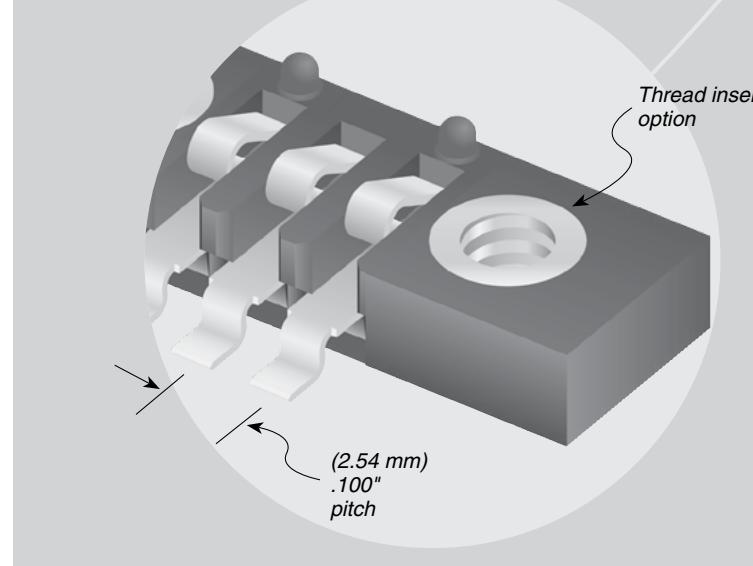

Note: Some sizes, styles and options are non-standard, non-returnable.