


ACCLIMATE™

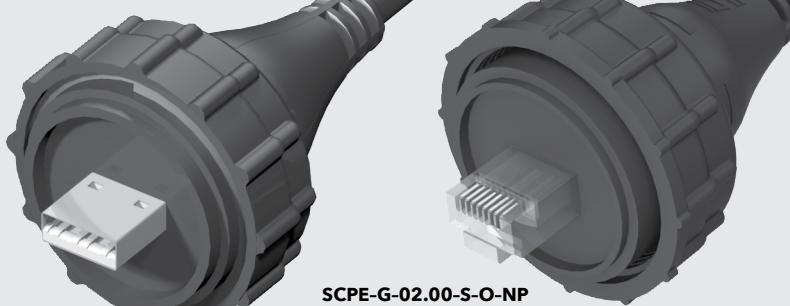

SCPU-17-G-02.00-AMS-AM

SCPE, SCPU, SCPFE SERIES

# IP68 SEALED USB & ETHERNET PLUGS

**Mates with:**  
SCRES

## SPECIFICATIONS

For complete specifications see [www.samtec.com?SCPE](http://www.samtec.com?SCPE)

**Insulator Material:**  
Polycarbonate

**Contact Material:**  
Phosphor Bronze

**Shield Material:**  
Phosphor Bronze

**Wire:**  
24 AWG

**Overmold:**  
PA66 GF13 FR

**Operating Temp Range:**  
-40 °C to +70 °C

**Current Rating:**  
3.8 A per pin (1 pin powered)  
**RoHS Compliant:**  
Yes

## DUST CAP

- DCA-17-02

## Note:

Some lengths, styles and options are non-standard, non-returnable.

**Mates with:**  
SCRUS

## SPECIFICATIONS

For complete specifications see [www.samtec.com?SCPU](http://www.samtec.com?SCPU)

**Insulator Material:**  
Glass Filled Thermoplastic

**Contact Material:**  
Copper Alloy

**Shield Material:** CRS

**Wire:**  
20 AWG (Power)

25 AWG (Signal)


28 AWG (Drain)

**Sealed Overmold:**  
PA66 GF13 FR

**Operating Temp Range:**  
-20 °C to +75 °C

**RoHS Compliant:**  
Yes

TYPE	PLATING	WIRE LENGTH	END OPTION	O	NP
<b>SCPE</b> = Sealed Circular Ethernet Cable Plug	<b>-G</b> = 50 $\mu$ " (1.27 $\mu$ m) Gold on Contact, Nickel on Shell	<b>-01.00</b> = (1 m) 39" Cable	<b>-D</b> = Double Ended (Both Ends Sealed)	<b>-O</b> = Outdoor Rated	<b>-NP</b> = Cat 5e (No polarization mates with SCRES -C5E)
		<b>-02.00</b> = (2 m) 79" Cable	<b>-S</b> = Single Ended (End No. 1 Sealed)		
		Standard lengths			

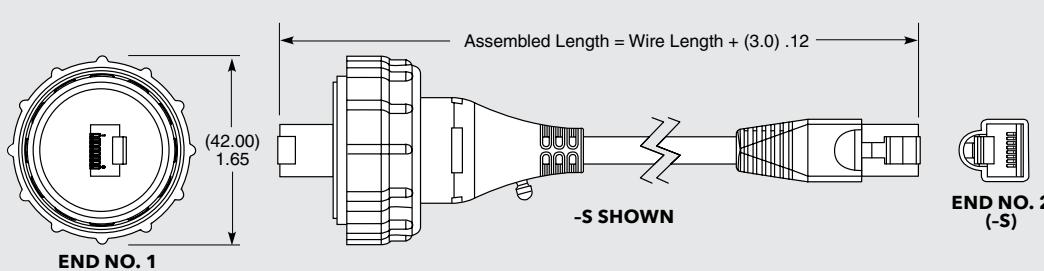


## FIELD TERMINATION KIT

- Ethernet Field Termination Kit available for long cable run and small-opening applications so housings can be customer-installed after the runs are complete.
- SCPFE-17-G-01 Series (For cable outside diameter range of 5.00-5.75 mm)
- SCPFE-17-G-02 Series (For cable outside diameter range of 5.75-6.50 mm)

## ALSO AVAILABLE (CONTACT SAMTEC)

- Other wire lengths

SCPU	SHELL SIZE	PLATING	WIRE LENGTH	END 1 OPTION	END 2 OPTION
	<b>-17</b> (Standard USB only)	<b>-G</b> = 30 $\mu$ " (0.76 $\mu$ m) Gold on Contact, Nickel on Shell	<b>-01.00</b> = (1 m) 40" Cable	<b>-AMS</b> = USB A Type, Sealed	<b>-AM</b> = USB A Type, Not Sealed
			<b>-02.00</b> = (2 m) 79" Cable	<b>-BMS</b> = USB B Type, Sealed	
		Standard lengths	(Assembled Length = Wire Length + (19.5 mm) .77")		

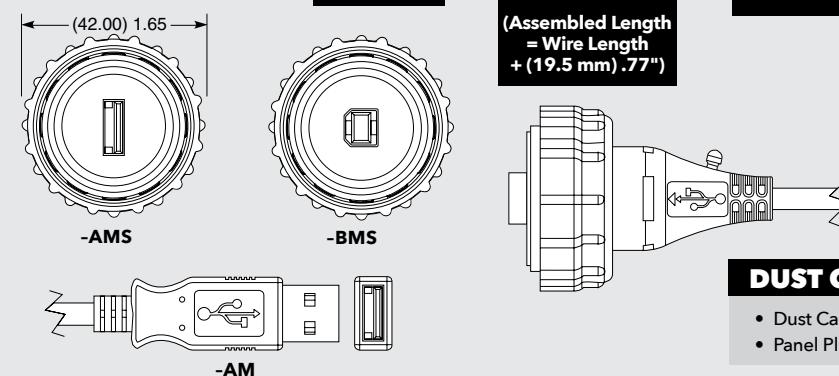

## ALSO AVAILABLE Contact Samtec

- Other wire lengths
- Other end options

## DUST CAPS & PANEL PLUG

- Dust Caps: DCA-17-01 or DCA-10-01
- Panel Plug: SCPPA-17-01

**Note:**  
Some lengths, styles and options are non-standard, non-returnable.