

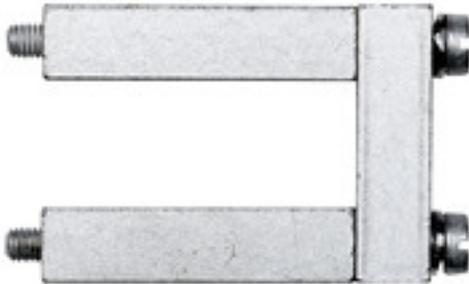
**WQV 70/95/2****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

**Product image****Power feed-in**

Our wide range of W-Series terminal blocks with our WPD main line branch terminals, which are optimised to guarantee both convenience and space gains, ensures a secure and convenient connection at the power feed-in.

**General ordering data**

Version	Cross-connector (terminal), when screwed in, Silver grey, 232 A, Number of poles: 2, Pitch in mm (P): 27.00, Insulated: No, Width: 10 mm
Order No.	<a href="#">1063500000</a>
Type	WQV 70/95/2
GTIN (EAN)	4008 190028329
Qty.	5 pc(s).

## WQV 70/95/2

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

www.weidmueller.com

## Technical data

### Dimensions and weights

Depth	61.6 mm	Depth (inches)	2.425 inch
Height	37 mm	Height (inches)	1.457 inch
Width	10 mm	Width (inches)	0.394 inch
Net weight	101.6 g		

### Temperatures

Storage temperature	-25 °C...55 °C	Ambient temperature	-5 °C...40 °C
---------------------	----------------	---------------------	---------------

### Material data

Material	tinned copper	Colour	Silver grey
----------	---------------	--------	-------------

### System specifications

Version	For the terminals
---------	-------------------

### Additional technical data

Installation advice	Direct mounting	Type of fixing	when screwed in
---------------------	-----------------	----------------	-----------------

### Conductors for clamping (rated connection)

Tightening torque, max.	3 Nm
-------------------------	------

### Cross-connector

Number of cross-connected terminals	2	Rated current, 2-pole	232 A
Rated current, multi-pole	192 A	Type	Cross-connector

### Dimensions

Pitch in mm (P)	27 mm
-----------------	-------

### General

Installation advice	Direct mounting	Number of poles	2
---------------------	-----------------	-----------------	---

### Rating data

Rated current	232 A
---------------	-------

### Classifications

ETIM 6.0	EC000489	ETIM 7.0	EC000489
ETIM 8.0	EC000489	ETIM 9.0	EC000489
ETIM 10.0	EC000489	ECLASS 9.0	27-14-11-40
ECLASS 9.1	27-14-11-40	ECLASS 10.0	27-14-11-40
ECLASS 11.0	27-14-11-40	ECLASS 12.0	27-14-11-40
ECLASS 13.0	27-25-03-03	ECLASS 14.0	27-25-03-03
ECLASS 15.0	27-25-03-03		

## WQV 70/95/2

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

[www.weidmueller.com](http://www.weidmueller.com)

# Technical data

### Environmental Product Compliance

RoHS Compliance Status	Compliant without exemption
REACH SVHC	No SVHC above 0.1 wt%

### Approvals

ROHS	Conform
------	---------

### Downloads

Engineering Data	<a href="#">CAD data – STEP</a>
User Documentation	<a href="#">StorageConditionsTerminalBlocks</a> <a href="#">Instruction</a>
Catalogues	<a href="#">Catalogues in PDF-format</a>
Brochures	