

IE-CDR-V14MSCPOF/VAPM-C**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Delivery incl. dust caps

FreeCon Active PROFINET repeater for PushPull Var. 14
plug-in connectors according to IEC 61076-3-117 and
PushPull Power according to the PROFINET specification

General ordering data

Version	POF repeater, FreeCon, IP65
Order No.	1253240000
Type	IE-CDR-V14MSCPOF/VAPM-C
GTIN (EAN)	4050118045833
Qty.	1 pc(s).
Alternative product	2455360000

IE-CDR-V14MSCPOF/VAPM-C**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data**Dimensions and weights**

Depth	53 mm	Depth (inches)	2.087 inch
Width	100 mm	Width (inches)	3.937 inch
Length	130.4 mm	Length (inches)	5.134 inch
Net weight	725.8 g		

Temperatures

Operating temperature	-20 °C...55 °C
-----------------------	----------------

General data

Data interface	PROFINET PushPull SCRJ POF (V14)	Housing main material	Aluminium profile, Cover: die-cast zinc, painted
Plugging cycles	≥ 100	Power interface	PROFINET PushPull Power
Protection degree	IP65	Type of mounting	None
UL 94 flammability rating	V-0	Wiring	PROFINET

Electrical properties

Baud rate	100 MB	Current consumption	200 mA typical
LED indicator	FO1: port active, FO2: port active, SF: general error, BF: bus error, US1: voltage 1 (electronics), US2: voltage 2	Operating voltage	24 V
Operational voltage range	18...30 V DC	Protocol	PROFINET IRT
Voltage type	DC		

General standards

Certificate no. (cULus)	E141197	Connector standard	IEC 61076-3-117 Var. 14, IEC 61754-24
Network standard	IEC 61158, IEC 61784		

Classifications

ETIM 6.0	EC000732	ETIM 7.0	EC000732
ETIM 8.0	EC000732	ETIM 9.0	EC000732
ETIM 10.0	EC000732	ECLASS 9.0	19-17-02-06
ECLASS 9.1	19-17-01-25	ECLASS 10.0	19-17-02-06
ECLASS 11.0	19-17-02-06	ECLASS 12.0	19-17-02-06
ECLASS 13.0	19-17-02-06	ECLASS 14.0	19-17-02-06
ECLASS 15.0	19-17-02-06		

IE-CDR-V14MSCPOF/VAPM-C

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data

Approvals

Approvals



Approvals MAMID	https://mdcop.weidmueller.com/mediadelivery/rendition/900_319222/-T1z1mm-S800/ https://mdcop.weidmueller.com/mediadelivery/rendition/900_319228/-T1z1mm-S800/
ROHS	Conform
UL File Number Search	UL Website
Certificate no. (cULus)	E141197

Environmental Product Compliance

RoHS Compliance Status	Compliant with exemption
RoHS Exemption (if applicable/known)	6c
REACH SVHC	Lead 7439-92-1
SCIP	67cf1078-beca-4687-860b-dc475a6ec24a

Downloads

Approval/Certificate/Document of Conformity	PNO_Zertifikat_1253240000.pdf
Engineering Data	CAD data – STEP CAD data – DWG CAD data – DXF
Software	Firmware – WM FCA PIR POF 1.05.01 Device description – GSDML 2.25 Weidmuller FCA PIR POF 20110913.zip Runtime Software – CFG configurator - Weidmueller FreeCon 08042011 Installer
User Documentation	Manual EN MAN IE GUIDE DE MAN IE GUIDE EN Firmware update manual Manual DE
Catalogues	Catalogues in PDF-format
Brochures	FL FIELDWIRING EN PI PROFINET CABLING EN PI PROFINET CABLING EN


IE-CDR-V14MSCPOF/VAPM-C

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany


www.weidmueller.com

Drawings

Dimensioned drawing

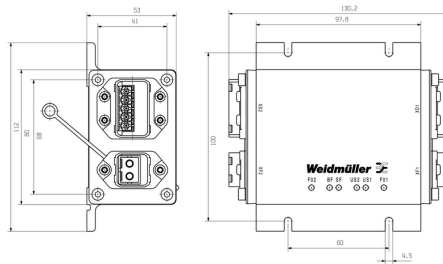

Wiring diagram

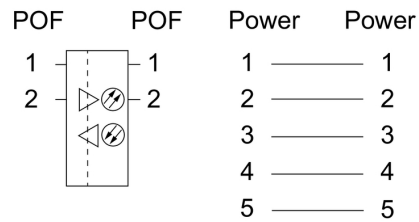

IE-CDR-V14MSCPOF/VAPM-C**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com**Accessories****Sets**

PushPull Power plug-in connector according to PROFINET specification

General ordering data

Type	IE-PS-VAPM-5P-2.5	Version
Order No.	2465440000	Power connector, Plug, PROFINET, Set of connectors
GTIN (EAN)	4050118522136	
Qty.	1 pc(s).	