

IE-CD-VAPM24V-Y-MA**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Y-distributor / connection coupling, FreeCon for plug-in
PushPull Power connector to PROFINET specification,
metal

General ordering data

Version	Y-distributor, FreeCon, Supply, IP65
Order No.	1297010000
Type	IE-CD-VAPM24V-Y-MA
GTIN (EAN)	4050118094589
Qty.	1 pc(s).

IE-CD-VAPM24V-Y-MA**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data**Dimensions and weights**

Net weight	7 16.82 g
------------	-----------

Temperatures

Operating temperature	-40 °C...70 °C
-----------------------	----------------

Classifications

ETIM 7.0	EC002597	ETIM 8.0	EC002597
ETIM 9.0	EC002597	ETIM 10.0	EC002597
ECLASS 9.1	27-44-03-18	ECLASS 10.0	27-44-03-18
ECLASS 11.0	27-44-03-18	ECLASS 12.0	27-44-03-18
ECLASS 13.0	27-44-03-18	ECLASS 14.0	27-44-03-18
ECLASS 15.0	27-44-03-18		

Environmental Product Compliance

RoHS Compliance Status	Compliant with exemption
RoHS Exemption (if applicable/known)	6c
REACH SVHC	Lead 7439-92-1
SCIP	4f3aae94-c2bc-4010-b63b-5b114ba6bd55

Approvals

Approvals



Approvals MAMID	https://mdcop.weidmueller.com/mediadelivery/rendition/900_319228/-T1z1mm-S800/
ROHS	Conform
UL File Number Search	UL Website
Certificate no. (cULus)	E316369

Downloads

Approval/Certificate/Document of Conformity	PROFINET Manufacturer's Declaration
Engineering Data	CAD data – STEP
User Documentation	MAN IE GUIDE DE MAN IE GUIDE EN
Catalogues	Catalogues in PDF-format
Brochures	MB FREECONTACT EN FL FIELDWIRING EN PI PROFINET CABLING EN PI PROFINET CABLING EN


IE-CD-VAPM24V-Y-MA

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com


Drawings

Dimensioned drawing

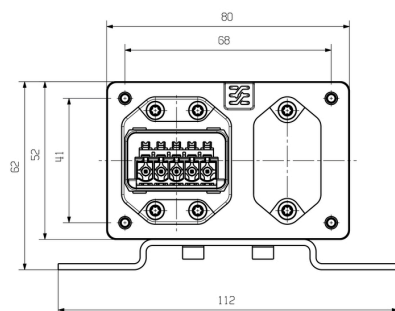

Front view

Dimensioned drawing

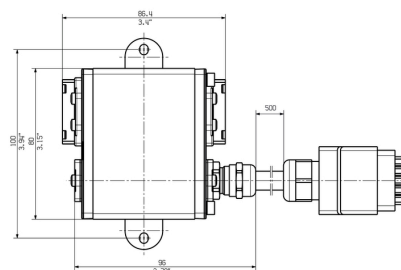

Overhead view