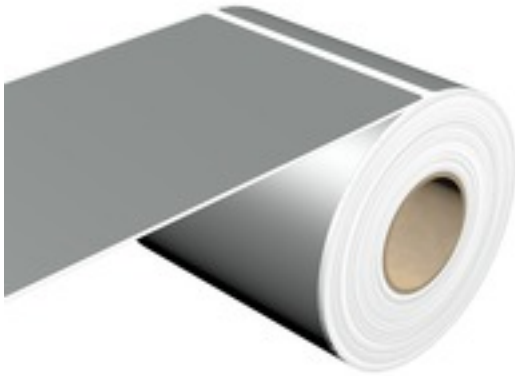


THM FS 101/160 SI**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

The THM labels offer brilliant printing quality thanks to the thermal transfer technology. Different materials and the user-friendly printing system under Windows optimise every marking effort.

- High-quality polyester labels in various colours or inexpensive paper labels are available
- Labels are automatically positioned in the printer for perfectly centred prints on each label.

General ordering data

Version	THM, Device markers, 160 x 101 mm, silver
Order No.	1378090000
Type	THM FS 101/160 SI
GTIN (EAN)	4050118179637
Qty.	1 pc(s).
compatible printer	2599430000 2599440000

THM FS 101/160 SI

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data

Dimensions and weights

Depth	0.08 mm	Depth (inches)	0.003 inch
Height	160 mm	Height (inches)	6.299 inch
Width	101 mm	Width (inches)	3.976 inch
Net weight	804 g		

Temperatures

Operating temperature range	-40...150 °C
-----------------------------	--------------

General data

Adhesive	Acrylate adhesive	
Approval acc. to UL 969	Yes	
Colour	silver	
Halogen	Yes	
Material	Polyester	
Number of markers per combination	1 Label reel = Device markers	
Number of markers per packaging unit	Form of supply	Label reel
Number per roll	250	
Operating temperature range	-40...150 °C	
Operating temperature range, max.	150 °C	
Operating temperature range, min.	-40 °C	
Printed characters	without	
Printing method	Thermal transfer	
UL 94 flammability rating	V-0	
Version	Self-adhesive	
Width	101 mm	

Device markers

Halogen	Yes
---------	-----

Classifications

ETIM 6.0	EC001288	ETIM 7.0	EC001288
ETIM 8.0	EC001288	ETIM 9.0	EC001288
ETIM 10.0	EC001288	ECLASS 9.0	27-40-06-29
ECLASS 9.1	27-40-06-29	ECLASS 10.0	27-40-06-29
ECLASS 11.0	27-28-11-04	ECLASS 12.0	27-28-11-04
ECLASS 13.0	27-28-11-04	ECLASS 14.0	27-28-11-04
ECLASS 15.0	27-28-11-04		

Approvals

ROHS	Conform
------	---------

Environmental Product Compliance

RoHS Compliance Status	Compliant without exemption
REACH SVHC	No SVHC above 0.1 wt%

THM FS 101/160 SI

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data

Downloads

Engineering Data

[CAD data – STEP](#)

[CAD data – DWG](#)

[CAD data – DXF](#)

Catalogues


[Catalogues in PDF-format](#)

THM FS 101/160 SI

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

Drawings

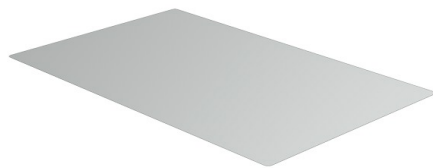

THM FS 101/160 SI**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com**Accessories****Ink ribbons**

These printers produce excellent printing results thanks to the thermal transfer technique. Different materials and the user-friendly printing system under Windows optimise marking efforts.

General ordering data

Type	RIBBON MM 110/360 SW	Version
Order No.	2005070000	Ink ribbon
GTIN (EAN)	4050118390049	
Qty.	1 pc(s).	