


WTA 8 TN-KO/ZA**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

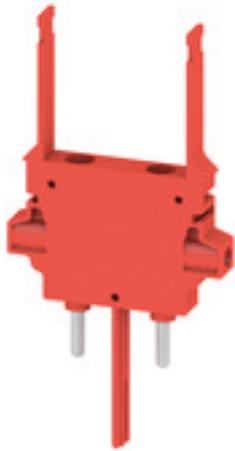

Test adapters and test plugs are used for the electrical connection between terminal blocks and the test equipment. In this way, an electrical contact can be established in the wired state and measurements can be done easily.

General ordering data

Version	Test adapter (terminal), 1.5 mm ² , 205 V, 6 A
Order No.	1915520000
Type	WTA 8 TN-KO/ZA
GTIN (EAN)	4032248548095
Qty.	25 pc(s).

WTA 8 TN-KO/ZA

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data

Dimensions and weights

Depth	71 mm	Depth (inches)	2.795 inch
Height	39 mm	Height (inches)	1.535 inch
Width	6 mm	Width (inches)	0.236 inch
Net weight	9.48 g		

Temperatures

Storage temperature	-25 °C...55 °C	Ambient temperature	-5 °C...40 °C
Continuous operating temp., min.	-50 °C	Continuous operating temp., max.	100 °C

Material data

Material	Wemid	Colour	red
UL 94 flammability rating	V-2		

Additional technical data

Installation advice	Direct mounting	With snap-in pegs	Yes
---------------------	-----------------	-------------------	-----

Conductors for clamping (rated connection)

Connection cross-section, stranded, max.	2.5 mm ²	Stripping length	7 mm
Type of connection	Screw connection	Wire connection cross section, finely stranded, max.	2.5 mm ²
Wire connection cross section, finely stranded, min.	0.5 mm ²	Wire connection cross-section, solid core, max.	2.5 mm ²
Wire connection cross-section, solid core, min.	0.5 mm ²		

Dimensions

Pitch in mm (P)	6 mm	Height with TS 35	78 mm
-----------------	------	-------------------	-------

General

Installation advice	Direct mounting	Number of poles	1
---------------------	-----------------	-----------------	---

Rating data

Rated cross-section	1.5 mm ²	Rated voltage	205 V
Rated current	6 A	Volume resistance according to IEC 60947-7-x	1.83 mΩ
Power loss in accordance with IEC 60947-7-x	0.56 W		

Classifications

ETIM 6.0	EC002555	ETIM 7.0	EC002555
ETIM 8.0	EC002555	ETIM 9.0	EC002555
ETIM 10.0	EC002555	ECLASS 9.0	27-14-11-48
ECLASS 9.1	27-14-11-48	ECLASS 10.0	27-14-11-48
ECLASS 11.0	27-14-11-48	ECLASS 12.0	27-14-11-48
ECLASS 13.0	27-25-03-04	ECLASS 14.0	27-25-03-04
ECLASS 15.0	27-25-03-04		

Creation date July 12, 2025 4:03:55 AM CEST

Catalogue status 04.07.2025 / We reserve the right to make technical changes.

Data sheet**WTA 8 TN-KO/ZA**

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

Technical data**Approvals**

ROHS	Conform
------	---------

Environmental Product Compliance

RoHS Compliance Status	Compliant with exemption
RoHS Exemption (if applicable/known)	6c
REACH SVHC	Lead 7439-92-1
SCIP	e1c310ef-6b67-4efa-80a6-d307472f4de9

Downloads

Engineering Data	CAD data – STEP
User Documentation	StorageConditionsTerminalBlocks
Catalogues	Catalogues in PDF-format