

IE-BS-V01M-RJ45-C**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Bayonet plug-in connector sets according to IEC
61076-3-106 ver.1 (Ethernet/IP), RJ45 metal insert incl.
RJ45 insert

General ordering data

Version	Flange RJ45, IP67, Variant 1 metal, RJ45 / RJ45 coupling, Cat.6A / Class EA (ISO/IEC 11801 2010)
Order No.	1963470000
Type	IE-BS-V01M-RJ45-C
GTIN (EAN)	4032248645565
Qty.	10 pc(s).

IE-BS-V01M-RJ45-C**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data**Dimensions and weights**

Height	32 mm	Height (inches)	1.26 inch
Width	32 mm	Width (inches)	1.26 inch
Net weight	72.8 g		

Temperatures

Operating temperature	-40 °C...70 °C
-----------------------	----------------

General data

Connection 1	RJ45	Connection 2	RJ45
Description of article	Variant 1 metal, RJ45 / RJ45 coupling	Seal material	EPDM
Colour	Miscellaneous	Housing main material	Zinc diecast
Category	Cat.6A / Class EA (ISO/ IEC 11801 2010)	Contact surface	Gold over nickel
Shielding	360°; all-round enclosure	Protection degree	IP67
Plugging cycles	750		

Electrical properties

Dielectric strength, contact / contact	≥ 1000 V AC/DC	Dielectric strength, contact / shield	≥ 1500 V AC/DC
--	----------------	---------------------------------------	----------------

General standards

Certificate no. (cULus)	E316369	Connector standard	IEC 61076-3-106 Var. 1, IEC 60603-7-51
-------------------------	---------	--------------------	--

Classifications

ETIM 6.0	EC001121	ETIM 7.0	EC001121
ETIM 8.0	EC001121	ETIM 9.0	EC001121
ETIM 10.0	EC001121	ECLASS 9.0	27-44-03-90
ECLASS 9.1	27-44-03-90	ECLASS 10.0	27-44-03-90
ECLASS 11.0	27-44-03-90	ECLASS 12.0	27-44-03-90
ECLASS 13.0	27-44-03-90	ECLASS 14.0	27-44-03-90
ECLASS 15.0	27-44-03-90		

Environmental Product Compliance

RoHS Compliance Status	Compliant with exemption
RoHS Exemption (if applicable/known)	6c
REACH SVHC	Lead 7439-92-1 6,6'-di-tert-butyl-2,2'-methylenedi-p-cresol 119-47-1
SCIP	c1a8d9e9-fd0c-4258-8c31-7317a7b4ce18

IE-BS-V01M-RJ45-C

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data

Approvals

Approvals



Approvals MAMID	https://mdcop.weidmueller.com/mediadelivery/rendition/900_319228/-T1z1mm-S800/
ROHS	Conform
UL File Number Search	UL Website
Certificate no. (cULus)	E316369

Downloads

Approval/Certificate/Document of Conformity	ISO/IEC and TIA/EIA DE ISO/IEC EN and TIA/EIA Screened Class E Category 6, 3 connector permanent link ISO/IEC EN and TIA/EIA Screened Class E Category 6, 4 connector channel ISO/IEC EN and TIA/EIA Screened Class EA Category 6A, 2 connector channel DUXR.E316369
Engineering Data	CAD data – STEP
Product Change Notification	Technical change to Bulkhead Variant 1 (Metal) - EN Technical change to Bulkhead Variant 1 (Metal) - DE 20190724 Technische Änderung zu Flansch Variante 1 (Metall) 20190724 Technische Änderung zu Flansch Variante 1 (Metall) 20190724 Technical change to Bulkhead Variant 1 (Metal)
User Documentation	MAN IE GUIDE DE MAN IE GUIDE EN Designation key / Type key Manual
Catalogues	Catalogues in PDF-format
Brochures	MB FREECONTACT EN FL FIELDWIRING EN PI PROFINET CABLING EN PI PROFINET CABLING EN


IE-BS-V01M-RJ45-C

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com


Drawings

Installation cut-out

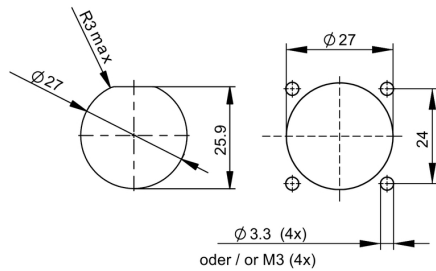

Mounting cut-out: 1. With central screw connection / 2. For mounting with four M3 screws

Detailed drawing

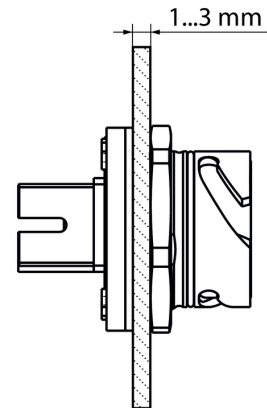

Wall thickness when using the central screw connection

IE-BS-V01M-RJ45-C**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com**Accessories****Dust caps**

For protecting your devices against dust and dirt.

General ordering data

Type	IE-BP-V01P	Version
Order No.	1965700000	Flange-mounted housing, protective cap
GTIN (EAN)	4032248653928	
Qty.	10 pc(s).	