

IE-OM-V01M-K11-1S**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com



Junction box, design for bayonet plug-in connectors ver.1
according to IEC 61076-3-106, metal

General ordering data

Version	Junction box, IP67, Variant 1, 1 port, straight
Order No.	1966300000
Type	IE-OM-V01M-K11-1S
GTIN (EAN)	4032248658497
Qty.	1 pc(s).

Creation date July 14, 2025 9:29:55 PM CEST

Catalogue status 04.07.2025 / We reserve the right to make technical changes.

IE-OM-V01M-K11-1S

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data

Dimensions and weights

Depth	57 mm	Depth (inches)	2.244 inch
Width	75 mm	Width (inches)	2.953 inch
Length	140 mm	Length (inches)	5.512 inch
Net weight	460 g		

Temperatures

Operating temperature	-40 °C...70 °C
-----------------------	----------------

General data

Colour	grey	Housing main material	AL-Si 12
Plugging cycles	750	Protection degree	IP67
Type of mounting	Floor-mounted, Wall mounting		

General standards

Connector standard	IEC 61076-3-106 Var. 1
--------------------	------------------------

Classifications

ETIM 7.0	EC002597	ETIM 8.0	EC002597
ETIM 9.0	EC002597	ETIM 10.0	EC002597
ECLASS 9.1	27-44-03-18	ECLASS 10.0	27-44-03-18
ECLASS 11.0	27-44-03-18	ECLASS 12.0	27-44-03-18
ECLASS 13.0	27-44-03-18	ECLASS 14.0	27-44-03-18
ECLASS 15.0	27-44-03-18		

Approvals

ROHS	Conform
------	---------

Environmental Product Compliance

RoHS Compliance Status	Compliant with exemption
RoHS Exemption (if applicable/known)	6bl, 6c
REACH SVHC	Lead 7439-92-1 6,6'-di-tert-butyl-2,2'-methylenedi-p-cresol 119-47-1
SCIP	e3782e8e-7b94-417d-a6f7-ac548c86df93

Downloads

Engineering Data	CAD data – STEP
User Documentation	MAN IE GUIDE DE MAN IE GUIDE EN
Catalogues	Catalogues in PDF-format
Brochures	MB FREECONTACT EN FL FIELDWIRING EN PI PROFINET CABLING EN PI PROFINET CABLING EN


IE-OM-V01M-K11-1S

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany


www.weidmueller.com

Drawings

Dimensioned drawing

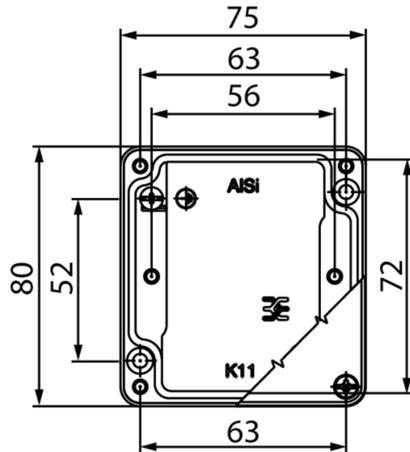

Drawing

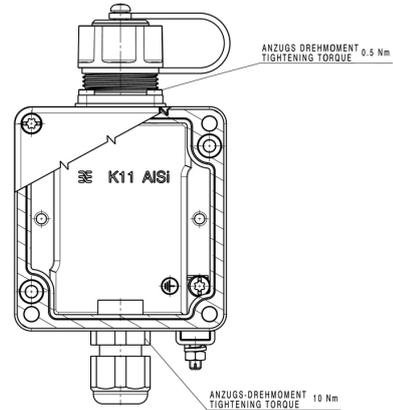

IE-OM-V01M-K11-1S

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Accessories

Sets - RJ45

Bayonet plug-in connector sets according to IEC 61076-3-106 ver.1 (EtherNet/IP), RJ45 metal insert incl. RJ45 insert



General ordering data

Type	IE-PS-V01M-RJ45-FH	Version
Order No.	1963120000	RJ45 plug, no tools required, Variant 1 metal, Cat.6A / Class EA (ISO/
GTIN (EAN)	4032248651627	IEC 11801 2010)
Qty.	10 pc(s).	

RJ45

RJ45 inserts for plug-in connectors ver.1 / 4 / 5 / 14, HDC and junction boxes IE-OM...; IE-OP...; IE-CC...



General ordering data

Type	IE-BI-RJ45-FJ-A	Version
Order No.	1962850000	RJ45 insert socket, Connector for base, TIA-568A
GTIN (EAN)	4032248645053	
Qty.	10 pc(s).	
Type	IE-BI-RJ45-FJ-P	Version
Order No.	1963830000	RJ45 insert socket, Connector for base, PROFINET
GTIN (EAN)	4032248646159	
Qty.	10 pc(s).	
Type	IE-BI-RJ45-FJ-B	Version
Order No.	1963840000	RJ45 insert socket, Connector for base, TIA-568B
GTIN (EAN)	4032248651894	
Qty.	10 pc(s).	