

ES EPG/HPG 60 WM 25

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

Similar to illustration**Crimping tools for cable lugs, connectors and wire-end ferrules with interchangeable inserts**

- extremely fast processing thanks to hydraulic support
- large processing range up to 300 mm²
- 270° revolving quick-action crimping head
- automatic pressure limitation and monitoring via pressure sensor
- electronic control and monitoring of the crimping process
- Saving of all crimping cycles and error messages to internal memory
- Reading of all cycles and error messages via USB
- Li-ion rechargeable battery with charge status indicator: 18 V, 2 Ah

General ordering data

Version	Crimping tool insert, 25mm ² , WM crimp
Order No.	2469560000
Type	ES EPG/HPG 60 WM 25
GTIN (EAN)	4050118483840
Qty.	1 pc(s).

ES EPG/HPG 60 WM 25

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data

Dimensions and weights

Depth	22 mm	Depth (inches)	0.866 inch
Height	42 mm	Height (inches)	1.654 inch
Width	42 mm	Width (inches)	1.654 inch
Net weight	167 g		

Crimp inserts

Crimp cross-section copper	25	Crimping width	12 mm
Crimping width in mm	12		

Description of contact

Conductor cross-section, max. AWG	4	Conductor cross-section, min. AWG	4
Crimping range, max.	25 mm ²	Type of contact	Euro series cable lug

tool data crimping

Cable lug cross section	nominal	25 mm ²
Crimping type/profile	WM crimp	

Classifications

ETIM 6.0	EC001282	ETIM 7.0	EC001282
ETIM 8.0	EC001282	ETIM 9.0	EC001282
ETIM 10.0	EC001282	ECLASS 9.0	21-04-90-90
ECLASS 9.1	21-01-90-90	ECLASS 10.0	21-04-90-90
ECLASS 11.0	21-04-90-90	ECLASS 12.0	21-04-90-90
ECLASS 13.0	21-04-90-90	ECLASS 14.0	21-04-90-90
ECLASS 15.0	21-04-90-90		

Environmental Product Compliance

RoHS Compliance Status	Compliant without exemption
REACH SVHC	No SVHC above 0.1 wt%

Downloads

Catalogues	Catalogues in PDF-format
------------	--

ES EPG/HPG 60 WM 25

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Accessories

25 mm²

The use of insulated connectors guarantees users consistent electrical connection quality in the long term.

- Wide range of insulated and non-insulated cable lugs and connectors
- Tubular cable lugs according to current market standards (Euroseries)
- Compression cable lugs acc. to DIN 46235
- Sheet metal cable lugs acc. to DIN 46234
- Insulated ring cable lugs to DIN 46237
- Insulated pin cable lugs to DIN 46231

General ordering data

Type	KQN-M8/-25	Version	
Order No.	1494140000		cable lug, terminal end,25 mm ²
GTIN (EAN)	4050118303872		
Qty.	50 pc(s).		
Type	KQN-M5/-25	Version	
Order No.	1494120000		cable lug, terminal end,25 mm ²
GTIN (EAN)	4050118303827		
Qty.	50 pc(s).		
Type	KQN-M16/-25	Version	
Order No.	1493490000		cable lug, terminal end,25 mm ²
GTIN (EAN)	4050118303148		
Qty.	50 pc(s).		
Type	KQN-M10/-25	Version	
Order No.	1494150000		cable lug, terminal end,25 mm ²
GTIN (EAN)	4050118303865		
Qty.	50 pc(s).		
Type	KQN-M12/-25	Version	
Order No.	1494160000		cable lug, terminal end,25 mm ²
GTIN (EAN)	4050118303902		
Qty.	50 pc(s).		
Type	KQN-M6/-25	Version	
Order No.	1494130000		cable lug, terminal end,25 mm ²
GTIN (EAN)	4050118303858		
Qty.	50 pc(s).		


ES EPG/HPG 60 WM 25

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Accessories

25 mm²

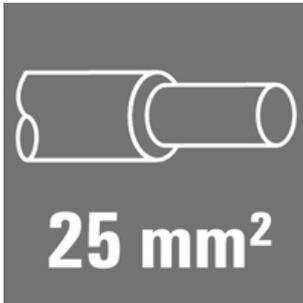

The use of insulated connectors guarantees users consistent electrical connection quality in the long term.

- Wide range of insulated and non-insulated cable lugs and connectors
- Tubular cable lugs according to current market standards (Euroseries)
- Compression cable lugs acc. to DIN 46235
- Sheet metal cable lugs acc. to DIN 46234
- Insulated ring cable lugs to DIN 46237
- Insulated pin cable lugs to DIN 46231

General ordering data

Type	VPLN/-25	Version	
Order No.	1492910000	cable lug, terminal end,25 mm ² ,25 mm ² ,None	
GTIN (EAN)	4050118302646		
Qty.	100 pc(s).		

25 mm²



The use of insulated connectors guarantees users consistent electrical connection quality in the long term.

- Wide range of insulated and non-insulated cable lugs and connectors
- Tubular cable lugs according to current market standards (Euroseries)
- Compression cable lugs acc. to DIN 46235
- Sheet metal cable lugs acc. to DIN 46234
- Insulated ring cable lugs to DIN 46237
- Insulated pin cable lugs to DIN 46231

General ordering data


Type	KWPN-M6/-25 90	Version	
Order No.	1497490000	cable lug, terminal end,25 mm ²	
GTIN (EAN)	4050118306668		
Qty.	100 pc(s).		
Type	KWPN-M10/-25 90	Version	
Order No.	1497520000	cable lug, terminal end,25 mm ²	
GTIN (EAN)	4050118306989		
Qty.	100 pc(s).		
Type	KWPN-M8/-25 90	Version	
Order No.	1497510000	cable lug, terminal end,25 mm ²	
GTIN (EAN)	4050118306972		
Qty.	100 pc(s).		
Type	KWPN-M12/-25 90	Version	
Order No.	1497530000	cable lug, terminal end,25 mm ²	
GTIN (EAN)	4050118307108		
Qty.	100 pc(s).		

ES EPG/HPG 60 WM 25

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Accessories

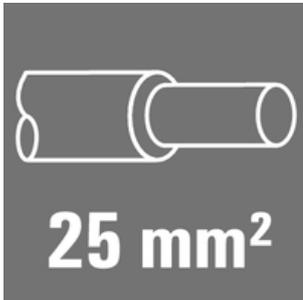25 mm²

The use of insulated connectors guarantees users consistent electrical connection quality in the long term.

- Wide range of insulated and non-insulated cable lugs and connectors
- Tubular cable lugs according to current market standards (Euroseries)
- Compression cable lugs acc. to DIN 46235
- Sheet metal cable lugs acc. to DIN 46234
- Insulated ring cable lugs to DIN 46237
- Insulated pin cable lugs to DIN 46231

General ordering data

Type	KWN-M6/-25 45	Version	
Order No.	1496180000	cable lug, terminal end,25 mm ² ,25 mm ² - 25 mm ²	
GTIN (EAN)	4050118305876		
Qty.	100 pc(s).		
Type	KWN-M8/-25 45	Version	
Order No.	1496190000	cable lug, terminal end,25 mm ² ,25 mm ² - 25 mm ²	
GTIN (EAN)	4050118306231		
Qty.	100 pc(s).		
Type	KWN-M10/-25 45	Version	
Order No.	1496200000	cable lug, terminal end,25 mm ² ,25 mm ² - 25 mm ²	
GTIN (EAN)	4050118305593		
Qty.	100 pc(s).		
Type	KWN-M12/-25 45	Version	
Order No.	1496210000	cable lug, terminal end,25 mm ² ,25 mm ² - 25 mm ²	
GTIN (EAN)	4050118305715		
Qty.	100 pc(s).		

25 mm²

The use of insulated connectors guarantees users consistent electrical connection quality in the long term.

- Wide range of insulated and non-insulated cable lugs and connectors
- Tubular cable lugs according to current market standards (Euroseries)
- Compression cable lugs acc. to DIN 46235
- Sheet metal cable lugs acc. to DIN 46234
- Insulated ring cable lugs to DIN 46237
- Insulated pin cable lugs to DIN 46231

General ordering data

Type	KP-M6/-25	Version	
Order No.	1497970000	cable lug, terminal end,25 mm ²	
GTIN (EAN)	4050118307412		
Qty.	100 pc(s).		

ES EPG/HPG 60 WM 25


Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Accessories

Type	KP-M10/-25	Version	
Order No.	1497990000		cable lug, terminal end,25 mm ²
GTIN (EAN)	4050118307535		
Qty.	100 pc(s).		
Type	KP-M8/-25	Version	
Order No.	1497980000		cable lug, terminal end,25 mm ²
GTIN (EAN)	4050118307528		
Qty.	100 pc(s).		
Type	KP-M12/-25	Version	
Order No.	1498000000		cable lug, terminal end,25 mm ²
GTIN (EAN)	4050118307504		
Qty.	100 pc(s).		
Type	KP-M16/-25	Version	
Order No.	1498010000		cable lug, terminal end,25 mm ²
GTIN (EAN)	4050118307443		
Qty.	100 pc(s).		

25 mm²

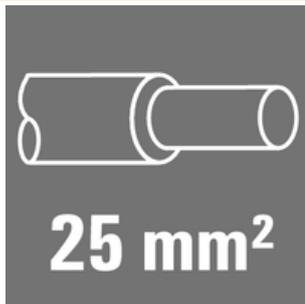

The use of insulated connectors guarantees users consistent electrical connection quality in the long term.

- Wide range of insulated and non-insulated cable lugs and connectors
- Tubular cable lugs according to current market standards (Euroseries)
- Compression cable lugs acc. to DIN 46235
- Sheet metal cable lugs acc. to DIN 46234
- Insulated ring cable lugs to DIN 46237
- Insulated pin cable lugs to DIN 46231

General ordering data

Type	VSTN/-25	Version	
Order No.	1494730000		cable lug, terminal end,25 mm ² ,25 mm ² ,None
GTIN (EAN)	4050118304275		
Qty.	50 pc(s).		

ES EPG/HPG 60 WM 25

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Accessories

25 mm²

The use of insulated connectors guarantees users consistent electrical connection quality in the long term.

- Wide range of insulated and non-insulated cable lugs and connectors
- Tubular cable lugs according to current market standards (Euroseries)
- Compression cable lugs acc. to DIN 46235
- Sheet metal cable lugs acc. to DIN 46234
- Insulated ring cable lugs to DIN 46237
- Insulated pin cable lugs to DIN 46231

General ordering data

Type	KRN-M6/-25	Version
Order No.	1496490000	cable lug, terminal end,25 mm ² ,25 mm ² - 25 mm ²
GTIN (EAN)	4050118305784	
Qty.	100 pc(s).	
Type	KRN-M8/-25	Version
Order No.	1496500000	cable lug, terminal end,25 mm ² ,25 mm ² - 25 mm ²
GTIN (EAN)	4050118305975	
Qty.	100 pc(s).	
Type	KRN-M14/-25	Version
Order No.	1496530000	cable lug, terminal end,25 mm ² ,25 mm ² - 25 mm ²
GTIN (EAN)	4050118305883	
Qty.	100 pc(s).	
Type	KRN-M5/-25	Version
Order No.	1495830000	cable lug, terminal end,25 mm ² ,25 mm ² - 25 mm ²
GTIN (EAN)	4050118305562	
Qty.	100 pc(s).	
Type	KRN-M10/-25	Version
Order No.	1496510000	cable lug, terminal end,25 mm ² ,25 mm ² - 25 mm ²
GTIN (EAN)	4050118305814	
Qty.	100 pc(s).	
Type	KRN-M12/-25	Version
Order No.	1496520000	cable lug, terminal end,25 mm ² ,25 mm ² - 25 mm ²
GTIN (EAN)	4050118306163	
Qty.	100 pc(s).	

ES EPG/HPG 60 WM 25

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Accessories

Tools



Crimping tools for cable lugs, connectors and wire-end ferrules with interchangeable inserts

- extremely fast processing thanks to hydraulic support
- large processing range up to 300 mm²
- 270° revolving quick-action crimping head
- automatic pressure limitation and monitoring via pressure sensor
- electronic control and monitoring of the crimping process
- Saving of all crimping cycles and error messages to internal memory
- Reading of all cycles and error messages via USB
- Li-ion rechargeable battery with charge status indicator: 18 V, 2 Ah

General ordering data

Type	EPG 60	Version
Order No.	2453810000	Pressing tools, Tools, Pressing tool, 6mm ² , 300mm ² , Hexagonal crimp,
GTIN (EAN)	4050118468434	WM crimp, Indent crimp, Trapezoidal crimp, Oval crimping
Qty.	1 pc(s).	

25 mm²



The use of insulated connectors guarantees users consistent electrical connection quality in the long term.

- Wide range of insulated and non-insulated cable lugs and connectors
- Tubular cable lugs according to current market standards (Euroseries)
- Compression cable lugs acc. to DIN 46235
- Sheet metal cable lugs acc. to DIN 46234
- Insulated ring cable lugs to DIN 46237
- Insulated pin cable lugs to DIN 46231

General ordering data

Type	KWN-M6/-25 90	Version
Order No.	1495850000	cable lug, terminal end,25 mm ² ,25 mm ² - 25 mm ²
GTIN (EAN)	4050118305456	
Qty.	100 pc(s).	
Type	KWN-M12/-25 90	Version
Order No.	1495890000	cable lug, terminal end,25 mm ² ,25 mm ² - 25 mm ²
GTIN (EAN)	4050118305647	
Qty.	100 pc(s).	
Type	KWN-M10/-25 90	Version
Order No.	1495880000	cable lug, terminal end,25 mm ² ,25 mm ² - 25 mm ²
GTIN (EAN)	4050118305449	
Qty.	100 pc(s).	
Type	KWN-M8/-25 90	Version
Order No.	1495870000	cable lug, terminal end,25 mm ² ,25 mm ² - 25 mm ²
GTIN (EAN)	4050118305470	
Qty.	100 pc(s).	

Creation date July 14, 2025 3:11:25 AM CEST

Catalogue status 04.07.2025 / We reserve the right to make technical changes.

ES EPG/HPG 60 WM 25

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Accessories

Type	KWN-M14/-25 90	Version	
Order No.	1495900000	Version	cable lug, terminal end, 25 mm ² , 25 mm ² - 25 mm ²
GTIN (EAN)	4050118305517		
Qty.	100 pc(s).		

25 mm²



The use of insulated connectors guarantees users consistent electrical connection quality in the long term.

- Wide range of insulated and non-insulated cable lugs and connectors
- Tubular cable lugs according to current market standards (Euroseries)
- Compression cable lugs acc. to DIN 46235
- Sheet metal cable lugs acc. to DIN 46234
- Insulated ring cable lugs to DIN 46237
- Insulated pin cable lugs to DIN 46231

General ordering data

Type	KSN/-25	Version	
Order No.	1492800000	Version	cable lug, terminal end, 25 mm ² , 25 mm ²
GTIN (EAN)	4050118302592		
Qty.	50 pc(s).		

Tools



Crimping tools for cable lugs, connectors and wire-end ferrules with interchangeable inserts

- extremely fast processing thanks to hydraulic support
- large processing range up to 400 mm²
- 360° revolving quick action crimping head
- automatic pressure limitation and monitoring via pressure sensor
- Additional features for APG series:
- electronic control and monitoring of the crimping process
- Saving of all crimping cycles and error messages to internal memory
- Reading of all cycles and error messages via USB

General ordering data


Type	HPG 60	Version	
Order No.	2453820000	Version	6mm ² , 300mm ² , Hexagonal crimp, WM crimp, Indent crimp,
GTIN (EAN)	4050118468427	Version	Trapezoidal crimp, Oval crimping
Qty.	1 pc(s).		

ES EPG/HPG 60 WM 25

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

Accessories

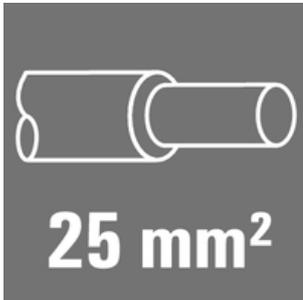25 mm²

The use of insulated connectors guarantees users consistent electrical connection quality in the long term.

- Wide range of insulated and non-insulated cable lugs and connectors
- Tubular cable lugs according to current market standards (Euroseries)
- Compression cable lugs acc. to DIN 46235
- Sheet metal cable lugs acc. to DIN 46234
- Insulated ring cable lugs to DIN 46237
- Insulated pin cable lugs to DIN 46231

General ordering data

Type	VSTN/25	Version	
Order No.	1493050000		cable lug, terminal end,25 mm ² ,25 mm ² ,None
GTIN (EAN)	4050118302783		
Qty.	100 pc(s).		

25 mm²

The use of insulated connectors guarantees users consistent electrical connection quality in the long term.

- Wide range of insulated and non-insulated cable lugs and connectors
- Tubular cable lugs according to current market standards (Euroseries)
- Compression cable lugs acc. to DIN 46235
- Sheet metal cable lugs acc. to DIN 46234
- Insulated ring cable lugs to DIN 46237
- Insulated pin cable lugs to DIN 46231

General ordering data

Type	VPN/-25	Version	
Order No.	1498640000		cable lug, terminal end,25 mm ² ,25 mm ² ,None
GTIN (EAN)	4050118308013		
Qty.	100 pc(s).		