

ES EPG/HPG 60 WM 50

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

Similar to illustration**Crimping tools for cable lugs, connectors and wire-end ferrules with interchangeable inserts**

- extremely fast processing thanks to hydraulic support
- large processing range up to 300 mm²
- 270° revolving quick-action crimping head
- automatic pressure limitation and monitoring via pressure sensor
- electronic control and monitoring of the crimping process
- Saving of all crimping cycles and error messages to internal memory
- Reading of all cycles and error messages via USB
- Li-ion rechargeable battery with charge status indicator: 18 V, 2 Ah

General ordering data

Version	Crimping tool insert, 50mm ² , WM crimp
Order No.	2469580000
Type	ES EPG/HPG 60 WM 50
GTIN (EAN)	4050118483864
Qty.	1 pc(s).

ES EPG/HPG 60 WM 50

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data

Dimensions and weights

Depth	22 mm	Depth (inches)	0.866 inch
Height	42 mm	Height (inches)	1.654 inch
Width	42 mm	Width (inches)	1.654 inch
Net weight	139 g		

Crimp inserts

Crimp cross-section copper	50	Crimping width	5 mm
Crimping width in mm	5		

Description of contact

Conductor cross-section, max. AWG	1	Conductor cross-section, min. AWG	1
Crimping range, max.	50 mm ²	Type of contact	Euro series cable lug

tool data crimping

Cable lug cross section	nominal	50 mm ²
Crimping type/profile	WM crimp	

Classifications

ETIM 6.0	EC001282	ETIM 7.0	EC001282
ETIM 8.0	EC001282	ETIM 9.0	EC001282
ETIM 10.0	EC001282	ECLASS 9.0	21-04-90-90
ECLASS 9.1	21-01-90-90	ECLASS 10.0	21-04-90-90
ECLASS 11.0	21-04-90-90	ECLASS 12.0	21-04-90-90
ECLASS 13.0	21-04-90-90	ECLASS 14.0	21-04-90-90
ECLASS 15.0	21-04-90-90		

Environmental Product Compliance

RoHS Compliance Status	Compliant without exemption
REACH SVHC	No SVHC above 0.1 wt%

Downloads

Catalogues	Catalogues in PDF-format
------------	--

ES EPG/HPG 60 WM 50

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

Accessories

50 mm²

The use of insulated connectors guarantees users consistent electrical connection quality in the long term.

- Wide range of insulated and non-insulated cable lugs and connectors
- Tubular cable lugs according to current market standards (Euroseries)
- Compression cable lugs acc. to DIN 46235
- Sheet metal cable lugs acc. to DIN 46234
- Insulated ring cable lugs to DIN 46237
- Insulated pin cable lugs to DIN 46231

General ordering data

Type	KQN-M16/-50	Version	
Order No.	1493180000		cable lug, terminal end,50 mm ²
GTIN (EAN)	4050118302844		
Qty.	50 pc(s).		
Type	KQN-M20/-50	Version	
Order No.	1493530000		cable lug, terminal end,50 mm ²
GTIN (EAN)	4050118303513		
Qty.	50 pc(s).		
Type	KQN-M6/-50	Version	
Order No.	1493510000		cable lug, terminal end,50 mm ²
GTIN (EAN)	4050118303179		
Qty.	50 pc(s).		
Type	KQN-M8/-50	Version	
Order No.	1493150000		cable lug, terminal end,50 mm ²
GTIN (EAN)	4050118302868		
Qty.	50 pc(s).		
Type	KQN-M10/-50	Version	
Order No.	1493160000		cable lug, terminal end,50 mm ²
GTIN (EAN)	4050118303049		
Qty.	50 pc(s).		
Type	KQN-M12/-50	Version	
Order No.	1493170000		cable lug, terminal end,50 mm ²
GTIN (EAN)	4050118303216		
Qty.	50 pc(s).		

ES EPG/HPG 60 WM 50

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

Accessories

50 mm²

The use of insulated connectors guarantees users consistent electrical connection quality in the long term.

- Wide range of insulated and non-insulated cable lugs and connectors
- Tubular cable lugs according to current market standards (Euroseries)
- Compression cable lugs acc. to DIN 46235
- Sheet metal cable lugs acc. to DIN 46234
- Insulated ring cable lugs to DIN 46237
- Insulated pin cable lugs to DIN 46231

General ordering data

Type	VSTN/50	Version	
Order No.	1493070000		cable lug, terminal end,50 mm ² ,50 mm ² ,None
GTIN (EAN)	4050118302691		
Qty.	100 pc(s).		

50 mm²

The use of insulated connectors guarantees users consistent electrical connection quality in the long term.

- Wide range of insulated and non-insulated cable lugs and connectors
- Tubular cable lugs according to current market standards (Euroseries)
- Compression cable lugs acc. to DIN 46235
- Sheet metal cable lugs acc. to DIN 46234
- Insulated ring cable lugs to DIN 46237
- Insulated pin cable lugs to DIN 46231

General ordering data

Type	VSTN/-50	Version	
Order No.	1494750000		cable lug, terminal end,50 mm ² ,50 mm ² ,None
GTIN (EAN)	4050118304381		
Qty.	50 pc(s).		

ES EPG/HPG 60 WM 50

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Accessories

50 mm²




The use of insulated connectors guarantees users consistent electrical connection quality in the long term.

- Wide range of insulated and non-insulated cable lugs and connectors
- Tubular cable lugs according to current market standards (Euroseries)
- Compression cable lugs acc. to DIN 46235
- Sheet metal cable lugs acc. to DIN 46234
- Insulated ring cable lugs to DIN 46237
- Insulated pin cable lugs to DIN 46231

General ordering data

Type	VPLN/-50	Version	
Order No.	1492930000		cable lug, terminal end,50 mm ² ,50 mm ² ,None
GTIN (EAN)	4050118302684		
Qty.	100 pc(s).		

50 mm²

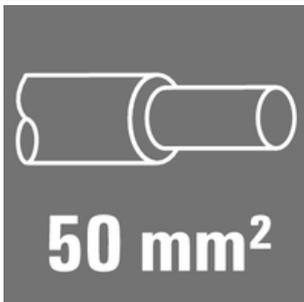

The use of insulated connectors guarantees users consistent electrical connection quality in the long term.

- Wide range of insulated and non-insulated cable lugs and connectors
- Tubular cable lugs according to current market standards (Euroseries)
- Compression cable lugs acc. to DIN 46235
- Sheet metal cable lugs acc. to DIN 46234
- Insulated ring cable lugs to DIN 46237
- Insulated pin cable lugs to DIN 46231

General ordering data

Type	KP-M12/-50	Version	
Order No.	1498090000		cable lug, terminal end,50 mm ²
GTIN (EAN)	4050118307375		
Qty.	100 pc(s).		
Type	KP-M8/-50	Version	
Order No.	1498070000		cable lug, terminal end,50 mm ²
GTIN (EAN)	4050118307566		
Qty.	100 pc(s).		
Type	KP-M16/-50	Version	
Order No.	1498110000		cable lug, terminal end,50 mm ²
GTIN (EAN)	4050118307474		
Qty.	100 pc(s).		
Type	KP-M14/-50	Version	
Order No.	1498570000		cable lug, terminal end,50 mm ²
GTIN (EAN)	4050118308105		
Qty.	100 pc(s).		

ES EPG/HPG 60 WM 50

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Accessories

Type	KP-M10/-50	Version
Order No.	1498080000	cable lug, terminal end,50 mm ²
GTIN (EAN)	4050118307559	
Qty.	100 pc(s).	
Type	KP-M20/-50	Version
Order No.	1498120000	cable lug, terminal end,50 mm ²
GTIN (EAN)	4050118307597	
Qty.	100 pc(s).	
Type	KP-M6/-50	Version
Order No.	1498510000	cable lug, terminal end,50 mm ²
GTIN (EAN)	4050118308006	
Qty.	100 pc(s).	

50 mm²



The use of insulated connectors guarantees users consistent electrical connection quality in the long term.

- Wide range of insulated and non-insulated cable lugs and connectors
- Tubular cable lugs according to current market standards (Euroseries)
- Compression cable lugs acc. to DIN 46235
- Sheet metal cable lugs acc. to DIN 46234
- Insulated ring cable lugs to DIN 46237
- Insulated pin cable lugs to DIN 46231

General ordering data

Type	KRN-M20/-50	Version
Order No.	1495840000	cable lug, terminal end,50 mm ² ,50 mm ² - 50 mm ²
GTIN (EAN)	4050118305364	
Qty.	100 pc(s).	
Type	KRN-M14/-50	Version
Order No.	1495750000	cable lug, terminal end,50 mm ² ,50 mm ² - 50 mm ²
GTIN (EAN)	4050118305197	
Qty.	100 pc(s).	
Type	KRN-M6/-50	Version
Order No.	1496590000	cable lug, terminal end,50 mm ² ,50 mm ² - 50 mm ²
GTIN (EAN)	4050118305746	
Qty.	100 pc(s).	
Type	KRN-M8/-50	Version
Order No.	1496600000	cable lug, terminal end,50 mm ² ,50 mm ² - 50 mm ²
GTIN (EAN)	4050118306149	
Qty.	100 pc(s).	
Type	KRN-M12/-50	Version
Order No.	1496620000	cable lug, terminal end,50 mm ² ,50 mm ² - 50 mm ²
GTIN (EAN)	4050118305722	
Qty.	100 pc(s).	
Type	KRN-M16/-50	Version
Order No.	1496630000	cable lug, terminal end,50 mm ² ,50 mm ² - 50 mm ²
GTIN (EAN)	4050118306200	
Qty.	100 pc(s).	

Creation date July 14, 2025 3:29:47 AM CEST

Catalogue status 04.07.2025 / We reserve the right to make technical changes.

ES EPG/HPG 60 WM 50

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

Accessories

Type	KRN-M10/-50	Version	
Order No.	1496610000		cable lug, terminal end,50 mm ² ,50 mm ² - 50 mm ²
GTIN (EAN)	4050118306064		
Qty.	100 pc(s).		

Tools



Crimping tools for cable lugs, connectors and wire-end ferrules with interchangeable inserts

- extremely fast processing thanks to hydraulic support
- large processing range up to 300 mm²
- 270° revolving quick-action crimping head
- automatic pressure limitation and monitoring via pressure sensor
- electronic control and monitoring of the crimping process
- Saving of all crimping cycles and error messages to internal memory
- Reading of all cycles and error messages via USB
- Li-ion rechargeable battery with charge status indicator: 18 V, 2 Ah

General ordering data

Type	EPG 60	Version	
Order No.	2453810000		Pressing tools, Tools, Pressing tool, 6mm ² , 300mm ² , Hexagonal crimp,
GTIN (EAN)	4050118468434		WM crimp, Indent crimp, Trapezoidal crimp, Oval crimping
Qty.	1 pc(s).		

50 mm²



The use of insulated connectors guarantees users consistent electrical connection quality in the long term.

- Wide range of insulated and non-insulated cable lugs and connectors
- Tubular cable lugs according to current market standards (Euroseries)
- Compression cable lugs acc. to DIN 46235
- Sheet metal cable lugs acc. to DIN 46234
- Insulated ring cable lugs to DIN 46237
- Insulated pin cable lugs to DIN 46231

General ordering data

Type	KWPN-M10/-50 90	Version	
Order No.	1497610000		cable lug, terminal end,50 mm ²
GTIN (EAN)	4050118307078		
Qty.	100 pc(s).		
Type	KWPN-M8/-50 90	Version	
Order No.	1497590000		cable lug, terminal end,50 mm ²
GTIN (EAN)	4050118306699		
Qty.	100 pc(s).		

ES EPG/HPG 60 WM 50

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Accessories

Type	KWPN-M12/-50 90	Version	
Order No.	1497620000	Version	cable lug, terminal end,50 mm ²
GTIN (EAN)	4050118306675		
Qty.	100 pc(s).		
Type	KWPN-M16/-50 90	Version	
Order No.	1497630000	Version	cable lug, terminal end,50 mm ²
GTIN (EAN)	4050118307115		
Qty.	100 pc(s).		

50 mm²



The use of insulated connectors guarantees users consistent electrical connection quality in the long term.

- Wide range of insulated and non-insulated cable lugs and connectors
- Tubular cable lugs according to current market standards (Euroseries)
- Compression cable lugs acc. to DIN 46235
- Sheet metal cable lugs acc. to DIN 46234
- Insulated ring cable lugs to DIN 46237
- Insulated pin cable lugs to DIN 46231

General ordering data

Type	VPN/-50	Version	
Order No.	1498660000	Version	cable lug, terminal end,50 mm ² ,50 mm ² ,None
GTIN (EAN)	4050118307948		
Qty.	50 pc(s).		

50 mm²



The use of insulated connectors guarantees users consistent electrical connection quality in the long term.

- Wide range of insulated and non-insulated cable lugs and connectors
- Tubular cable lugs according to current market standards (Euroseries)
- Compression cable lugs acc. to DIN 46235
- Sheet metal cable lugs acc. to DIN 46234
- Insulated ring cable lugs to DIN 46237
- Insulated pin cable lugs to DIN 46231

General ordering data

Type	KSN/-50	Version	
Order No.	1492820000	Version	cable lug, terminal end,50 mm ² ,50 mm ²
GTIN (EAN)	4050118302769		
Qty.	50 pc(s).		

ES EPG/HPG 60 WM 50

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Accessories

50 mm²



The use of insulated connectors guarantees users consistent electrical connection quality in the long term.

- Wide range of insulated and non-insulated cable lugs and connectors
- Tubular cable lugs according to current market standards (Euroseries)
- Compression cable lugs acc. to DIN 46235
- Sheet metal cable lugs acc. to DIN 46234
- Insulated ring cable lugs to DIN 46237
- Insulated pin cable lugs to DIN 46231

General ordering data

Type	KWN-M6/-50 45	Version
Order No.	1496270000	cable lug, terminal end,50 mm ² ,50 mm ² - 50 mm ²
GTIN (EAN)	4050118305937	
Qty.	50 pc(s).	
Type	KWN-M8/-50 45	Version
Order No.	1496280000	cable lug, terminal end,50 mm ² ,50 mm ² - 50 mm ²
GTIN (EAN)	4050118306101	
Qty.	50 pc(s).	
Type	KWN-M12/-50 45	Version
Order No.	1496300000	cable lug, terminal end,50 mm ² ,50 mm ² - 50 mm ²
GTIN (EAN)	4050118306040	
Qty.	50 pc(s).	
Type	KWN-M10/-50 45	Version
Order No.	1496290000	cable lug, terminal end,50 mm ² ,50 mm ² - 50 mm ²
GTIN (EAN)	4050118305760	
Qty.	50 pc(s).	

Tools



Crimping tools for cable lugs, connectors and wire-end ferrules with interchangeable inserts

- extremely fast processing thanks to hydraulic support
- large processing range up to 400 mm²
- 360° revolving quick action crimping head
- automatic pressure limitation and monitoring via pressure sensor
- Additional features for APG series:
- electronic control and monitoring of the crimping process
- Saving of all crimping cycles and error messages to internal memory
- Reading of all cycles and error messages via USB

General ordering data

Type	HPG 60	Version
Order No.	2453820000	6mm ² , 300mm ² , Hexagonal crimp, WM crimp, Indent crimp,
GTIN (EAN)	4050118468427	Trapezoidal crimp, Oval crimping
Qty.	1 pc(s).	

Creation date July 14, 2025 3:29:47 AM CEST

Catalogue status 04.07.2025 / We reserve the right to make technical changes.

9

ES EPG/HPG 60 WM 50

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Accessories

50 mm²



The use of insulated connectors guarantees users consistent electrical connection quality in the long term.

- Wide range of insulated and non-insulated cable lugs and connectors
- Tubular cable lugs according to current market standards (Euroseries)
- Compression cable lugs acc. to DIN 46235
- Sheet metal cable lugs acc. to DIN 46234
- Insulated ring cable lugs to DIN 46237
- Insulated pin cable lugs to DIN 46231

General ordering data

Type	KRN-M6/-50 S	Version	
Order No.	1494820000		cable lug, terminal end,50 mm ² ,50 mm ² - 50 mm ²
GTIN (EAN)	4050118304114		
Qty.	25 pc(s).		
Type	KRN-M8/-50 S	Version	
Order No.	1494830000		cable lug, terminal end,50 mm ² ,50 mm ² - 50 mm ²
GTIN (EAN)	4050118304404		
Qty.	25 pc(s).		
Type	KRN-M10/-50 S	Version	
Order No.	1494840000		cable lug, terminal end,50 mm ² ,50 mm ² - 50 mm ²
GTIN (EAN)	4050118304619		
Qty.	25 pc(s).		

50 mm²



The use of insulated connectors guarantees users consistent electrical connection quality in the long term.

- Wide range of insulated and non-insulated cable lugs and connectors
- Tubular cable lugs according to current market standards (Euroseries)
- Compression cable lugs acc. to DIN 46235
- Sheet metal cable lugs acc. to DIN 46234
- Insulated ring cable lugs to DIN 46237
- Insulated pin cable lugs to DIN 46231

General ordering data

Type	KWN-M6/-50 90	Version	
Order No.	1495950000		cable lug, terminal end,50 mm ² ,50 mm ² - 50 mm ²
GTIN (EAN)	4050118305388		
Qty.	100 pc(s).		
Type	KWN-M8/-50 90	Version	
Order No.	1495970000		cable lug, terminal end,50 mm ² ,50 mm ² - 50 mm ²
GTIN (EAN)	4050118305425		
Qty.	100 pc(s).		

ES EPG/HPG 60 WM 50

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Accessories

Type	KWN-M20/-50 90	Version
Order No.	1494710000	cable lug, terminal end,50 mm ² ,50 mm ² - 50 mm ²
GTIN (EAN)	4050118304442	
Qty.	100 pc(s).	
Type	KWN-M12/-50 90	Version
Order No.	1495990000	cable lug, terminal end,50 mm ² ,50 mm ² - 50 mm ²
GTIN (EAN)	4050118305654	
Qty.	100 pc(s).	
Type	KWN-M16/-50 90	Version
Order No.	1496000000	cable lug, terminal end,50 mm ² ,50 mm ² - 50 mm ²
GTIN (EAN)	4050118305630	
Qty.	100 pc(s).	
Type	KWN-M10/-50 90	Version
Order No.	1495980000	cable lug, terminal end,50 mm ² ,50 mm ² - 50 mm ²
GTIN (EAN)	4050118305494	
Qty.	100 pc(s).	
Type	KWN-M14/50 90	Version
Order No.	1494650000	cable lug, terminal end,50 mm ² ,50 mm ² - 50 mm ²
GTIN (EAN)	4050118304251	
Qty.	100 pc(s).	