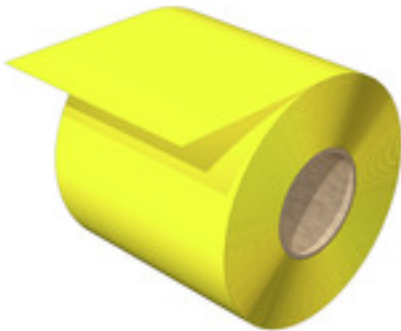


THM PV EL 90 GE 30M**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

UV-radiation causes high stress and aging of plastic in the outdoor application.

Our new THM PV labels resist these influences and are extremely durable in outdoor use.

Compact designed packaging are our TABPACK-PV. These are pre-printed warning labels, which should be a part of the basic equipment of a professional photovoltaic builder.

Your advantages at a glance:

- Weathering resistance tested according to ISO DIN EN ISO 4892-2:2013 table 3, procedure A cycle 1 at 5000 hours
- Individually labeled with the M-Print® PRO
- Easy and fast printing with the THM MultiMark

General ordering data

Version	Device markers, Device markers, 90 x , yellow
Order No.	2817440000
Type	THM PV EL 90 GE 30M
GTIN (EAN)	4064675322757
Qty.	1 pc(s).
compatible printer	2599430000 2599440000

THM PV EL 90 GE 30M

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data

Dimensions and weights

Depth	0.1 mm	Depth (inches)	0.004 inch
Height	90 mm	Height (inches)	3.543 inch
Length	30,000 mm	Length (inches)	1,181.1 inch
Net weight	290 g		

General data

Adhesive	Polyacrylate adhesive	Approval acc. to UL 969	Yes
Colour	yellow	Halogen	Yes
Length	30,000 mm	Material	Vinyl film
Operating temperature range, max.	110 °C	Operating temperature range, min.	-50 °C
Printed characters	without	UL 94 flammability rating	V-0
Version	Self-adhesive		

Conductor and cable markers

Halogen	Yes
---------	-----

Device markers

Halogen	Yes
---------	-----

Classifications

ETIM 6.0	EC001288	ETIM 7.0	EC001288
ETIM 8.0	EC001288	ETIM 9.0	EC001288
ETIM 10.0	EC001288	ECLASS 9.0	27-40-06-29
ECLASS 9.1	27-40-06-29	ECLASS 10.0	27-40-06-29
ECLASS 11.0	27-28-11-04	ECLASS 12.0	27-28-11-04
ECLASS 13.0	27-28-11-04	ECLASS 14.0	27-28-11-04
ECLASS 15.0	27-28-11-04		

Approvals

ROHS	Conform
------	---------

Environmental Product Compliance

RoHS Compliance Status	Compliant without exemption
REACH SVHC	No SVHC above 0.1 wt%

Downloads


White paper	Fact Sheet PV Markierer Fact Sheet EN PV Markers
Catalogues	Catalogues in PDF-format

THM PV EL 90 GE 30M

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

Drawings

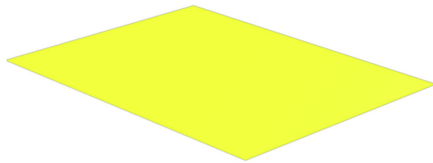

THM PV EL 90 GE 30M**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold


Germany

www.weidmueller.com**Accessories****Ink ribbons**

These printers produce excellent printing results thanks to the thermal transfer technique. Different materials and the user-friendly printing system under Windows optimise marking efforts.

General ordering data

Type	RIBBON MM 110/360 SW	Version
Order No.	2005070000	Ink ribbon
GTIN (EAN)	4050118390049	
Qty.	1 pc(s).	

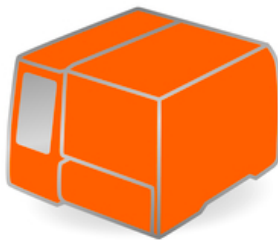THM MULTIMARK

These printers produce excellent printing results thanks to the thermal transfer technique. Different materials and the user-friendly printing system under Windows optimise marking efforts.

General ordering data

Type	MULTIMARK ROLLER 115
Order No.	1357420000
GTIN (EAN)	4050118160314
Qty.	1 pc(s).

THM PV EL 90 GE 30M

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26


D-32758 Detmold

Germany

www.weidmueller.com

Accessories

THM MULTIMARK PLUS

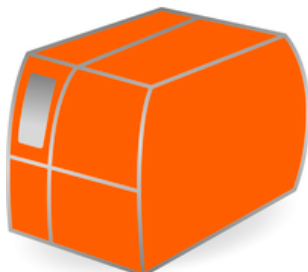

These printers produce excellent printing results thanks to the thermal transfer technique. Different materials and the user-friendly printing system under Windows optimise marking efforts.

General ordering data

Type	MULTIMARK PLUS ROLLER 1 ...
Order No.	2672590000
GTIN (EAN)	4050118708097
Qty.	1 pc(s).