

SDI SET S2.5-5.5/PH1/2 VOLT**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

VDE insulated screwdriver sets, for working on live parts up to 1000 V AC and 1500 V DC, DIN EN 60900. IEC 900. Each piece is "GS" safety tested. Blade made from fully hardened, high-alloy chromium-vanadium-molybdenum steel, gun-metal finish.

General ordering data

Version	Mounting tool
Order No.	2854990000
Type	SDI SET S2.5-5.5/PH1/2 VOLT
GTIN (EAN)	4064675530336
Qty.	1 pc(s).
Packaging	Cardboard box

SDI SET S2.5-5.5/PH1/2 VOLT**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com**Technical data****Dimensions and weights**

Width	285 mm	Width (inches)	11.22 inch
Net weight	507 g		

Technical data

Description of article	Screwdriver VDE SET + Volttester
------------------------	-------------------------------------

Screwing tools

Form	Slotted, Crosshead
------	--------------------

Classifications

ETIM 6.0	EC000149	ETIM 7.0	EC011815
ETIM 8.0	EC011815	ETIM 9.0	EC011815
ETIM 10.0	EC011815	ECLASS 9.0	21-04-50-03
ECLASS 9.1	21-04-50-03	ECLASS 10.0	21-04-50-03
ECLASS 11.0	21-04-50-16	ECLASS 12.0	21-04-50-16
ECLASS 13.0	21-04-50-16	ECLASS 14.0	21-04-50-16
ECLASS 15.0	21-04-50-16		

Approvals

Approvals



Approvals MAMID	https://mdcop.weidmueller.com/mediadelivery/rendition/900_319263/-T1z1mm-S800/
-----------------	---

Environmental Product Compliance

RoHS Compliance Status	Not affected
REACH SVHC	No SVHC above 0.1 wt%

Downloads

Catalogues	Catalogues in PDF-format
------------	--

SDI SET S2.5-5.5/PH1/2 VOLT

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26


D-32758 Detmold

Germany

www.weidmueller.com

Accessories

Slotted screwdriver

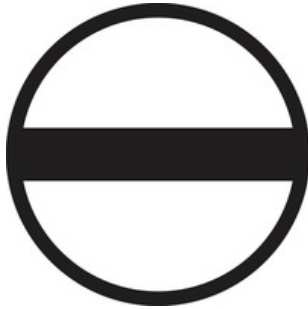

VDE insulated slot-head screwdriver, SDI DIN 7437, ISO 2380/2, drive output acc. to DIN 5264, ISO 2380/1. SoftFinish grip

General ordering data

Type	SDIS 0.4X2.0X60	Version
Order No.	2749780000	Screwdriver, Blade width (B): 2 mm, Blade length: 60 mm, Blade
GTIN (EAN)	4050118896527	thickness (A): 0.4 mm
Qty.	1 pc(s).	
Type	SDIS 0.4X2.5X75	Version
Order No.	2749790000	Screwdriver, Blade width (B): 2.5 mm, Blade length: 75 mm, Blade
GTIN (EAN)	4050118896534	thickness (A): 0.4 mm
Qty.	1 pc(s).	
Type	SDIS 0.5X3.0X100	Version
Order No.	2749800000	Screwdriver, Blade width (B): 3 mm, Blade length: 100 mm, Blade
GTIN (EAN)	4050118896541	thickness (A): 0.5 mm
Qty.	1 pc(s).	
Type	SDIS 0.6X3.5X100	Version
Order No.	2749810000	Screwdriver, Blade width (B): 3.5 mm, Blade length: 100 mm, Blade
GTIN (EAN)	4050118897012	thickness (A): 0.6 mm
Qty.	1 pc(s).	
Type	SDIS 0.8X4.0X100	Version
Order No.	2749820000	Screwdriver, Blade width (B): 4 mm, Blade length: 100 mm, Blade
GTIN (EAN)	4050118897029	thickness (A): 0.8 mm
Qty.	1 pc(s).	
Type	SDIS 1.0X5.5X125	Version
Order No.	2749850000	Screwdriver, Blade width (B): 5.5 mm, Blade length: 125 mm, Blade
GTIN (EAN)	4050118897050	thickness (A): 1 mm
Qty.	1 pc(s).	