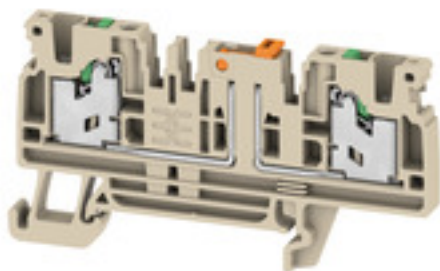


**SDT 2.5 2C****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)**General ordering data**

|            |                                                                                                                    |
|------------|--------------------------------------------------------------------------------------------------------------------|
| Version    | Test-disconnect terminal, SNAP IN, dark beige, 2.5 mm², 20 A, 500 V, Number of connections: 2, Number of levels: 1 |
| Order No.  | <a href="#">3016670000</a>                                                                                         |
| Type       | SDT 2.5 2C                                                                                                         |
| GTIN (EAN) | 4099986926523                                                                                                      |
| Qty.       | 50 pc(s).                                                                                                          |

**SDT 2.5 2C****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

**Technical data****Dimensions and weights**

|            |          |                 |            |
|------------|----------|-----------------|------------|
| Depth      | 37.65 mm | Depth (inches)  | 1.482 inch |
| Height     | 71 mm    | Height (inches) | 2.795 inch |
| Width      | 5.1 mm   | Width (inches)  | 0.201 inch |
| Net weight | 10.689 g |                 |            |

**Temperatures**

|                                  |        |                                  |        |
|----------------------------------|--------|----------------------------------|--------|
| Continuous operating temp., min. | -60 °C | Continuous operating temp., max. | 130 °C |
|----------------------------------|--------|----------------------------------|--------|

**Material data**

|                           |            |                                |       |
|---------------------------|------------|--------------------------------|-------|
| Material                  | Wemid      | Insulating material            | Wemid |
| Colour                    | dark beige | Colour of operational elements | green |
| UL 94 flammability rating | V-0        |                                |       |

**System specifications**

|                               |     |                                     |       |
|-------------------------------|-----|-------------------------------------|-------|
| End cover plate required      | Yes | Number of potentials                | 1     |
| Number of levels              | 1   | Number of clamping points per level | 2     |
| Number of potentials per tier | 1   | Levels cross-connected internally   | No    |
| PE connection                 | No  | Rail                                | TS 35 |
| N-function                    | No  | PE function                         | No    |
| PEN function                  | No  |                                     |       |

**Additional technical data**

|                          |       |                |         |
|--------------------------|-------|----------------|---------|
| Explosion-tested version | No    | Open sides     | right   |
| Snap-on                  | Yes   | Type of fixing | Snap-on |
| Type of mounting         | TS 35 |                |         |

**Conductors for clamping (additional connection)**

Connection type, additional connection SNAP IN

## SDT 2.5 2C

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

## Technical data

## Conductors for clamping (rated connection)

|                                                                                         |                      |                                                                                         |                     |
|-----------------------------------------------------------------------------------------|----------------------|-----------------------------------------------------------------------------------------|---------------------|
| Blade size                                                                              | 0.6 x 3.5 mm         | Clamping range, max.                                                                    | 2.5 mm <sup>2</sup> |
| Clamping range, min.                                                                    | 0.34 mm <sup>2</sup> | Connection cross-section, finely stranded, max.                                         | 2.5 mm <sup>2</sup> |
| Connection cross-section, finely stranded, min.                                         | 0.5 mm <sup>2</sup>  | Connection cross-section, stranded, max.                                                | 2.5 mm <sup>2</sup> |
| Connection cross-section, stranded, min.                                                | 0.5 mm <sup>2</sup>  | Connection direction                                                                    | top                 |
| Gauge to IEC 60947-1                                                                    | A3                   | Number of connections                                                                   | 2                   |
| Stripping length                                                                        | 10 mm                | Type of connection                                                                      | SNAP IN             |
| Type of connection 2                                                                    | SNAP IN              | Wire connection cross section AWG, max.                                                 | AWG 14              |
| Wire connection cross section AWG, min.                                                 | AWG 20               | Wire connection cross section, finely stranded, max.                                    | 2.5 mm <sup>2</sup> |
| Wire connection cross section, finely stranded, min.                                    | 2.5 mm <sup>2</sup>  | Wire connection cross-section, finely stranded with wire-end ferrules DIN 46228/1, max. | 0.5 mm <sup>2</sup> |
| Wire connection cross-section, finely stranded with wire-end ferrules DIN 46228/1, min. | 0.5 mm <sup>2</sup>  | Wire connection cross-section, finely stranded with wire-end ferrules DIN 46228/4, max. | 2.5 mm <sup>2</sup> |
| Wire connection cross-section, finely stranded with wire-end ferrules DIN 46228/4, min. | 0.5 mm <sup>2</sup>  |                                                                                         |                     |

## General

|                                         |        |                                         |               |
|-----------------------------------------|--------|-----------------------------------------|---------------|
| Rail                                    | TS 35  | Standards                               | IEC 60947-7-1 |
| Wire connection cross section AWG, max. | AWG 14 | Wire connection cross section AWG, min. | AWG 20        |

## Rating data

|                                              |                     |                                 |               |
|----------------------------------------------|---------------------|---------------------------------|---------------|
| Rated cross-section                          | 2.5 mm <sup>2</sup> | Rated voltage                   | 500 V         |
| Rated DC voltage                             | 500 V               | Rated current                   | 20 A          |
| Current at maximum wires                     | 20 A                | Standards                       | IEC 60947-7-1 |
| Volume resistance according to IEC 60947-7-x | 1.33 mΩ             | Rated impulse withstand voltage | 6 kV          |
| Power loss in accordance with IEC 60947-7-x  | 0.77 mW             | Pollution severity              | 3             |
| Surge voltage category                       | III                 |                                 |               |

## Classifications

|             |             |             |             |
|-------------|-------------|-------------|-------------|
| ETIM 6.0    | EC000902    | ETIM 7.0    | EC000902    |
| ETIM 8.0    | EC000902    | ETIM 9.0    | EC000902    |
| ETIM 10.0   | EC000902    | ECLASS 9.0  | 27-14-11-26 |
| ECLASS 9.1  | 27-14-11-26 | ECLASS 10.0 | 27-14-11-26 |
| ECLASS 11.0 | 27-14-11-26 | ECLASS 12.0 | 27-14-11-26 |
| ECLASS 13.0 | 27-25-01-09 | ECLASS 14.0 | 27-25-01-09 |
| ECLASS 15.0 | 27-25-01-09 |             |             |

## Approvals

Approvals



Approvals MAMID

[https://mdcop.weidmueller.com/mediadelivery/rendition/900\\_319222/-T1z1mm-S800/](https://mdcop.weidmueller.com/mediadelivery/rendition/900_319222/-T1z1mm-S800/)

Creation date June 25, 2025 11:03:49 AM CEST

Catalogue status 21.06.2025 / We reserve the right to make technical changes.

## SDT 2.5 2C

**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)

## Technical data

### Environmental Product Compliance

|                        |                             |
|------------------------|-----------------------------|
| RoHS Compliance Status | Compliant without exemption |
|------------------------|-----------------------------|

|            |                       |
|------------|-----------------------|
| REACH SVHC | No SVHC above 0.1 wt% |
|------------|-----------------------|

### Downloads

|                  |                                 |
|------------------|---------------------------------|
| Engineering Data | <a href="#">CAD data – STEP</a> |
|------------------|---------------------------------|

|                    |                                                              |
|--------------------|--------------------------------------------------------------|
| User Documentation | <a href="#">TI_maximum_voltages with adjoining terminals</a> |
|--------------------|--------------------------------------------------------------|

**SDT 2.5 2C**

**Weidmüller Interface GmbH & Co. KG**

 
Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)

**Drawings**



## SDT 2.5 2C

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

## Accessories

## Blank



WS markers are the perfect match for the W-series connectors. Thanks to their system compatibility, the WS tags can also be used with the I-series and the Z-series. The large marking surfaces do not only permit long character strings but also multi-line text. WS markers are ideal for labels with long, customised character strings. Thanks to the proven MultiCard format, printing with PrintJet CONNECT oder/or Plotter is possible.

- Can be fitted in strips or individually
- Markers in proven MultiCard format

**For custom printing:** Please send us a file of our labeling software M-Print PRO or M-Print PRO Online (without installation) for your labeling specifications.

## General ordering data

|            |                            |                                                                   |
|------------|----------------------------|-------------------------------------------------------------------|
| Type       | WS 8/5 PLUS MC NE WS       | Version                                                           |
| Order No.  | <a href="#">1951870000</a> | WS, Terminal marker, 8 x 5 mm, Pitch in mm (P): 5.00 Weidmueller, |
| GTIN (EAN) | 4032248631605              | Allen-Bradley, white                                              |
| Qty.       | 600 pc(s).                 |                                                                   |
| Type       | WS 8/5 MC NE BL            | Version                                                           |
| Order No.  | <a href="#">1773521693</a> | WS, Terminal marker, 8 x 5 mm, Pitch in mm (P): 5.00 Weidmueller, |
| GTIN (EAN) | 4032248141715              | Allen-Bradley, blue                                               |
| Qty.       | 720 pc(s).                 |                                                                   |
| Type       | WS 8/5 MC NE OR            | Version                                                           |
| Order No.  | <a href="#">1773521690</a> | WS, Terminal marker, 8 x 5 mm, Pitch in mm (P): 5.00 Weidmueller, |
| GTIN (EAN) | 4032248143092              | Allen-Bradley, orange                                             |
| Qty.       | 720 pc(s).                 |                                                                   |
| Type       | WS 8/5 MC NE WS            | Version                                                           |
| Order No.  | <a href="#">1640740000</a> | WS, Terminal marker, 8 x 5 mm, Pitch in mm (P): 5.00 Weidmueller, |
| GTIN (EAN) | 4008190279103              | Allen-Bradley, white                                              |
| Qty.       | 720 pc(s).                 |                                                                   |
| Type       | WS 8/5 MC NE RT            | Version                                                           |
| Order No.  | <a href="#">1773521686</a> | WS, Terminal marker, 8 x 5 mm, Pitch in mm (P): 5.00 Weidmueller, |
| GTIN (EAN) | 4032248141531              | Allen-Bradley, red                                                |
| Qty.       | 720 pc(s).                 |                                                                   |
| Type       | WS 8/5 MC NE GE            | Version                                                           |
| Order No.  | <a href="#">1773521687</a> | WS, Terminal marker, 8 x 5 mm, Pitch in mm (P): 5.00 Weidmueller, |
| GTIN (EAN) | 4032248141548              | Allen-Bradley, yellow                                             |
| Qty.       | 720 pc(s).                 |                                                                   |

## SDT 2.5 2C

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

## Accessories

## WS 8/5



## WS/ DEK

MultiMark terminal markers use an innovative composite material made from two components. The hard base contour of the marker snaps securely into the connector. The elastic surface finish makes the marker easy to mount. This specially punched material enables the strips to be stretched to accommodate the slight variations in spacing that tend to add up, especially with long terminal blocks. Another advantage: the excellent printability of the surface material guarantees durable and wear-resistant labelling. A print resolution of 300 dpi also produces a very legible script.

## Your benefits with MultiMark

- Firm hold and durable printing
- Continuous strips save installation time
- Easy mounting thanks to an innovative composite material
- Large label field for optimal legibility
- High flexibility thanks to manufacturer independence

## General ordering data

|            |                            |                                                   |
|------------|----------------------------|---------------------------------------------------|
| Type       | WS 8/5 MM BP WS            | Version                                           |
| Order No.  | <a href="#">2619810000</a> | WS, Terminal marker, 8 x 5 mm, Weidmueller, white |
| GTIN (EAN) | 4050118626278              |                                                   |
| Qty.       | 8,000 pc(s).               |                                                   |
| Type       | WS 8/5 MM WS               | Version                                           |
| Order No.  | <a href="#">2007150000</a> | WS, Terminal marker, 8 x 5 mm, Weidmueller, white |
| GTIN (EAN) | 4050118392029              |                                                   |
| Qty.       | 800 pc(s).                 |                                                   |

## Switch lock



## General ordering data

|            |                            |                                        |
|------------|----------------------------|----------------------------------------|
| Type       | DTLE 2.5/4                 | Version                                |
| Order No.  | <a href="#">2910530000</a> | Locking element (terminal), Wemid, red |
| GTIN (EAN) | 4099986519466              |                                        |
| Qty.       | 25 pc(s).                  |                                        |

## SDT 2.5 2C

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

## Accessories

## Blank



The Dekafix (DEK) marker is the universal marker for all conductor and plug-in connectors as well as for electronic sub-assemblies. The system is ideal for short number sequences and covers a wide range of ready-printed markers.

Strips for fast installation in only one work step. The printing is easy to read, rich in contrast and available in various widths.

- Large range of ready-to-use markers
- Strips for fast installation
- Terminal markers, suitable for all Weidmüller cable connectors
- Available as blank MultiCard or with standard printing

**For custom printing:** Please send us a file of our labeling software M-Print PRO or M-Print PRO Online (without installation) for your labeling specifications.

## General ordering data

|            |                            |                                                           |
|------------|----------------------------|-----------------------------------------------------------|
| Type       | DEK 5/5 MC NE SW           | Version                                                   |
| Order No.  | <a href="#">1457550000</a> | Dekafix, Terminal marker, 5 x 5 mm, Pitch in mm (P): 5.00 |
| GTIN (EAN) | 4050118263817              | Weidmueller, black                                        |
| Qty.       | 1,000 pc(s).               |                                                           |
| Type       | DEK 5/5 MC NE BL           | Version                                                   |
| Order No.  | <a href="#">1609801693</a> | Dekafix, Terminal marker, 5 x 5 mm, Pitch in mm (P): 5.00 |
| GTIN (EAN) | 4008190397166              | Weidmueller, blue                                         |
| Qty.       | 1,000 pc(s).               |                                                           |
| Type       | DEK 5/5 MC NE BR           | Version                                                   |
| Order No.  | <a href="#">1249870000</a> | Dekafix, Terminal marker, 5 x 5 mm, Pitch in mm (P): 5.00 |
| GTIN (EAN) | 4050118051865              | Weidmueller, brown                                        |
| Qty.       | 1,000 pc(s).               |                                                           |
| Type       | DEK 5/5 MC NE GN           | Version                                                   |
| Order No.  | <a href="#">1609801688</a> | Dekafix, Terminal marker, 5 x 5 mm, Pitch in mm (P): 5.00 |
| GTIN (EAN) | 4008190397142              | Weidmueller, green                                        |
| Qty.       | 1,000 pc(s).               |                                                           |
| Type       | DEK 5/5 MC NE WS           | Version                                                   |
| Order No.  | <a href="#">1609801044</a> | Dekafix, Terminal marker, 5 x 5 mm, Pitch in mm (P): 5.00 |
| GTIN (EAN) | 4008190397111              | Weidmueller, white                                        |
| Qty.       | 1,000 pc(s).               |                                                           |
| Type       | DEK 5/5 S MC NE WS         | Version                                                   |
| Order No.  | <a href="#">1341620000</a> | Dekafix, Terminal marker, 5 x 5 mm, Pitch in mm (P): 5.00 |
| GTIN (EAN) | 4050118145793              | Weidmueller, white                                        |
| Qty.       | 400 pc(s).                 |                                                           |
| Type       | DEK 5/5 MC NE GE           | Version                                                   |
| Order No.  | <a href="#">1609801687</a> | Dekafix, Terminal marker, 5 x 5 mm, Pitch in mm (P): 5.00 |
| GTIN (EAN) | 4008190397135              | Weidmueller, yellow                                       |
| Qty.       | 1,000 pc(s).               |                                                           |
| Type       | DEK 5/5 MC NE GR           | Version                                                   |
| Order No.  | <a href="#">1609801691</a> | Dekafix, Terminal marker, 5 x 5 mm, Pitch in mm (P): 5.00 |
| GTIN (EAN) | 4008190397159              | Weidmueller, grey                                         |
| Qty.       | 1,000 pc(s).               |                                                           |



## SDT 2.5 2C

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

## Accessories

|            |                            |                                                           |
|------------|----------------------------|-----------------------------------------------------------|
| Type       | DEK 5/5 MC NE VI           | Version                                                   |
| Order No.  | <a href="#">1249860000</a> | Dekafix, Terminal marker, 5 x 5 mm, Pitch in mm (P): 5.00 |
| GTIN (EAN) | 4050118042764              | Weidmueller, violet                                       |
| Qty.       | 1,000 pc(s).               |                                                           |
| Type       | DEK 5/5 MC NE RT           | Version                                                   |
| Order No.  | <a href="#">1609801686</a> | Dekafix, Terminal marker, 5 x 5 mm, Pitch in mm (P): 5.00 |
| GTIN (EAN) | 4008190397128              | Weidmueller, red                                          |
| Qty.       | 1,000 pc(s).               |                                                           |
| Type       | DEK 5/5 MC NE OR           | Version                                                   |
| Order No.  | <a href="#">1238340000</a> | Dekafix, Terminal marker, 5 x 5 mm, Pitch in mm (P): 5.00 |
| GTIN (EAN) | 4050118062632              | Weidmueller, orange                                       |
| Qty.       | 1,000 pc(s).               |                                                           |

## DEK 5/5



## WS/ DEK

MultiMark terminal markers use an innovative composite material made from two components. The hard base contour of the marker snaps securely into the connector. The elastic surface finish makes the marker easy to mount. This specially punched material enables the strips to be stretched to accommodate the slight variations in spacing that tend to add up, especially with long terminal blocks. Another advantage: the excellent printability of the surface material guarantees durable and wear-resistant labelling. A print resolution of 300 dpi also produces a very legible script.

**Your benefits with MultiMark**

- Firm hold and durable printing
- Continuous strips save installation time
- Easy mounting thanks to an innovative composite material
- Large label field for optimal legibility
- High flexibility thanks to manufacturer independence

## General ordering data

|            |                            |                                                        |
|------------|----------------------------|--------------------------------------------------------|
| Type       | DEK 5/5 MM BP WS           | Version                                                |
| Order No.  | <a href="#">2619770000</a> | Dekafix, Terminal marker, 5 x 5 mm, Weidmueller, white |
| GTIN (EAN) | 4050118626315              |                                                        |
| Qty.       | 10,000 pc(s).              |                                                        |
| Type       | DEK 5/5 MM WS              | Version                                                |
| Order No.  | <a href="#">2007110000</a> | Dekafix, Terminal marker, 5 x 5 mm, Weidmueller, white |
| GTIN (EAN) | 4050118391862              |                                                        |
| Qty.       | 800 pc(s).                 |                                                        |

## SDT 2.5 2C

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

## Accessories

## Custom printing



The Dekafix (DEK) marker is the universal marker for all conductor and plug-in connectors as well as for electronic sub-assemblies. The system is ideal for short number sequences and covers a wide range of ready-printed markers.

Strips for fast installation in only one work step. The printing is easy to read, rich in contrast and available in various widths.

- Large range of ready-to-use markers
- Strips for fast installation
- Terminal markers, suitable for all Weidmüller cable connectors
- Available as blank MultiCard or with standard printing

**For custom printing:** Please send us a file of our labeling software M-Print PRO or M-Print PRO Online (without installation) for your labeling specifications.

## General ordering data

|            |                            |                                                           |
|------------|----------------------------|-----------------------------------------------------------|
| Type       | DEK 5/5 S MC SDR           | Version                                                   |
| Order No.  | <a href="#">1341590000</a> | Dekafix, Terminal marker, 5 x 5 mm, Pitch in mm (P): 5.00 |
| GTIN (EAN) | 4050118146042              | Weidmueller, To customer specification                    |
| Qty.       | 80 pc(s).                  |                                                           |
| Type       | DEK 5/5 PLUS MC SDR        | Version                                                   |
| Order No.  | <a href="#">1854500000</a> | Dekafix, Terminal marker, 5 x 5 mm, Pitch in mm (P): 5.00 |
| GTIN (EAN) | 4032248393602              | Weidmueller, To customer specification                    |
| Qty.       | 200 pc(s).                 |                                                           |
| Type       | DEK 5/5 MC SDR             | Version                                                   |
| Order No.  | <a href="#">1609810000</a> | Dekafix, Terminal marker, 5 x 5 mm, Pitch in mm (P): 5.00 |
| GTIN (EAN) | 4008190456597              | Weidmueller, To customer specification                    |
| Qty.       | 200 pc(s).                 |                                                           |

2.5 mm<sup>2</sup>

## General ordering data

|            |                            |                                                                      |
|------------|----------------------------|----------------------------------------------------------------------|
| Type       | SEP 3C 2.5                 | Version                                                              |
| Order No.  | <a href="#">2751090000</a> | End plate for terminals, dark beige, Height: 69.5 mm, Width: 2.1 mm, |
| GTIN (EAN) | 4064675267614              | V-0, Wemid, Snap-on: Yes                                             |
| Qty.       | 20 pc(s).                  |                                                                      |

## SDT 2.5 2C

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

## Accessories

2.5 mm<sup>2</sup>


2.5  
mm<sup>2</sup>

The plug-in cross-connections feature easy handling and quick installation. This saves a great deal of time during installation in comparison with screwed solutions.

## General ordering data

|            |                            |                                                                       |
|------------|----------------------------|-----------------------------------------------------------------------|
| Type       | ZQV 2.5N/10 WT             | Version                                                               |
| Order No.  | <a href="#">2831640000</a> | Cross-connector (terminal), Plugged, white, 24 A, Number of poles:    |
| GTIN (EAN) | 40646754 16876             | 10, Pitch in mm (P): 5.10, Insulated: Yes, Width: 48.7 mm             |
| Qty.       | 20 pc(s).                  |                                                                       |
| Type       | ZQV 2.5N/9 BL              | Version                                                               |
| Order No.  | <a href="#">1527870000</a> | Cross-connector (terminal), Plugged, blue, 24 A, Number of poles: 9,  |
| GTIN (EAN) | 4050118448580              | Pitch in mm (P): 5.10, Insulated: Yes, Width: 43.6 mm                 |
| Qty.       | 20 pc(s).                  |                                                                       |
| Type       | ZQV 2.5N/5 BL              | Version                                                               |
| Order No.  | <a href="#">1527790000</a> | Cross-connector (terminal), Plugged, blue, 24 A, Number of poles: 5,  |
| GTIN (EAN) | 4050118448627              | Pitch in mm (P): 5.10, Insulated: Yes, Width: 23.2 mm                 |
| Qty.       | 20 pc(s).                  |                                                                       |
| Type       | ZQV 2.5N/8 BL              | Version                                                               |
| Order No.  | <a href="#">1527840000</a> | Cross-connector (terminal), Plugged, blue, 24 A, Number of poles: 8,  |
| GTIN (EAN) | 4050118448597              | Pitch in mm (P): 5.10, Insulated: Yes, Width: 38.5 mm                 |
| Qty.       | 20 pc(s).                  |                                                                       |
| Type       | ZQV 2.5N/4 RD              | Version                                                               |
| Order No.  | <a href="#">2108700000</a> | Cross-connector (terminal), Plugged, red, 24 A, Number of poles: 4,   |
| GTIN (EAN) | 4050118448528              | Pitch in mm (P): 5.10, Insulated: Yes, Width: 18.1 mm                 |
| Qty.       | 60 pc(s).                  |                                                                       |
| Type       | ZQV 2.5N/10 BL             | Version                                                               |
| Order No.  | <a href="#">1527880000</a> | Cross-connector (terminal), Plugged, blue, 24 A, Number of poles: 10, |
| GTIN (EAN) | 4050118448573              | Pitch in mm (P): 5.10, Insulated: Yes, Width: 48.7 mm                 |
| Qty.       | 20 pc(s).                  |                                                                       |
| Type       | ZQV 2.5N/2                 | Version                                                               |
| Order No.  | <a href="#">1527540000</a> | Cross-connector (terminal), Plugged, orange, 24 A, Number of poles:   |
| GTIN (EAN) | 4050118448467              | 2, Pitch in mm (P): 5.10, Insulated: Yes, Width: 7.9 mm               |
| Qty.       | 60 pc(s).                  |                                                                       |
| Type       | ZQV 2.5N/20 WT             | Version                                                               |
| Order No.  | <a href="#">2831650000</a> | Cross-connector (terminal), Plugged, white, 24 A, Number of poles:    |
| GTIN (EAN) | 40646754 16883             | 20, Pitch in mm (P): 5.10, Insulated: Yes, Width: 102 mm              |
| Qty.       | 20 pc(s).                  |                                                                       |
| Type       | ZQV 2.5N/6                 | Version                                                               |
| Order No.  | <a href="#">1527630000</a> | Cross-connector (terminal), Plugged, orange, 24 A, Number of poles:   |
| GTIN (EAN) | 4050118448429              | 6, Pitch in mm (P): 5.10, Insulated: Yes, Width: 28.3 mm              |
| Qty.       | 20 pc(s).                  |                                                                       |
| Type       | ZQV 2.5N/6 RD              | Version                                                               |
| Order No.  | <a href="#">2108720000</a> | Cross-connector (terminal), Plugged, red, 24 A, Number of poles: 6,   |
| GTIN (EAN) | 4050118448504              | Pitch in mm (P): 5.10, Insulated: Yes, Width: 28.3 mm                 |
| Qty.       | 20 pc(s).                  |                                                                       |

## SDT 2.5 2C

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

## Accessories

|            |                            |                                                                         |
|------------|----------------------------|-------------------------------------------------------------------------|
| Type       | ZQV 2.5N/8 RD              | Version                                                                 |
| Order No.  | <a href="#">2108870000</a> | Cross-connector (terminal), Plugged, red, 24 A, Number of poles: 8,     |
| GTIN (EAN) | 4050118448481              | Pitch in mm (P): 5.10, Insulated: Yes, Width: 38.5 mm                   |
| Qty.       | 20 pc(s).                  |                                                                         |
| Type       | ZQV 2.5N/8 WT              | Version                                                                 |
| Order No.  | <a href="#">2831620000</a> | Cross-connector (terminal), Plugged, white, 24 A, Number of poles: 8,   |
| GTIN (EAN) | 4064675416852              | Pitch in mm (P): 5.10, Insulated: Yes, Width: 38.5 mm                   |
| Qty.       | 20 pc(s).                  |                                                                         |
| Type       | ZQV 2.5N/4 WT              | Version                                                                 |
| Order No.  | <a href="#">2831580000</a> | Cross-connector (terminal), Plugged, white, 24 A, Number of poles: 4,   |
| GTIN (EAN) | 4064675416814              | Pitch in mm (P): 5.10, Insulated: Yes, Width: 18.1 mm                   |
| Qty.       | 60 pc(s).                  |                                                                         |
| Type       | ZQV 2.5N/3 WT              | Version                                                                 |
| Order No.  | <a href="#">2831570000</a> | Cross-connector (terminal), Plugged, white, 24 A, Number of poles: 3,   |
| GTIN (EAN) | 4064675416807              | Pitch in mm (P): 5.10, Insulated: Yes, Width: 13 mm                     |
| Qty.       | 60 pc(s).                  |                                                                         |
| Type       | ZQV 2.5N/7 WT              | Version                                                                 |
| Order No.  | <a href="#">2831610000</a> | Cross-connector (terminal), Plugged, white, 24 A, Number of poles: 7,   |
| GTIN (EAN) | 4064675416845              | Pitch in mm (P): 5.10, Insulated: Yes, Width: 33.4 mm                   |
| Qty.       | 20 pc(s).                  |                                                                         |
| Type       | ZQV 2.5N/7 BL              | Version                                                                 |
| Order No.  | <a href="#">1527830000</a> | Cross-connector (terminal), Plugged, blue, 24 A, Number of poles: 7,    |
| GTIN (EAN) | 4050118448603              | Pitch in mm (P): 5.10, Insulated: Yes, Width: 33.4 mm                   |
| Qty.       | 20 pc(s).                  |                                                                         |
| Type       | ZQV 2.5N/20 BL             | Version                                                                 |
| Order No.  | <a href="#">1527890000</a> | Cross-connector (terminal), Plugged, blue, 24 A, Number of poles: 20,   |
| GTIN (EAN) | 4050118448566              | Pitch in mm (P): 5.10, Insulated: Yes, Width: 102 mm                    |
| Qty.       | 20 pc(s).                  |                                                                         |
| Type       | ZQV 2.5N/6 WT              | Version                                                                 |
| Order No.  | <a href="#">2831600000</a> | Cross-connector (terminal), Plugged, white, 24 A, Number of poles: 6,   |
| GTIN (EAN) | 4064675416838              | Pitch in mm (P): 5.10, Insulated: Yes, Width: 28.3 mm                   |
| Qty.       | 20 pc(s).                  |                                                                         |
| Type       | ZQV 2.5N/8 BK              | Version                                                                 |
| Order No.  | <a href="#">2831730000</a> | Cross-connector (terminal), Plugged, black, 24 A, Number of poles: 8,   |
| GTIN (EAN) | 4064675416968              | Pitch in mm (P): 5.10, Insulated: Yes, Width: 38.5 mm                   |
| Qty.       | 20 pc(s).                  |                                                                         |
| Type       | ZQV 2.5N/50 RD             | Version                                                                 |
| Order No.  | <a href="#">2109000000</a> | Cross-connector (terminal), Plugged, red, 24 A, Number of poles: 50,    |
| GTIN (EAN) | 4050118486001              | Pitch in mm (P): 5.10, Insulated: Yes, Width: 255 mm                    |
| Qty.       | 5 pc(s).                   |                                                                         |
| Type       | ZQV 2.5N/20                | Version                                                                 |
| Order No.  | <a href="#">1527720000</a> | Cross-connector (terminal), Plugged, orange, 24 A, Number of poles: 20, |
| GTIN (EAN) | 4050118447972              | Pitch in mm (P): 5.10, Insulated: Yes, Width: 102 mm                    |
| Qty.       | 20 pc(s).                  |                                                                         |
| Type       | ZQV 2.5N/10 RD             | Version                                                                 |
| Order No.  | <a href="#">2108910000</a> | Cross-connector (terminal), Plugged, red, 24 A, Number of poles: 10,    |
| GTIN (EAN) | 4050118486018              | Pitch in mm (P): 5.10, Insulated: Yes, Width: 48.7 mm                   |
| Qty.       | 20 pc(s).                  |                                                                         |
| Type       | ZQV 2.5N/20 RD             | Version                                                                 |
| Order No.  | <a href="#">2108920000</a> | Cross-connector (terminal), Plugged, red, 24 A, Number of poles: 20,    |
| GTIN (EAN) | 4050118485899              | Pitch in mm (P): 5.10, Insulated: Yes, Width: 102 mm                    |
| Qty.       | 20 pc(s).                  |                                                                         |

## SDT 2.5 2C

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

## Accessories

|            |                            |                                                                        |
|------------|----------------------------|------------------------------------------------------------------------|
| Type       | ZQV 2.5N/5 RD              | Version                                                                |
| Order No.  | <a href="#">2108710000</a> | Cross-connector (terminal), Plugged, red, 24 A, Number of poles: 5,    |
| GTIN (EAN) | 4050118448511              | Pitch in mm (P): 5.10, Insulated: Yes, Width: 23.2 mm                  |
| Qty.       | 20 pc(s).                  |                                                                        |
| Type       | ZQV 2.5N/6 BL              | Version                                                                |
| Order No.  | <a href="#">1527820000</a> | Cross-connector (terminal), Plugged, blue, 24 A, Number of poles: 6,   |
| GTIN (EAN) | 4050118448610              | Pitch in mm (P): 5.10, Insulated: Yes, Width: 28.3 mm                  |
| Qty.       | 20 pc(s).                  |                                                                        |
| Type       | ZQV 2.5N/6 BK              | Version                                                                |
| Order No.  | <a href="#">2831710000</a> | Cross-connector (terminal), Plugged, black, 24 A, Number of poles: 6,  |
| GTIN (EAN) | 4064675416944              | Pitch in mm (P): 5.10, Insulated: Yes, Width: 28.3 mm                  |
| Qty.       | 20 pc(s).                  |                                                                        |
| Type       | ZQV 2.5N/3 BK              | Version                                                                |
| Order No.  | <a href="#">2831680000</a> | Cross-connector (terminal), Plugged, black, 24 A, Number of poles: 3,  |
| GTIN (EAN) | 4064675416913              | Pitch in mm (P): 5.10, Insulated: Yes, Width: 13 mm                    |
| Qty.       | 60 pc(s).                  |                                                                        |
| Type       | ZQV 2.5N/5                 | Version                                                                |
| Order No.  | <a href="#">1527620000</a> | Cross-connector (terminal), Plugged, orange, 24 A, Number of poles:    |
| GTIN (EAN) | 4050118448436              | 5, Pitch in mm (P): 5.10, Insulated: Yes, Width: 23.2 mm               |
| Qty.       | 20 pc(s).                  |                                                                        |
| Type       | ZQV 2.5N/7 BK              | Version                                                                |
| Order No.  | <a href="#">2831720000</a> | Cross-connector (terminal), Plugged, black, 24 A, Number of poles: 7,  |
| GTIN (EAN) | 4064675416951              | Pitch in mm (P): 5.10, Insulated: Yes, Width: 33.4 mm                  |
| Qty.       | 20 pc(s).                  |                                                                        |
| Type       | ZQV 2.5N/20 BK             | Version                                                                |
| Order No.  | <a href="#">2831760000</a> | Cross-connector (terminal), Plugged, black, 24 A, Number of poles: 20, |
| GTIN (EAN) | 4064675416999              | Pitch in mm (P): 5.10, Insulated: Yes, Width: 102 mm                   |
| Qty.       | 20 pc(s).                  |                                                                        |
| Type       | ZQV 2.5N/50                | Version                                                                |
| Order No.  | <a href="#">1527730000</a> | Cross-connector (terminal), Plugged, orange, 24 A, Number of poles:    |
| GTIN (EAN) | 4050118411362              | 50, Pitch in mm (P): 5.10, Insulated: Yes, Width: 255 mm               |
| Qty.       | 5 pc(s).                   |                                                                        |
| Type       | ZQV 2.5N/2 RD              | Version                                                                |
| Order No.  | <a href="#">2108470000</a> | Cross-connector (terminal), Plugged, red, 24 A, Number of poles: 2,    |
| GTIN (EAN) | 4050118448542              | Pitch in mm (P): 5.10, Insulated: Yes, Width: 7.9 mm                   |
| Qty.       | 60 pc(s).                  |                                                                        |
| Type       | ZQV 2.5N/4 BL              | Version                                                                |
| Order No.  | <a href="#">1527780000</a> | Cross-connector (terminal), Plugged, blue, 24 A, Number of poles: 4,   |
| GTIN (EAN) | 4050118448634              | Pitch in mm (P): 5.10, Insulated: Yes, Width: 18.1 mm                  |
| Qty.       | 60 pc(s).                  |                                                                        |
| Type       | ZQV 2.5N/7                 | Version                                                                |
| Order No.  | <a href="#">1527640000</a> | Cross-connector (terminal), Plugged, orange, 24 A, Number of poles:    |
| GTIN (EAN) | 4050118448412              | 7, Pitch in mm (P): 5.10, Insulated: Yes, Width: 33.4 mm               |
| Qty.       | 20 pc(s).                  |                                                                        |
| Type       | ZQV 2.5N/50 BL             | Version                                                                |
| Order No.  | <a href="#">1527920000</a> | Cross-connector (terminal), Plugged, blue, 24 A, Number of poles: 50,  |
| GTIN (EAN) | 4050118448559              | Pitch in mm (P): 5.10, Insulated: Yes, Width: 255 mm                   |
| Qty.       | 5 pc(s).                   |                                                                        |
| Type       | ZQV 2.5N/3 BL              | Version                                                                |
| Order No.  | <a href="#">1527770000</a> | Cross-connector (terminal), Plugged, blue, 24 A, Number of poles: 3,   |
| GTIN (EAN) | 4050118448641              | Pitch in mm (P): 5.10, Insulated: Yes, Width: 13 mm                    |
| Qty.       | 60 pc(s).                  |                                                                        |

Creation date June 25, 2025 11:03:49 AM CEST

## SDT 2.5 2C

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

## Accessories

|            |                            |                                                                       |
|------------|----------------------------|-----------------------------------------------------------------------|
| Type       | ZQV 2.5N/9                 | Version                                                               |
| Order No.  | <a href="#">1527680000</a> | Cross-connector (terminal), Plugged, orange, 24 A, Number of poles:   |
| GTIN (EAN) | 4050118447996              | 9, Pitch in mm (P): 5.10, Insulated: Yes, Width: 43.6 mm              |
| Qty.       | 20 pc(s).                  |                                                                       |
| Type       | ZQV 2.5N/5 WT              | Version                                                               |
| Order No.  | <a href="#">2831590000</a> | Cross-connector (terminal), Plugged, white, 24 A, Number of poles: 5, |
| GTIN (EAN) | 4064675416821              | Pitch in mm (P): 5.10, Insulated: Yes, Width: 23.2 mm                 |
| Qty.       | 20 pc(s).                  |                                                                       |
| Type       | ZQV 2.5N/3 RD              | Version                                                               |
| Order No.  | <a href="#">2108690000</a> | Cross-connector (terminal), Plugged, red, 24 A, Number of poles: 3,   |
| GTIN (EAN) | 4050118448535              | Pitch in mm (P): 5.10, Insulated: Yes, Width: 13 mm                   |
| Qty.       | 60 pc(s).                  |                                                                       |
| Type       | ZQV 2.5N/8                 | Version                                                               |
| Order No.  | <a href="#">1527670000</a> | Cross-connector (terminal), Plugged, orange, 24 A, Number of poles:   |
| GTIN (EAN) | 4050118448405              | 8, Pitch in mm (P): 5.10, Insulated: Yes, Width: 38.5 mm              |
| Qty.       | 20 pc(s).                  |                                                                       |
| Type       | ZQV 2.5N/4                 | Version                                                               |
| Order No.  | <a href="#">1527590000</a> | Cross-connector (terminal), Plugged, orange, 24 A, Number of poles:   |
| GTIN (EAN) | 4050118448443              | 4, Pitch in mm (P): 5.10, Insulated: Yes, Width: 18.1 mm              |
| Qty.       | 60 pc(s).                  |                                                                       |
| Type       | ZQV 2.5N/4 BK              | Version                                                               |
| Order No.  | <a href="#">2831690000</a> | Cross-connector (terminal), Plugged, black, 24 A, Number of poles: 4, |
| GTIN (EAN) | 4064675416920              | Pitch in mm (P): 5.10, Insulated: Yes, Width: 18.1 mm                 |
| Qty.       | 60 pc(s).                  |                                                                       |
| Type       | ZQV 2.5N/9 WT              | Version                                                               |
| Order No.  | <a href="#">2831630000</a> | Cross-connector (terminal), Plugged, white, 24 A, Number of poles: 9, |
| GTIN (EAN) | 4064675416869              | Pitch in mm (P): 5.10, Insulated: Yes, Width: 43.6 mm                 |
| Qty.       | 20 pc(s).                  |                                                                       |
| Type       | ZQV 2.5N/2 BK              | Version                                                               |
| Order No.  | <a href="#">2831670000</a> | Cross-connector (terminal), Plugged, black, 24 A, Number of poles: 2, |
| GTIN (EAN) | 4064675416906              | Pitch in mm (P): 5.10, Insulated: Yes, Width: 7.9 mm                  |
| Qty.       | 60 pc(s).                  |                                                                       |
| Type       | ZQV 2.5N/50 WT             | Version                                                               |
| Order No.  | <a href="#">2831660000</a> | Cross-connector (terminal), Plugged, white, 24 A, Number of poles:    |
| GTIN (EAN) | 4064675416890              | 50, Pitch in mm (P): 5.10, Insulated: Yes, Width: 255 mm              |
| Qty.       | 5 pc(s).                   |                                                                       |
| Type       | ZQV 2.5N/2 BL              | Version                                                               |
| Order No.  | <a href="#">1527740000</a> | Cross-connector (terminal), Plugged, blue, 24 A, Number of poles: 2,  |
| GTIN (EAN) | 4050118448658              | Pitch in mm (P): 5.10, Insulated: Yes, Width: 7.9 mm                  |
| Qty.       | 60 pc(s).                  |                                                                       |
| Type       | ZQV 2.5N/10                | Version                                                               |
| Order No.  | <a href="#">1527690000</a> | Cross-connector (terminal), Plugged, orange, 24 A, Number of poles:   |
| GTIN (EAN) | 4050118447989              | 10, Pitch in mm (P): 5.10, Insulated: Yes, Width: 48.7 mm             |
| Qty.       | 20 pc(s).                  |                                                                       |
| Type       | ZQV 2.5N/9 RD              | Version                                                               |
| Order No.  | <a href="#">2108900000</a> | Cross-connector (terminal), Plugged, red, 24 A, Number of poles: 9,   |
| GTIN (EAN) | 4050118448474              | Pitch in mm (P): 5.10, Insulated: Yes, Width: 43.6 mm                 |
| Qty.       | 20 pc(s).                  |                                                                       |
| Type       | ZQV 2.5N/5 BK              | Version                                                               |
| Order No.  | <a href="#">2831700000</a> | Cross-connector (terminal), Plugged, black, 24 A, Number of poles: 5, |
| GTIN (EAN) | 4064675416937              | Pitch in mm (P): 5.10, Insulated: Yes, Width: 23.2 mm                 |
| Qty.       | 20 pc(s).                  |                                                                       |

Creation date June 25, 2025 11:03:49 AM CEST

Catalogue status 21.06.2025 / We reserve the right to make technical changes.

14

## SDT 2.5 2C

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

## Accessories

|            |                            |                                                                        |
|------------|----------------------------|------------------------------------------------------------------------|
| Type       | ZQV 2.5N/50 BK             | Version                                                                |
| Order No.  | <a href="#">2831770000</a> | Cross-connector (terminal), Plugged, black, 24 A, Number of poles: 50, |
| GTIN (EAN) | 4064675417002              | Pitch in mm (P): 5.10, Insulated: Yes, Width: 255 mm                   |
| Qty.       | 5 pc(s).                   |                                                                        |
| Type       | ZQV 2.5N/7 RD              | Version                                                                |
| Order No.  | <a href="#">2108810000</a> | Cross-connector (terminal), Plugged, red, 24 A, Number of poles: 7,    |
| GTIN (EAN) | 4050118448498              | Pitch in mm (P): 5.10, Insulated: Yes, Width: 33.4 mm                  |
| Qty.       | 20 pc(s).                  |                                                                        |
| Type       | ZQV 2.5N/10 BK             | Version                                                                |
| Order No.  | <a href="#">2831750000</a> | Cross-connector (terminal), Plugged, black, 24 A, Number of poles: 10, |
| GTIN (EAN) | 4064675416982              | Pitch in mm (P): 5.10, Insulated: Yes, Width: 48.7 mm                  |
| Qty.       | 20 pc(s).                  |                                                                        |
| Type       | ZQV 2.5N/2 WT              | Version                                                                |
| Order No.  | <a href="#">2831560000</a> | Cross-connector (terminal), Plugged, white, 24 A, Number of poles: 2,  |
| GTIN (EAN) | 4064675416692              | Pitch in mm (P): 5.10, Insulated: Yes, Width: 7.9 mm                   |
| Qty.       | 60 pc(s).                  |                                                                        |
| Type       | ZQV 2.5N/9 BK              | Version                                                                |
| Order No.  | <a href="#">2831740000</a> | Cross-connector (terminal), Plugged, black, 24 A, Number of poles: 9,  |
| GTIN (EAN) | 4064675416975              | Pitch in mm (P): 5.10, Insulated: Yes, Width: 43.6 mm                  |
| Qty.       | 20 pc(s).                  |                                                                        |
| Type       | ZQV 2.5N/3                 | Version                                                                |
| Order No.  | <a href="#">1527570000</a> | Cross-connector (terminal), Plugged, orange, 24 A, Number of poles:    |
| GTIN (EAN) | 4050118448450              | 3, Pitch in mm (P): 5.10, Insulated: Yes, Width: 13 mm                 |
| Qty.       | 60 pc(s).                  |                                                                        |

## A-Series



Weidmüller's range of products includes end brackets that guarantee a permanent, reliable mounting on the terminal rail and prevent sliding. Versions with and without screws are available. The end brackets include marking options, also for group markers, and also a test plug holder.

## General ordering data

|            |                            |                       |
|------------|----------------------------|-----------------------|
| Type       | AEB 35 SCL/1 V0            | Version               |
| Order No.  | <a href="#">2661280000</a> | A-series, End bracket |
| GTIN (EAN) | 4050118702163              |                       |
| Qty.       | 20 pc(s).                  |                       |
| Type       | AEB 35 SC/1                | Version               |
| Order No.  | <a href="#">1991920000</a> | A-series, End bracket |
| GTIN (EAN) | 4050118376722              |                       |
| Qty.       | 50 pc(s).                  |                       |
| Type       | AEB 35 SCL/1 V0 BK         | Version               |
| Order No.  | <a href="#">2661300000</a> | A-series, End bracket |
| GTIN (EAN) | 4050118702187              |                       |
| Qty.       | 20 pc(s).                  |                       |

## SDT 2.5 2C

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

## Accessories

|            |                            |                       |
|------------|----------------------------|-----------------------|
| Type       | AEB 35 SCL/1 V0 GY         | Version               |
| Order No.  | <a href="#">2661290000</a> | A-series, End bracket |
| GTIN (EAN) | 4050118702170              |                       |
| Qty.       | 20 pc(s).                  |                       |
| Type       | AEB 35 SC/1 BK             | Version               |
| Order No.  | <a href="#">2475310000</a> | A-series, End bracket |
| GTIN (EAN) | 4050118487114              |                       |
| Qty.       | 50 pc(s).                  |                       |

## Fuse holder



The fuse holder SIHA quickly turns a disconnect terminal into a fuse terminal: simply remove the disconnect lever and attach the fuse unit.

## General ordering data

|            |                            |                                                                        |
|------------|----------------------------|------------------------------------------------------------------------|
| Type       | SIHA 3/G20 BL              | Version                                                                |
| Order No.  | <a href="#">1004260000</a> | Fuse holder for feed-through modular terminal, blue, 6.3 A, pluggable, |
| GTIN (EAN) | 4032248709717              | V-0, Wemid                                                             |
| Qty.       | 25 pc(s).                  |                                                                        |
| Type       | SIHA 3/G20/LD 10-36V BL    | Version                                                                |
| Order No.  | <a href="#">1005250000</a> | Fuse holder for feed-through modular terminal, blue, 2.31 A,           |
| GTIN (EAN) | 4032248712038              | pluggable, V-0, Wemid                                                  |
| Qty.       | 25 pc(s).                  |                                                                        |
| Type       | SIHA 3/G20/LD 140-250V     | Version                                                                |
| Order No.  | <a href="#">7921600000</a> | Fuse holder for feed-through modular terminal, black, 2.31 mA,         |
| GTIN (EAN) | 4032248322633              | pluggable, V-0, Wemid                                                  |
| Qty.       | 25 pc(s).                  |                                                                        |
| Type       | SIHA 3/G20/LD 35-70V       | Version                                                                |
| Order No.  | <a href="#">7921580000</a> | Fuse holder for feed-through modular terminal, black, 2.31 mA,         |
| GTIN (EAN) | 4032248322619              | pluggable, V-0, Wemid                                                  |
| Qty.       | 25 pc(s).                  |                                                                        |
| Type       | SIHA 3/G20/LD 60-150V      | Version                                                                |
| Order No.  | <a href="#">7921590000</a> | Fuse holder for feed-through modular terminal, black, 2.31 mA,         |
| GTIN (EAN) | 4032248322626              | pluggable, V-0, Wemid                                                  |
| Qty.       | 25 pc(s).                  |                                                                        |
| Type       | SIHA 3/G20/LD 10-36V       | Version                                                                |
| Order No.  | <a href="#">7921570000</a> | Fuse holder for feed-through modular terminal, black, 2.31 mA,         |
| GTIN (EAN) | 4032248322503              | pluggable, V-0, Wemid                                                  |
| Qty.       | 25 pc(s).                  |                                                                        |
| Type       | SIHA 3/G20                 | Version                                                                |
| Order No.  | <a href="#">7926190000</a> | Fuse holder for feed-through modular terminal, black, 6.3 A,           |
| GTIN (EAN) | 4032248264612              | pluggable, V-0, Wemid                                                  |
| Qty.       | 1,000 pc(s).               |                                                                        |



**SDT 2.5 2C****Weidmüller Interface GmbH & Co. KG**


Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)**Accessories**

|            |                            |                                                              |
|------------|----------------------------|--------------------------------------------------------------|
| Type       | SIHA 3/G20                 | Version                                                      |
| Order No.  | <a href="#">7921560000</a> | Fuse holder for feed-through modular terminal, black, 6.3 A, |
| GTIN (EAN) | 4032248264643              | pluggable, V-0, Wemid                                        |
| Qty.       | 25 pc(s).                  |                                                              |

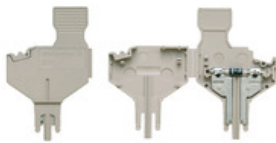**Component plugs**

The component plug is used to integrate an electrical component in a disconnect terminal block. After soldering the electronic component, the plug can be integrated into the disconnection area of our disconnect terminal blocks and thus changes the disconnect terminal block into a modular terminal block with integrated electronic component.

**General ordering data**

|            |                            |                                   |
|------------|----------------------------|-----------------------------------|
| Type       | BEST                       | Version                           |
| Order No.  | <a href="#">1833100000</a> | Accessories, Component plug       |
| GTIN (EAN) | 4032248501014              |                                   |
| Qty.       | 50 pc(s).                  |                                   |
| Type       | BEST/D                     | Version                           |
| Order No.  | <a href="#">1878560000</a> | Accessories, Component plug, 1 A  |
| GTIN (EAN) | 4032248471492              |                                   |
| Qty.       | 50 pc(s).                  |                                   |
| Type       | BEST/DRBR                  | Version                           |
| Order No.  | <a href="#">1878570000</a> | Accessories, Component plug, 22 A |
| GTIN (EAN) | 4032248471508              |                                   |
| Qty.       | 50 pc(s).                  |                                   |