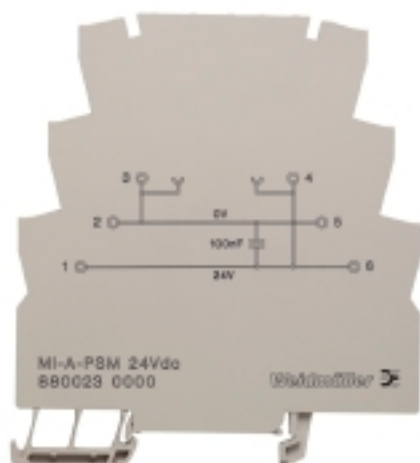


MI-A-PSM24VDC**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Specific adapter to be connected to the MICROSERIE RELAYS using a 10-pole flat-cable connector or 15-pole Sub-D connector.

General ordering data

Version	Adapter, MICRO-Interface, IEC 60603/DIN41612 plug-in connectors, Screw connection
Order No.	8800230000
Type	MI-A-PSM24VDC
GTIN (EAN)	4032248497171
Qty.	10 pc(s).

MI-A-PSM24VDC

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data

Dimensions and weights

Depth	6 mm	Depth (inches)	0.236 inch
Height	98 mm	Height (inches)	3.858 inch
Width	88 mm	Width (inches)	3.465 inch
Net weight	32 g		

Temperatures

Storage temperature	-20...85 °C	Operating temperature	0...50 °C
---------------------	-------------	-----------------------	-----------

Connection data

Voltage supply	max. 30 V AC/DC
----------------	-----------------

Ratings data

Operating voltage	30 V UC	Max. current per channel	0.5 A
Total operating current	2 A		

Insulation coordination (EN50178)

According to	DIN EN 50178	Rated insulation voltage	< 50 V AC
Surge voltage category	III	Pollution severity level	2
Insulation test voltage AC	0.35 kV		

Supply connection

Type of connection	Screw connection
--------------------	------------------

Classifications

ETIM 6.0	EC002584	ETIM 7.0	EC002584
ETIM 8.0	EC002584	ETIM 9.0	EC002584
ETIM 10.0	EC002584	ECLASS 9.0	27-33-02-92
ECLASS 9.1	27-24-22-92	ECLASS 10.0	27-33-02-92
ECLASS 11.0	27-33-02-92	ECLASS 12.0	27-33-02-92
ECLASS 13.0	27-33-02-92	ECLASS 14.0	27-33-02-92
ECLASS 15.0	27-33-02-92		

Approvals

ROHS	Conform
------	---------

Environmental Product Compliance

RoHS Compliance Status	Compliant without exemption
REACH SVHC	No SVHC above 0.1 wt%

Downloads

Catalogues	Catalogues in PDF-format
------------	--

MI-A-PSM24VDC

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Drawings

Electric symbol

