
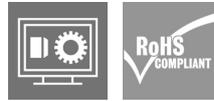


H0,75/16T ZH HBL SV

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

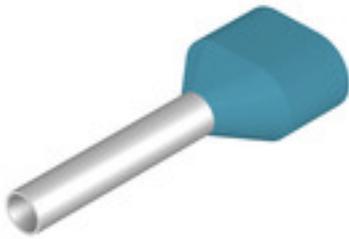

- in multipack bag (5 x 100 pcs.)
- Weidmüller colour code
- DIN colour code
- other colour code

General ordering data

| | |
|------------|---|
| Version | Wire-end ferrule, Twin wire-end ferrule, 13 mm, 10 mm, Light Blue |
| Order No. | 9005 140000 |
| Type | H0,75/16T ZH HBL SV |
| GTIN (EAN) | 4008 190482725 |
| Qty. | 500 pc(s). |
| Packaging | Multipack bag |

Creation date June 13, 2025 2:45:37 AM CEST

Catalogue status 07.06.2025 / We reserve the right to make technical changes.

H0,75/16T ZH HBL SV

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data

Dimensions and weights

Net weight 0.15 g

Technical data

| | | | |
|------------------------|-----------------------------------|---------|-----------------------|
| Description of article | Twin wire end ferrule, light blue | Version | Twin wire-end ferrule |
|------------------------|-----------------------------------|---------|-----------------------|

Wire-end ferrules

| | | | |
|---|---------------|-----------------------------|----------------------|
| Collar height (A) | 5.5 mm | Collar width (B) | 3 mm |
| Colour code | Telemecanique | Conductor cross-section | 0.75 mm ² |
| Contact surface diameter (D1) | 1.7 mm | Contact surface length (L2) | 10 mm |
| L1 in mm | 16 mm | Metal sleeve thickness (S1) | 0.15 mm |
| Plastic collar thickness (S2) | 0.3 mm | Stripping length | 13 mm |
| Wire connection cross section AWG, max. | AWG 18 | | |

Classifications

| | | | |
|-------------|-------------|-------------|-------------|
| ETIM 6.0 | EC000005 | ETIM 7.0 | EC000005 |
| ETIM 8.0 | EC000005 | ETIM 9.0 | EC000005 |
| ETIM 10.0 | EC000005 | ECLASS 9.0 | 27-40-02-01 |
| ECLASS 9.1 | 27-40-02-01 | ECLASS 10.0 | 27-40-02-01 |
| ECLASS 11.0 | 27-40-02-01 | ECLASS 12.0 | 27-40-02-01 |
| ECLASS 13.0 | 27-40-02-01 | ECLASS 14.0 | 27-40-02-01 |
| ECLASS 15.0 | 27-40-02-01 | | |

Environmental Product Compliance

| | |
|------------------------|-----------------------------|
| RoHS Compliance Status | Compliant without exemption |
| REACH SVHC | No SVHC above 0.1 wt% |

Approvals

| | |
|------|---------|
| ROHS | Conform |
|------|---------|

Downloads

| | |
|---|--|
| Approval/Certificate/Document of Conformity | Certificate of Compliance |
| Engineering Data | CAD data – STEP |
| User Documentation | Technical information - EN Technical information - DE |
| Catalogues | Catalogues in PDF-format |
| Brochures | |

Data sheet

H0,75/16T ZH HBL SV

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

Drawings

Drawing

