


Datasheet revision 1.1

[www.chipquik.com](http://www(chipquik.com)


## Solder Training Board with many configurations & components (120 parts)

Product comes unassembled with 120 parts.

Photos:

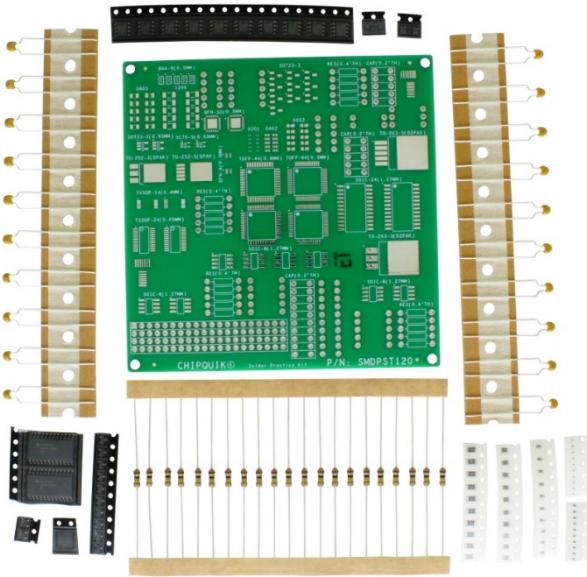

Top

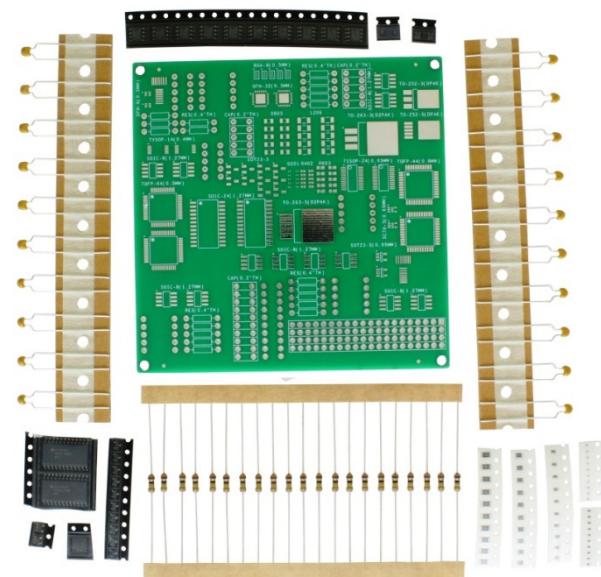

Bottom

### Product Highlights

This double-sided practice PCB includes a variety of SMD and TH configurations.

Populate the board with an assortment of 120 components (included).

All component footprints are clearly marked on board.

### Specifications

PCB construction: FR-4 UL94V-0

PCB operating temperature range: -40°C to +130°C (-40°F to +266°F)

PCB reflow maximum temperature: +260°C (500°F)

