 




Datasheet

LL01NI-BYKxxL19-T

Available Distribution




Dimensions


Part Number	LxW	Height
LL01NI-BYKxxL19-T	16x16	8

*All dimensions are in millimeters.

 LED



Packaging Details (SPQ)

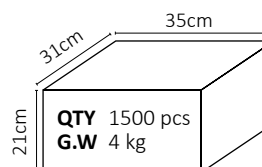

Recommend Applications



General Information



- Lens Material PC
- Lens Color Transparent
- Operating Temperature -40°C~+110°C
- Light Transmission Rate 400nm~900nm > 90%
- ☑ If necessary, Clean lenses with mild soap, water and soft cloth.
- ⚠ Never use any commercial cleaning solvents on lenses, like alcohol.
- ⚠ Please handle or install lenses with wearing gloves, skin oils may damage lens or its optical characteristic.

Accessories




- Available with Tape
LL01A00AYQXX

Mechanical Specification

*All dimensions are in millimeters.


Lens Dimension

LL01NI-BYK××L19

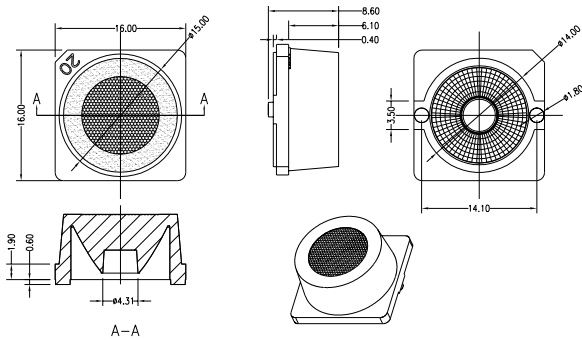

Tape Dimension

LL01A00AYQXX

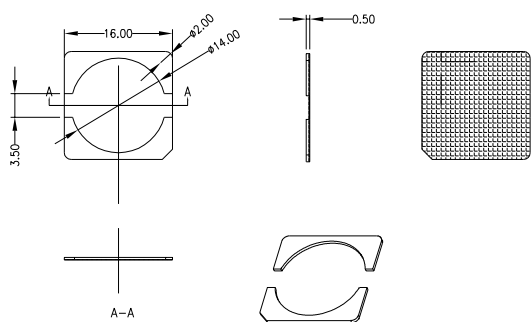


Assembly Instruction

Part No LL01NI-BYK××L19

Fixing Method



Luminaire Accessories

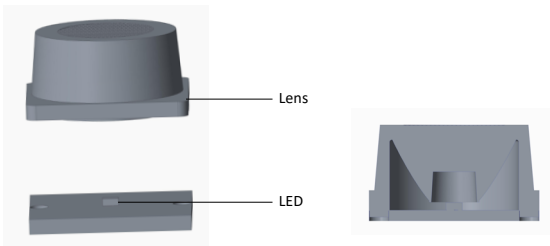

Assembly Instruction

Part No LL01NI-BYK××L19-T
Tape LL01A00AYQXX


Fixing Method




Tape




Luminaire Accessories

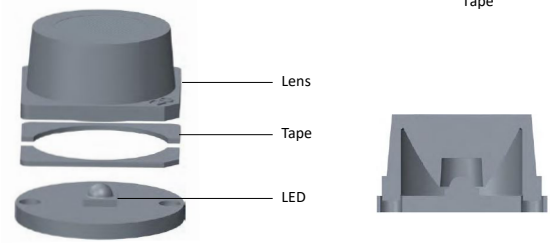

Photometric Distribution

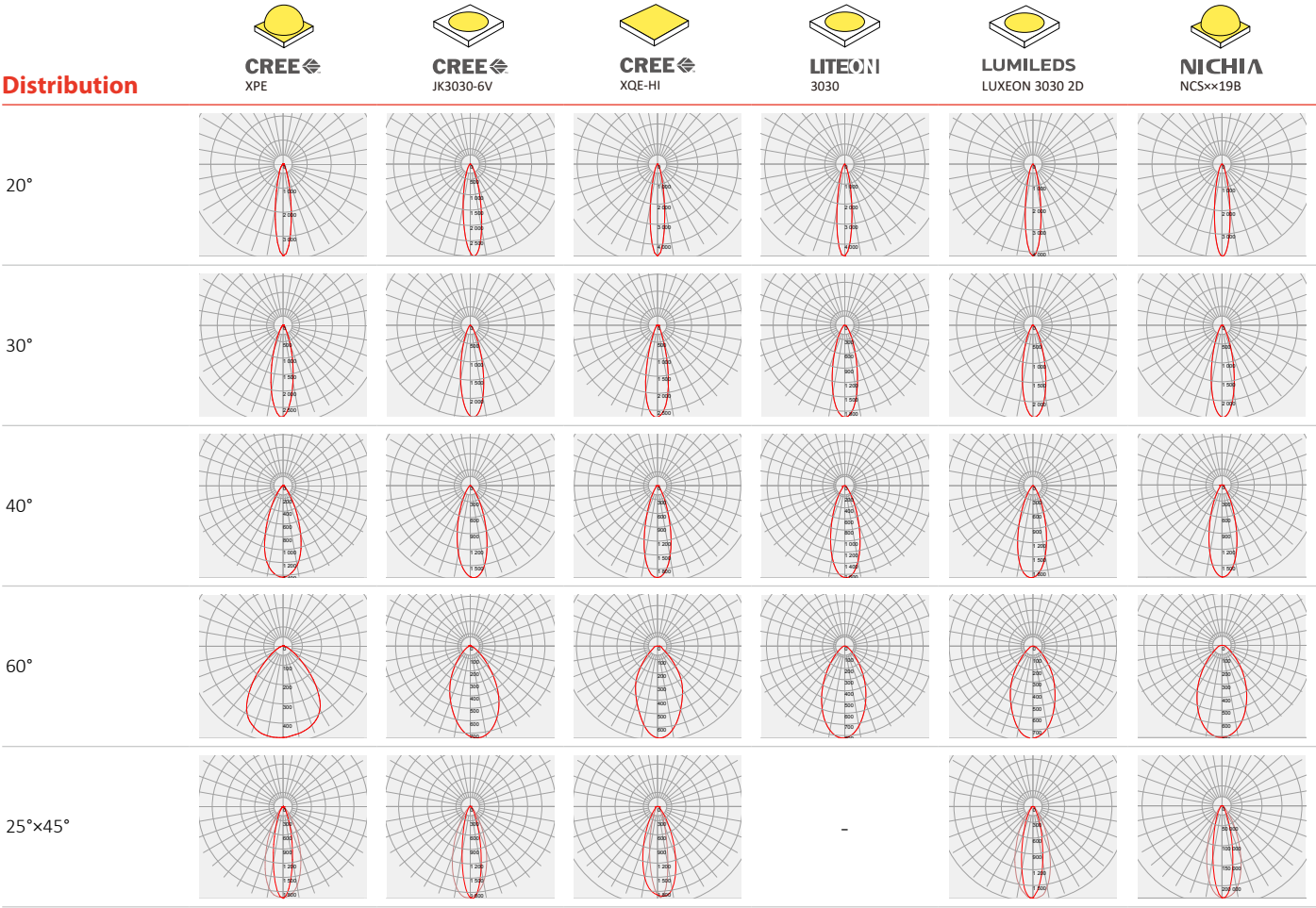

Photometric Distribution

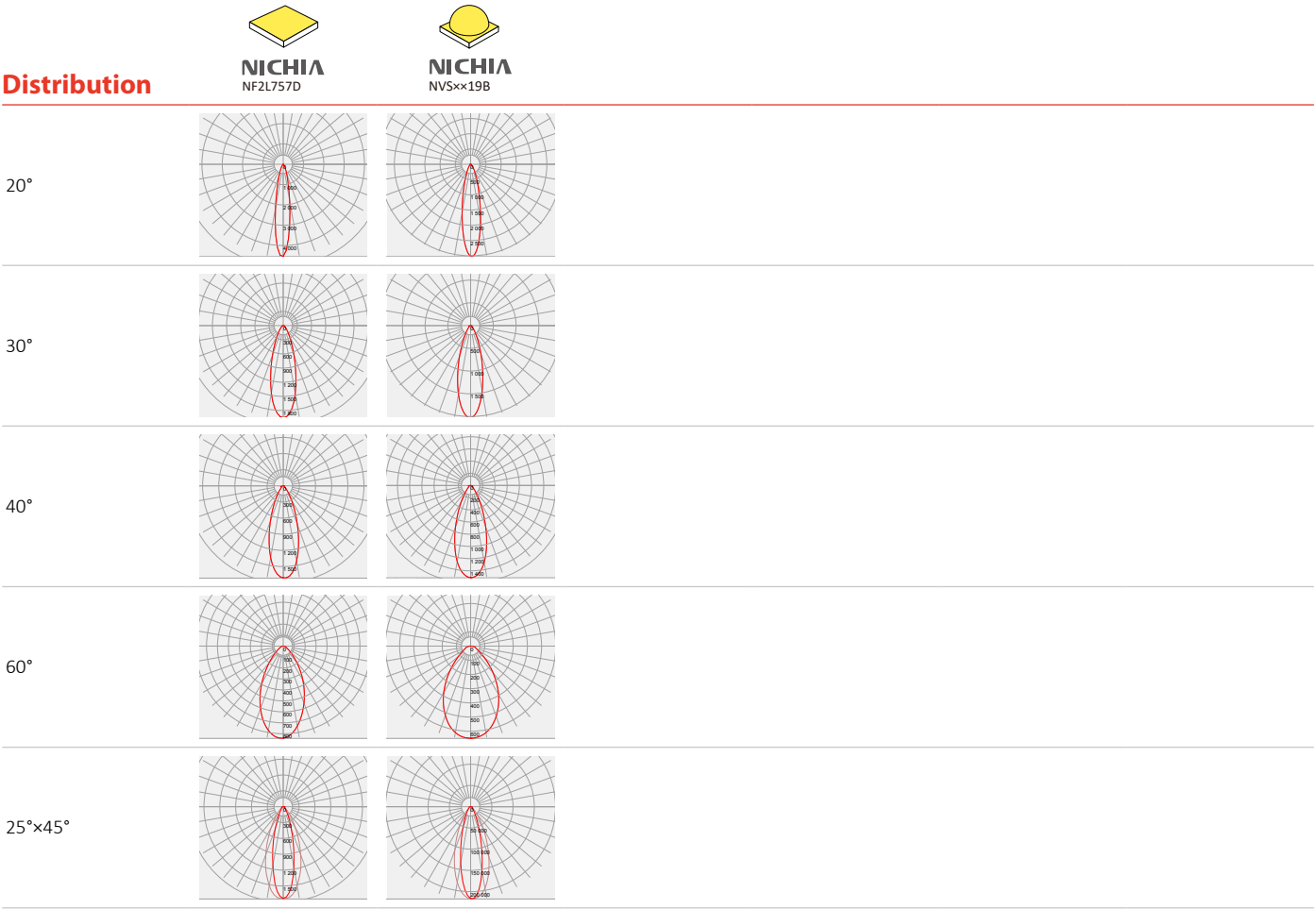

Details by LED

Part No	Tape	LED Package Size	LED
LL01NI-BYK××L19-T	 LL01A00AYQXX	1016 / 1616 / 3030 / 3535 LES Ø2.6	 CREE XPE  CREE JK3030-6V  CREE XQE-HI  LITEON 3030  LUMILEDS LUXEON 3030 2D  NICHIA NCS××19B  NICHIA NF2L757D  NICHIA NVS××19B

LED	Part No	FWHM	cd / lm	IES
 CREE XPE	LL01NI-BYK20L19-T	20°	3.8	
	LL01NI-BYK30L19-T	27°	2.7	
	LL01NI-BYK40L19-T	43°	1.4	
	LL01NI-BYK60L19-T	82°	0.4	
	LL01NI-BYK2545L19-T	24°×43°	1.9	
 CREE JK3030-6V	LL01NI-BYK20L19-T	22°	3.0	
	LL01NI-BYK30L19-T	28°	2.5	
	LL01NI-BYK40L19-T	36°	1.7	
	LL01NI-BYK60L19-T	60°	0.7	
	LL01NI-BYK2545L19-T	23°×42°	1.9	
 CREE XQE-HI	LL01NI-BYK20L19-T	18°	4.5	
	LL01NI-BYK30L19-T	27°	2.7	
	LL01NI-BYK40L19-T	32°	1.9	
	LL01NI-BYK60L19-T	60°	0.6	
	LL01NI-BYK2545L19-T	40°×22°	1.9	
 LITEON 3030	LL01NI-BYK20L19-T	18°	4.5	
	LL01NI-BYK30L19-T	31°	1.9	
	LL01NI-BYK40L19-T	36°	1.6	
	LL01NI-BYK60L19-T	55°	0.8	
	LL01NI-BYK2545L19-T	-	-	-
 LUMILEDS LUXEON 3030 2D	LL01NI-BYK20L19-T	19°	4.1	
	LL01NI-BYK30L19-T	29°	2.4	
	LL01NI-BYK40L19-T	35°	1.9	
	LL01NI-BYK60L19-T	56°	0.7	
	LL01NI-BYK2545L19-T	26°×43°	1.7	
 NICHIA NCS××19B	LL01NI-BYK20L19-T	19°	4.0	
	LL01NI-BYK30L19-T	28°	2.4	
	LL01NI-BYK40L19-T	34°	1.7	
	LL01NI-BYK60L19-T	62°	0.6	
	LL01NI-BYK2545L19-T	24°×41°	1.8	

LED	Part No	FWHM	cd / lm	IES
 NICHIA NF2L757D	LL01NI-BYK20L19-T	18°	4.5	
	LL01NI-BYK30L19-T	31°	1.9	
	LL01NI-BYK40L19-T	36°	1.7	
	LL01NI-BYK60L19-T	55°	0.8	
	LL01NI-BYK2545L19-T	26°×43°	1.7	
 NICHIA NVS××19B	LL01NI-BYK20L19-T	22°	3.0	
	LL01NI-BYK30L19-T	31°	1.9	
	LL01NI-BYK40L19-T	38°	1.4	
	LL01NI-BYK60L19-T	68°	0.6	
	LL01NI-BYK2545L19-T	26°×42°	1.6	

Product Nomenclature

Ledlink Led Type Lens Angle Tape
LL 01 NI -BYK 20 L19 -T
Lens Dot Number Serial Number Type of Material

Ledlink Optics, Inc

Taiwan HQ

15F, No.655,Bannan Rd., Chung-Ho Dist.,
New Taipei City, Taiwan 235

Ledlink Optics (Dongguan) Co., Ltd

Dongguan Factory

No.6, Gaoxin Road, Tiankeng, Hengli Town, Dongguan City,
Guangdong Province, China 523478

Ledlink Optics (Yangzhou) Co., Ltd

Yangzhou Factory

No.180, LinJiang Rd., YangZhou City, Jiangsu Province, China 225009

www.ledlink-optics.com

service@ledlink-optics.com

