 





Datasheet

LL01ZZ-CPRxxL46

Available Distribution



 LED




Dimensions

Part Number	Diameter	Height
LL01ZZ-CPRxxL46	Ø47	8.5

*All dimensions are in millimeters.


Packaging Details (SPQ)

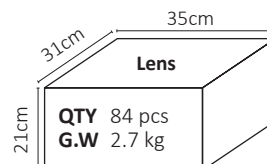

Recommend Applications



 General Information




- Lens Material PC
- Lens Color Transparent
- Operating Temperature -40°C~+110°C
- Light Transmission Rate 400nm~900nm > 90%
- ✓ If necessary, Clean lenses with mild soap, water and soft cloth.
- ⚠ Never use any commercial cleaning solvents on lenses, like alcohol.
- ⚠ Please handle or install lenses with wearing gloves, skin oils may damage lens or its optical characteristic.

Mechanical Specification

*All dimensions are in millimeters.

Lens Dimension



LL01ZZ-CPRxxL46

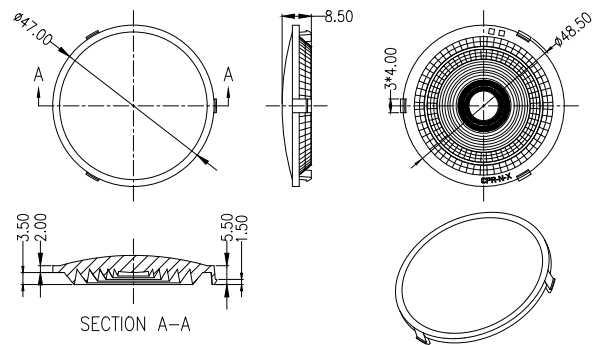

Assembly Instruction

Fixing Method



Part No LED
LL01ZZ-CPRxxL46
Bridgelux Vesta TW Gen2 DP 9mm
CREE CXA1304 / CXA1820

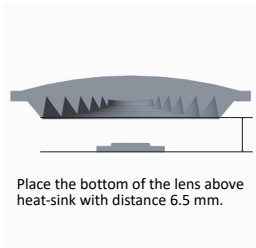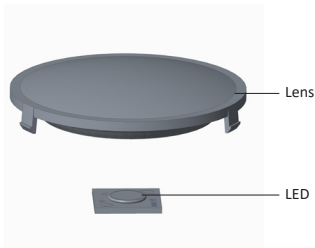

Assembly Instruction

Fixing Method



Part No LED
LL01ZZ-CPRxxL46
CREE MHB-A

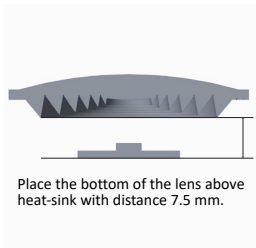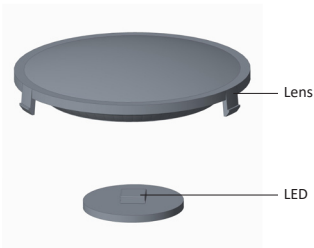

Assembly Instruction

Fixing Method



Part No LED
LL01ZZ-CPRxxL46
CITIZEN CLL020

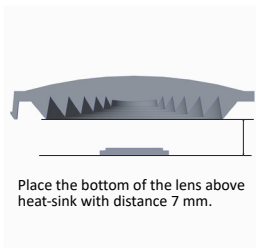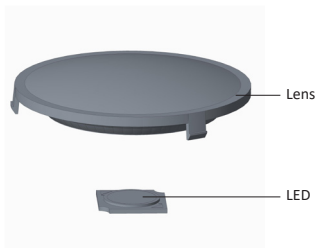


Assembly Instruction

Fixing Method

Part No LED
LL01ZZ-CPRxxL46
XICATO XTM-9mm / XTM-19mm

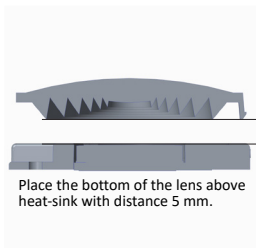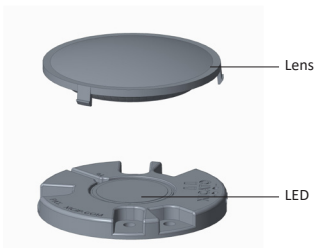

Photometric Distribution

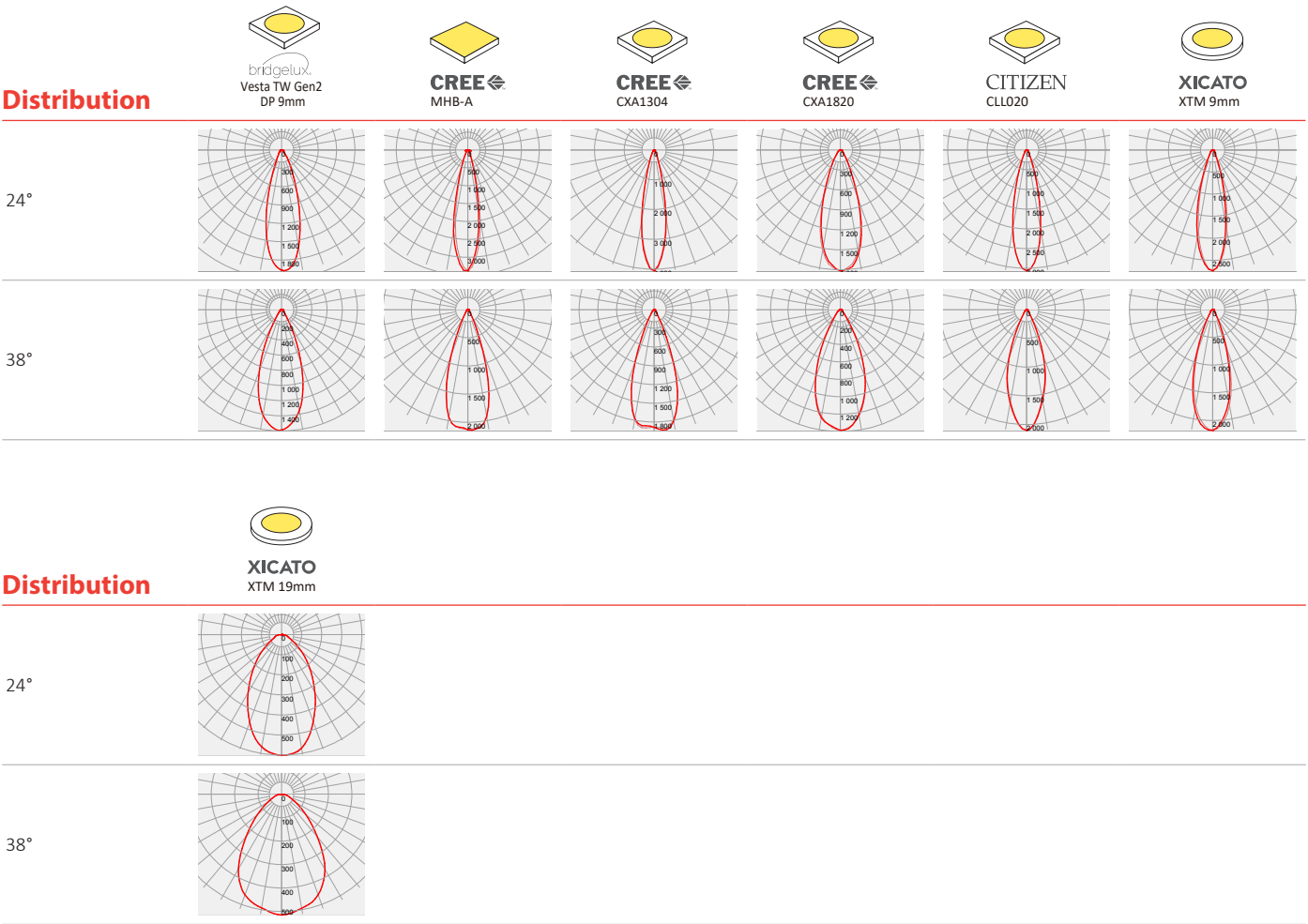

Details by LED

Part No	Connector	LED Package Size	LED
LL01ZZ-CPRxxL46	-	5050 LES Ø6~19	 bridgelux. Vesta TW Gen2 DP 9mm  CREE MHB-A  CREE CXA1304  CREE CXA1820  CITIZEN CLL020  XICATO XTM 9mm  XICATO XTM 19mm

LED	Part No	FWHM	cd / lm	IES
 bridgelux. Vesta TW Gen2 DP 9mm	LL01ZZ-CPR24L46	31°	1.9	
	LL01ZZ-CPR38L46	40°	1.5	
 CREE MHB-A	LL01ZZ-CPR24L46	22°	3.3	
	LL01ZZ-CPR38L46	36°	2.1	
 CREE CXA1304	LL01ZZ-CPR24L46	22°	4.0	
	LL01ZZ-CPR38L46	38°	1.9	
 CREE CXA1820	LL01ZZ-CPR24L46	36°	1.8	
	LL01ZZ-CPR38L46	45°	1.3	
 CITIZEN CLL020	LL01ZZ-CPR24L46	25°	3.0	
	LL01ZZ-CPR38L46	35°	2.0	
 XICATO XTM 9mm	LL01ZZ-CPR24L46	27°	2.7	
	LL01ZZ-CPR38L46	33°	2.1	
 XICATO XTM 19mm	LL01ZZ-CPR24L46	65°	0.6	
	LL01ZZ-CPR38L46	76°	0.5	

Product Nomenclature

Ledlink Led Type Lens Angle
LL 01 ZZ- CPR 24 L46
Lens Dot Number Serial Number Type of Material

Ledlink Optics, Inc

Taiwan HQ

15F, No.655, Bannan Rd., Chung-Ho Dist.,
New Taipei City, Taiwan 235

Ledlink Optics (Dongguan) Co., Ltd

Dongguan Factory

No.6, Gaoxin Road, Tiankeng, Hengli Town, Dongguan City,
Guangdong Province, China 523478

Ledlink Optics (Yangzhou) Co., Ltd

Yangzhou Factory

No.180, LinJiang Rd., YangZhou City, Jiangsu Province, China 225009

www.ledlink-optics.com

service@ledlink-optics.com

