 


Datasheet

LL01ZZ-DZLxxL06-M2

Available Distribution



LED



Recommand Applications



General Information




- Lens Material PMMA 8N
- Operating Temperature -40°C~+70°C
- UL Flammability HB @1.5mm
- UL RTI Elec 90°C @1.5mm
- Light Transmission Rate 400nm~900nm > 90%
- ✓ If necessary, Clean lenses with mild soap, water and soft cloth.
- ⚠ Never use any commercial cleaning solvents on lenses, like alcohol.
- ⚠ Please handle or install lenses with wearing gloves, skin oils may damage lens or its optical characteristic.

Dimensions

Part Number	Diameter	Height
LL01ZZ-DZLxxL06-M2	Ø 62	27.5

*All dimensions are in millimeters.

Packaging Details (SPQ)

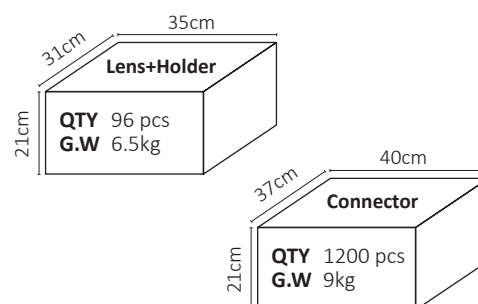

Accessories




- Available with Holder
LL01ZZABF120H2
- Available with Connector
LL01A00CXDB2 (CREE CXA1520)
LL01A00CXC2 (CREE CXA1830)
LL01A00CXEB2 (CITIZEN CLU028)

Mechanical Specification


*All dimensions are in millimeters.

Lens Dimension

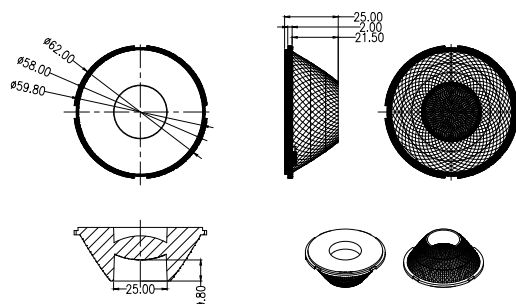


Holder Dimension

LL01ZZABF120H2

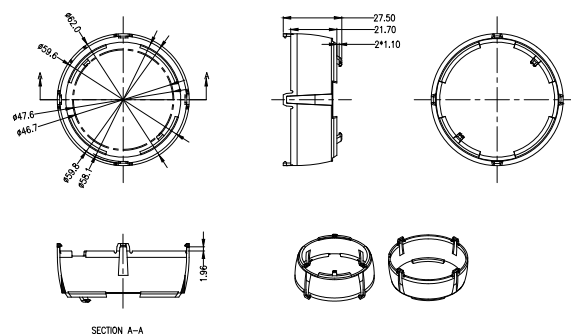

Connector Dimension

LL01A00CXDB2

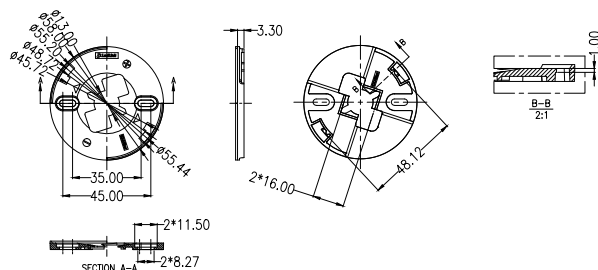


Assembly Instruction

Fixing Method

Part No LL01ZZ-DZLxL06
Holder LL01ZZABF120H2
Connector LL01A00CXDB2
LED CREE CXA1520




Luminarie Accessories

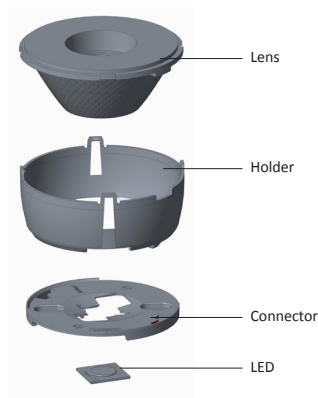

Connector Dimension

LL01A00CXC2

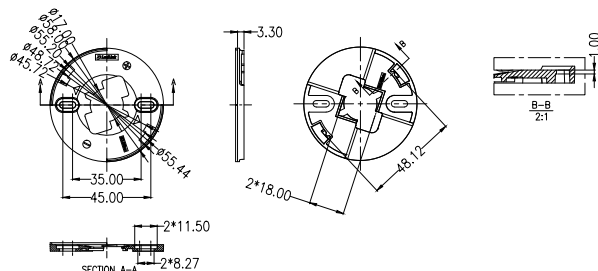



Assembly Instruction

Fixing Method

Part No LL01ZZ-DZLxL06
Holder LL01ZZABF120H2
Connector LL01A00CXC2
LED CREE CXA1830




 Luminarie Accessories

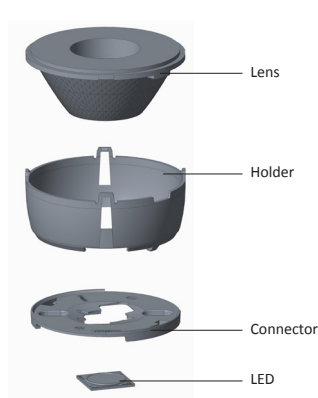

Connector Dimension



LL01A00CXEB2

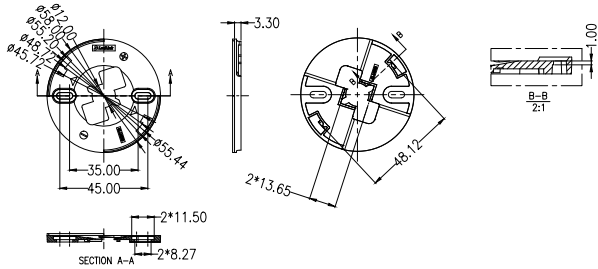


Assembly Instruction

Part No LL01ZZ-DZL××L06
Holder LL01ZZABF120H2
Connector LL01A00CXEB2
LED CITIZEN CLU028

 Fixing Method

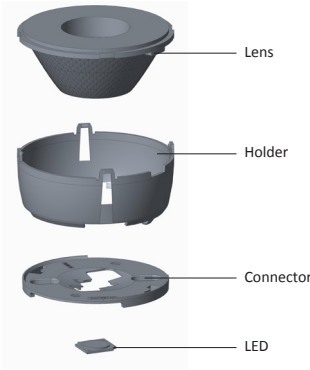

Photometric Distribution

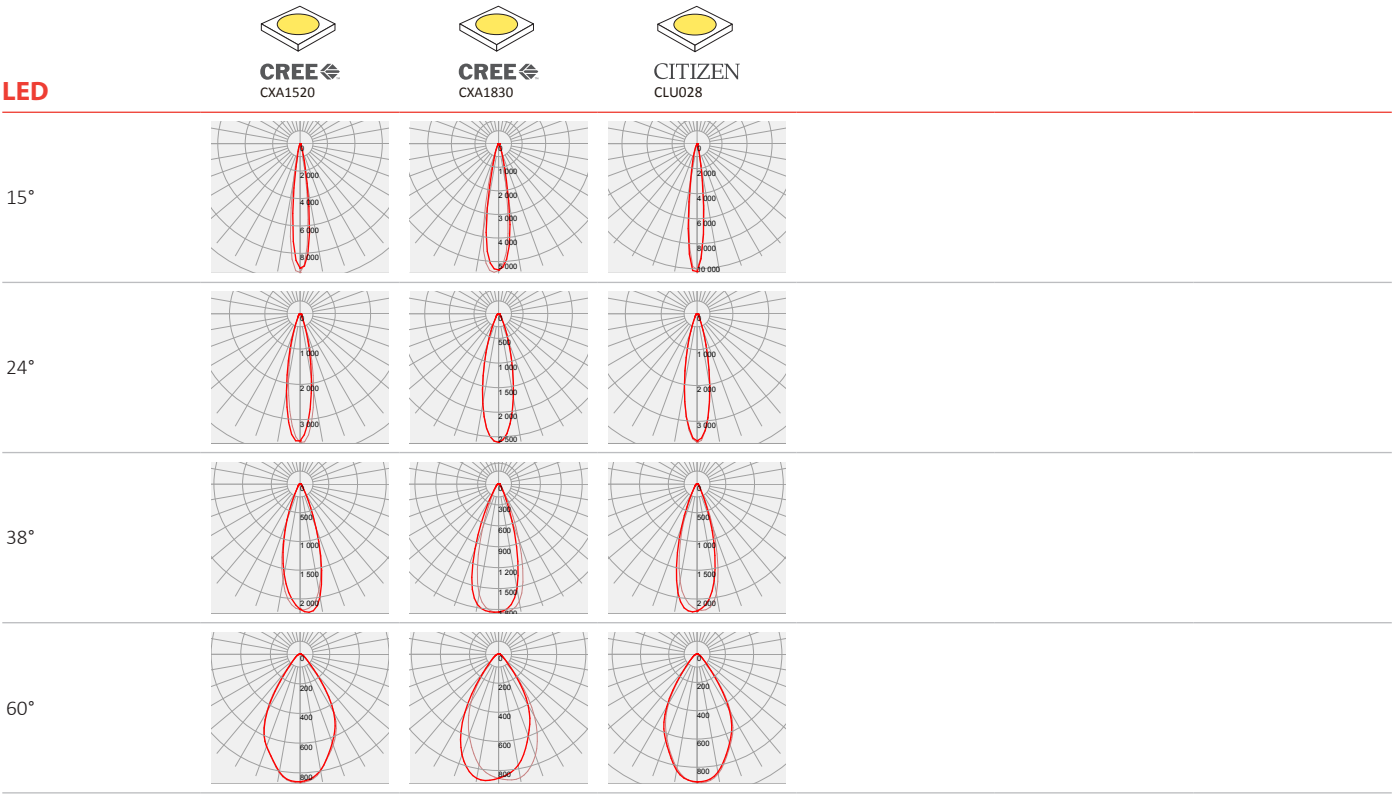

Details by LED

Part No	Holder	Connector	LED Size	LED
LL01ZZ-DZLxxL06-M2	 LL01ZZABF120H2	 LL01A00CXDB2	Ø8.9	 CREE CXA1520
		 LL01A00CXC2	Ø16	 CREE CXA1830
		 LL01A00CXEB2	Ø9.8	 CITIZEN CLU028

LED	Part No	FWHM	cd / lm	IES
 CREE CXA1520	LL01ZZ-DZL15L06-M2	14°	9.3	
	LL01ZZ-DZL24L06-M2	22°	3.6	
	LL01ZZ-DZL38L06-M2	32°	2.2	
	LL01ZZ-DZL60L06-M2	61°	0.8	
 CREE CXA1830	LL01ZZ-DZL15L06-M2	19°	5.4	
	LL01ZZ-DZL24L06-M2	27°	2.6	
	LL01ZZ-DZL38L06-M2	36°	1.8	
	LL01ZZ-DZL60L06-M2	59°	0.8	
 CITIZEN CLU028	LL01ZZ-DZL15L06-M2	13°	10.2	
	LL01ZZ-DZL24L06-M2	22°	3.5	
	LL01ZZ-DZL38L06-M2	32°	2.2	
	LL01ZZ-DZL60L06-M2	59°	0.9	

Product Nomenclature

Ledlink Led Type Lens Angle Holder
LL 01 ZZ- DZL 15 L06- M2
Lens Dot Number Serial Number Type of Material

Ledlink Optics, Inc

Taiwan HQ

15F, No.655, Bannan Rd., Chung-Ho Dist.,
New Taipei City, Taiwan 235

Ledlink Optics (Dongguan) Co., Ltd

Dongguan Factory

No.5, TianKeng Industrial Dist., HengLi Town, DongGuan City,
GuangDong Province, China 523478

Ledlink Optics (Yangzhou) Co., Ltd

Yangzhou Factory

No.180, LinJiang Rd., YangZhou City, Jiangsu Province, China 225009

www.ledlink-optics.com

service@ledlink-optics.com

