


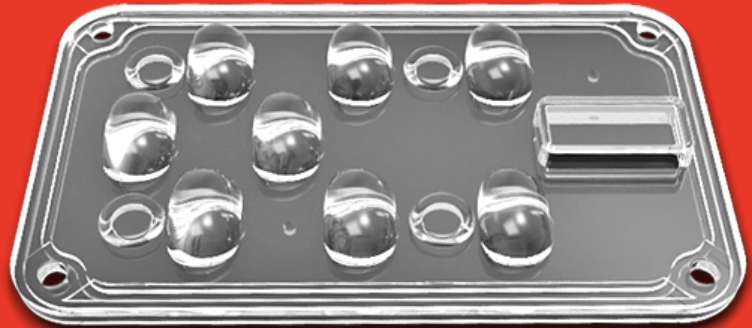

Datasheet

LL08BR-DCB35140L52

Available Distribution



35°×140°

Dimensions

Part Number	L×W	Height
LL08BR-DCB35140L52	118.26×70.26	9.69


*All dimensions are in millimeters.

LED



bridgelux
5050

Packaging Details (SPQ)

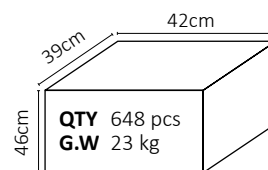


Recommend Applications



Street

 General Information



- Lens Material PC
- Lens Color Transparent
- Operating Temperature -40°C~+110°C
- Light Transmission Rate 400nm~900nm > 90%
- ☑ If necessary, Clean lenses with mild soap, water and soft cloth.
- ⚠ Never use any commercial cleaning solvents on lenses, like alcohol.
- ⚠ Please handle or install lenses with wearing gloves, skin oils may damage lens or its optical characteristic.

Accessories




- Available with Waterproof Gasket LL01A00SWX2

Mechanical Specification

*All dimensions are in millimeters.


Lens Dimension

LL08BR-DCB35140L52

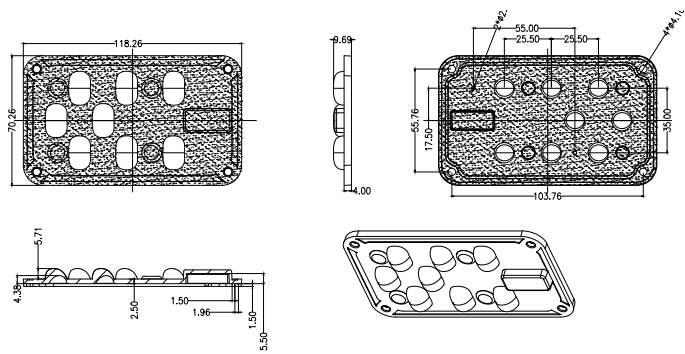


Waterproof Gasket Dimension

LL01A00SWX2

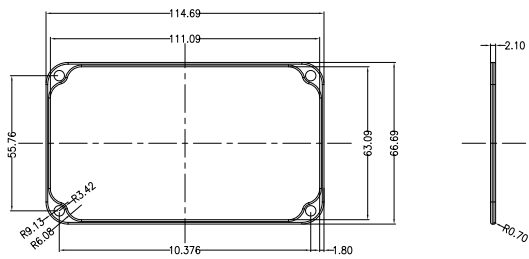

Assembly Instruction

Fixing Method

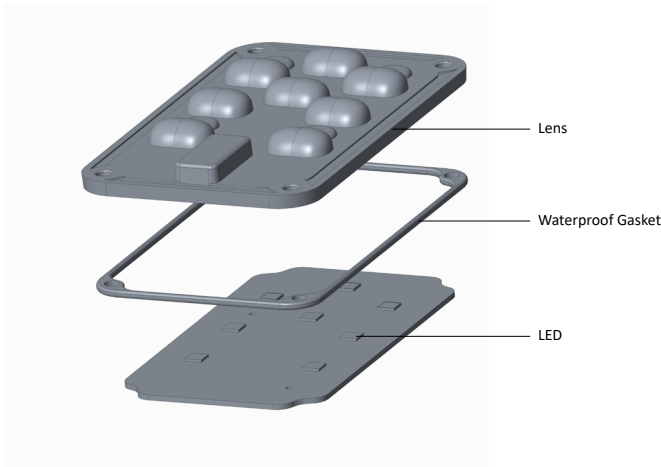


Screw

Photometric Distribution


LED



35°x140°

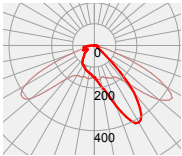

Details by LED

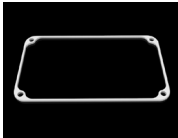Part No	Waterproof Gasket	LED Package Size	LED
LL08BR-DCB35140L52	 LL01A00SWX2	5050	 bridgelux. 5050

LED	Part No	Type	FWHM	cd / lm	IES
 bridgelux. 5050	LL08BR-DCB35140L52	I-Short	30°×133°	1.0	

Product Nomenclature

Ledlink Led Type Lens Angle
LL 08 BR- DCB 35140 L52
Lens Dot Number Serial Number Type of Material

Ledlink Optics, Inc

Taiwan HQ

15F, No.655,Bannan Rd., Chung-Ho Dist.,
New Taipei City, Taiwan 235

Ledlink Optics (Dongguan) Co., Ltd

Dongguan Factory

No.6, Gaoxin Road, Tiankeng, Hengli Town, Dongguan City,
Guangdong Province, China 523478

Ledlink Optics (Yangzhou) Co., Ltd

Yangzhou Factory

No.180, LinJiang Rd., YangZhou City, Jiangsu Province, China 225009

www.ledlink-optics.com

service@ledlink-optics.com

