

©

A



B

C


D

E

Ruhestellung
free position
Schaltpunkt
operating position
zul. Endstellung
total travel
position allowed

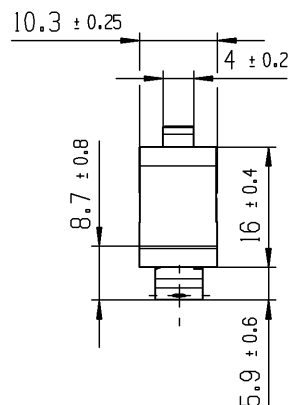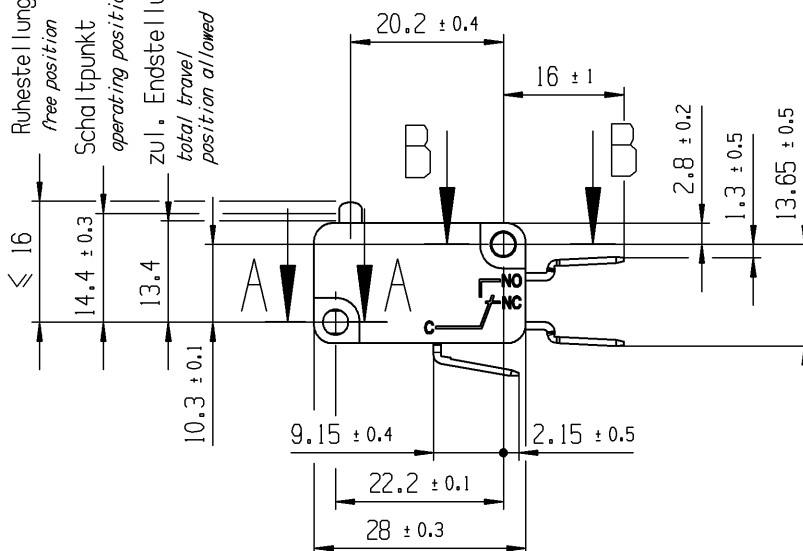

Flachstecker 6.3 x 0.8
EN 61058 / EN 61210 / DIN 46244
blade terminal 6.3 x 0.8
EN 61058 / 61210 / DIN 46244

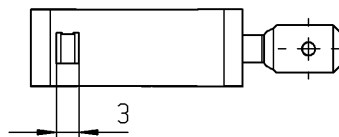


Aufschrift
marking

1005


T100
8181A 250V AC 5E4



Herstellort /- jahr / -woche
date code of manufacture:
place / year / week


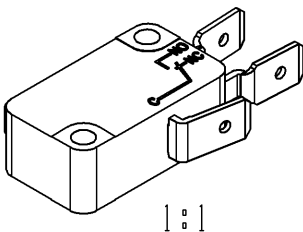


3.35 ± 0.05 x 3.08 ± 0.06

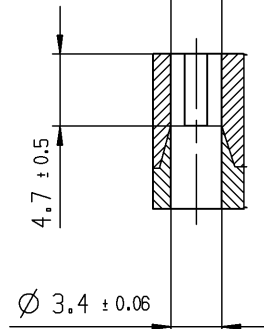

A-A
2:1


B-B
2:1

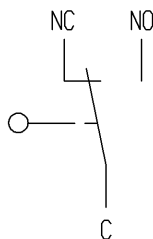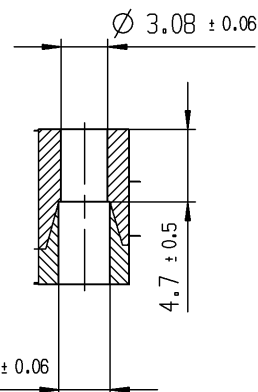

Wechsler 1-polig
single pole changeover

Schalt-Betaetigungskraft 2.4 bis 3.8 N
actuating force 2.4 up to 3.8 N

 Differenzweg ≤ 1.2 mm
movement differential

-		-					-		1005.1010-XX			
Figure		Type					Customer No.		Art.No.-PI			
General tolerances							Sheet 01			Ident. K	Document number 10051010	Index h
All dimensions are in millimetres		Shape and location ⊙ ≡	Angle ± 2 °	Edge tolerance 		Length						
					0-6	± 0.1	± 0.2					
					>6-15	± 0.15	± 0.3					
					>15-30	± 0.2	± 0.5					
					>30-70	± 0.3	± 10%					
					>70-120	± 0.4						
					>120	± 0.8						
				Format DIN	Projection 	Scale 1:1	Snap action switch					
				A4								
				System NX V11.0			 MARQUARDT					
				Replacement of Zg.gl.Nr.v.10.10.1995								
h	131138	2020-04-01		GAIEDB								
g	128895	2019-10-23		HHE								
f	109072	2017-08-16		TRIGUIK								
e	92840	2015-07-07		JENDOUBIR								
Index	MEC-No.	Date (YYYY-MM-DD)		Edited by								