

©

A

B

C

D

 
E

Ruhestellung
free position
Schaltpunkt
operating position
zul. Endstellung
total travel
position allowed

Aufschrift
marking




1005µ
10(4)A 400V AC 1E4 T100
6(2.5)A 400V AC 5E4



Herstellort /- jahr / -woche
Code of manufacture:
place / year / week





A-A
2:1

3.35 ± 0.05 x 3.08 ± 0.06

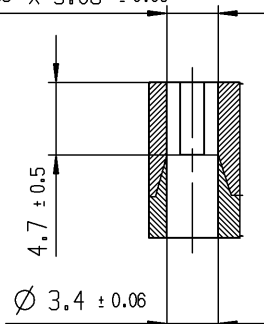


B-B
2:1

NC NO
C

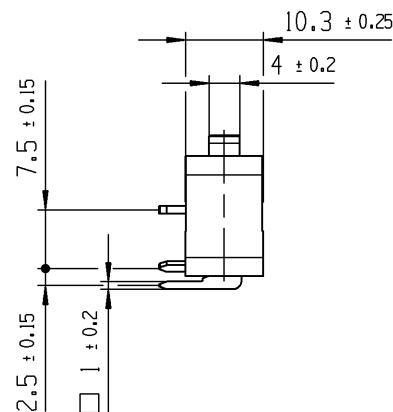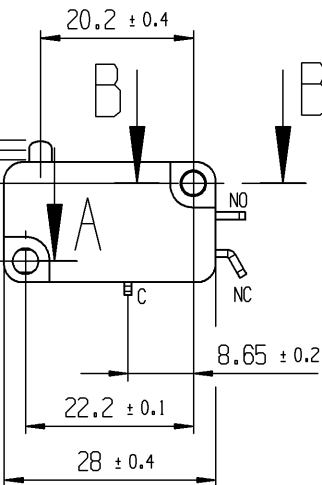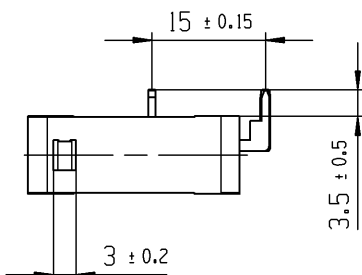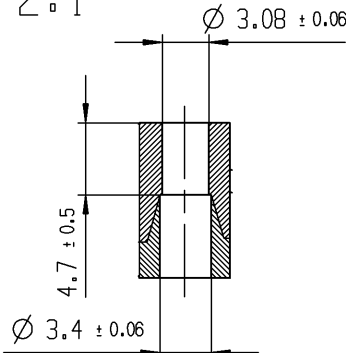

Empfohlenes Lochbild, Bestueckungsseite
Toleranzen nach DIN IEC 326
Teil 3 sehr fein
In den Durchgangsloechern fixieren
recommended hole pattern, component side
tolerances according to DIN IEC 326
part 3 very fine
fixation in the clearance hole

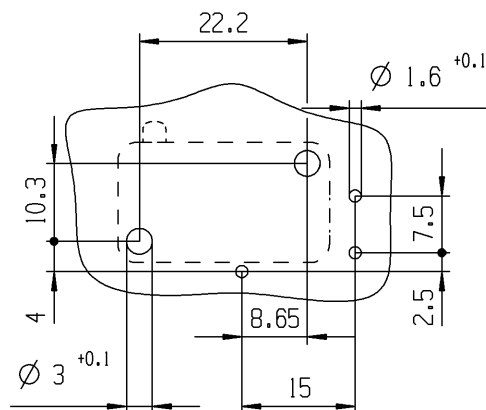

Wechsler 1-polig
single pole changeover

Schalt-Betaetigungskraft 1.5 bis 2.5 N
actuating force 1.5 up to 2.5 N
Differenzweg ≤ 0.3 mm
movement differential

-	-	-	1005.3501-XX
Figure	Type	Customer Part No.	Art.No.-PI
Shape and location © ≡	Angle ± 2 ° Edge tolerance	Sheet 01	
		Ident. K	Document number 10053501
		Index f	
		Snap action switch	
f	137878	2022-01-20	KELBOUSSIM
e	128297	2020-01-17	HHE
d	85443	2013-10-07	BRC
c	28404	2000-01-19	PFU
Index	MEC-No.	Date (YYYY-MM-DD)	Edited by
All dimensions are in millimetres		System NX V1872	Replacement of
		Zg.gl.Nr.v.19.01.2000	

MARQUARDT