
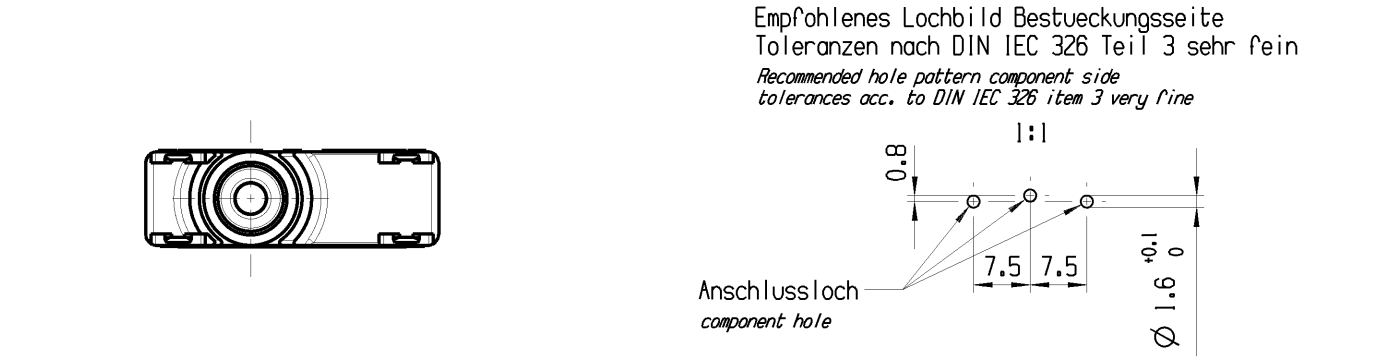


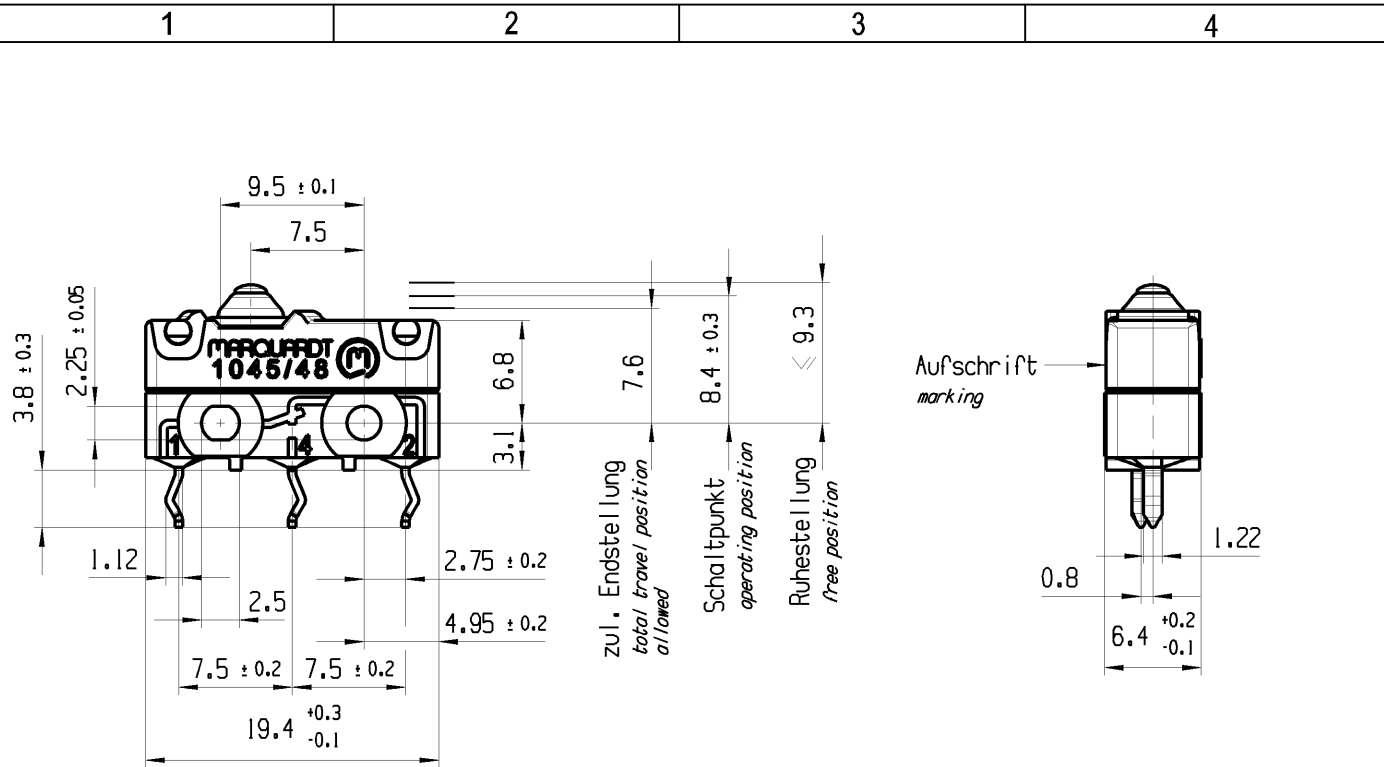

Aufschrift
Marking

NC 2 NO 4

1045 2251 1/250 40T100 100E3 PYMMDD

1 C

Wechsler 1-polig
Kontakte vergoldet
single pole changeover
contacts gold plated

Schaltbetaetigungskraft
actuating force $\leq 1.9 \text{ N}$

Rueckschaltkraft
release force $\geq 0.5 \text{ N}$

Differenzweg
movement differential $\leq 0.1 \text{ mm}$

G: Konform nach IEC 60335-1:2001 Kap. 30
G: matching IEC 60335-1:2001 clause 30

IP Schutzklasse nach EN 60529
protection class acc to EN 60529 IP 67

IP 67

1:1

-		XXX						1045.2251-XX				
Figure		Type						Art.No.-PI				
General tolerances							Sheet 01			Ident. K	Document number 10452251	Index d
All dimensions are in millimetres		Shape and location  0.1	Angle ± 2 °	Edge tolerance  +0.25 +0.1 0 -0.25		Length						
					0-6	± 0.1	± 0.2					
					>6-15	± 0.15	± 0.3					
					>15-30	± 0.2	± 0.5					
					>30-70	± 0.3						
					>70-120	± 0.4	± 10%					
					>120	± 0.8						
d	126682	2019-08-30			LEK			Format DIN A4	Projection 	Scale 2:1	Snap action switch	
c	83090	2013-03-11			BRC							
b	78489	2012-04-26			BRC							
a	77237	2012-02-13			BRC			System NX V6.0			Replacement of	
Index	MEC-No.	Date (YYYY-MM-DD)			Edited by							
MARQUARDT												