




NEW PRODUCT INTRODUCTION

PEEK FASTENERS

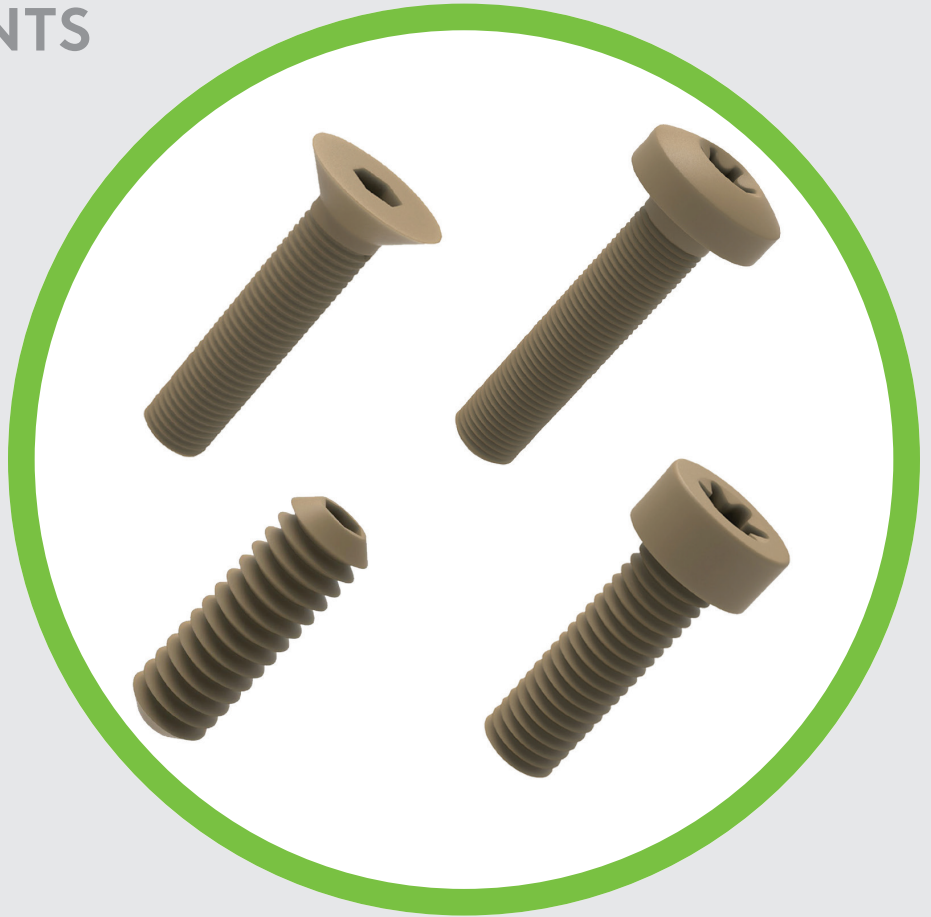

PEEK fasteners are ideal for applications that require higher performance plastics, thermal and electrical resistance, and low outgassing for harsh environments, reducing the risk of containment and thermal instability. Essentra's PEEK range offers lightweight and versatile alternatives that securely bridge the gap between nylon fasteners and traditional metal fasteners.

APPLICATIONS & INDUSTRIES

- Fuel Systems
- Aerospace
- Medical Industries
- Electronics
- Ultra-High Vacuums
- Automotive Manufacturing
- Oil & Gas Refining
- Energy Services Equipment

WRPH Series PEEK Pan Head Screws - Torx Drive





Specifications:

- Material: PEEK
- Color: Beige

Features:

- High-strength, chemically resistant PEEK
- Pan head with Torx drive for even load and high torque
- Reliable performance up to 260°C / 500°F

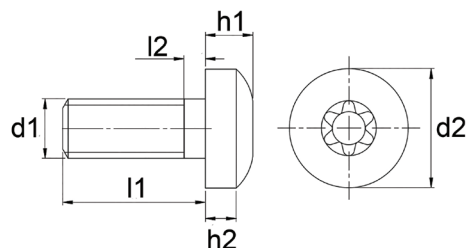

Item No.	d1	d2	l1	l2	h1	h2	Torx Size
20820190	M2.5	5.0	6.0	0.9	2.0	1.3	TX-8
20820206	M2.5	5.0	8.0	0.9	2.0	1.3	TX-8
20820213	M2.5	5.0	10.0	0.9	2.0	1.3	TX-8
20820220	M2.5	5.0	12.0	0.9	2.0	1.3	TX-8
20820268	M3	6.0	6.0	1.0	2.4	1.6	TX-10
20820275	M3	6.0	8.0	1.0	2.4	1.6	TX-10
20820282	M3	6.0	10.0	1.0	2.4	1.6	TX-10
20820299	M3	6.0	12.0	1.0	2.4	1.6	TX-10
20820305	M3	6.0	15.0	1.0	2.4	1.6	TX-10
20820329	M3	6.0	25.0	1.0	2.4	1.6	TX-10
20820343	M4	8.0	6.0	1.4	3.1	2.0	TX-20
20820350	M4	8.0	8.0	1.4	3.1	2.0	TX-20
20820367	M4	8.0	10.0	1.4	3.1	2.0	TX-20
20820374	M4	8.0	12.0	1.4	3.1	2.0	TX-20
20820381	M4	8.0	15.0	1.4	3.1	2.0	TX-20
20820398	M4	8.0	20.0	1.4	3.1	2.0	TX-20
20820404	M4	8.0	25.0	1.4	3.1	2.0	TX-20
20820428	M5	10.0	8.0	1.6	3.8	2.5	TX-25
20820435	M5	10.0	10.0	1.6	3.8	2.5	TX-25
20820442	M5	10.0	12.0	1.6	3.8	2.5	TX-25
20820459	M5	10.0	15.0	1.6	3.8	2.5	TX-25
20820466	M5	10.0	20.0	1.6	3.8	2.5	TX-25
20820473	M5	10.0	25.0	1.6	3.8	2.5	TX-25
20820503	M6	12.0	10.0	2.0	4.6	3.0	TX-30
20820510	M6	12.0	12.0	2.0	4.6	3.0	TX-30
20820527	M6	12.0	15.0	2.0	4.6	3.0	TX-30
20820534	M6	12.0	20.0	2.0	4.6	3.0	TX-30
20820541	M6	12.0	25.0	2.0	4.6	3.0	TX-30
20820558	M6	12.0	30.0	2.0	4.6	3.0	TX-30



PEEK fasteners are ideal for applications that require higher performance plastics, thermal and electrical resistance, and low outgassing for harsh environments, reducing the risk of containment and thermal instability. Essentra's PEEK range offers lightweight and versatile alternatives that securely bridge the gap between nylon fasteners and traditional metal fasteners.

APPLICATIONS & INDUSTRIES

- Fuel Systems
- Aerospace
- Medical Industries
- Electronics
- Ultra-High Vacuums
- Automotive Manufacturing
- Oil & Gas Refining
- Energy Services Equipment

WRLP Series PEEK Low Profile Screws - Torx and Socket Drive

NEW

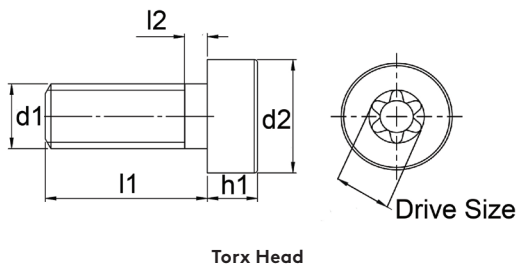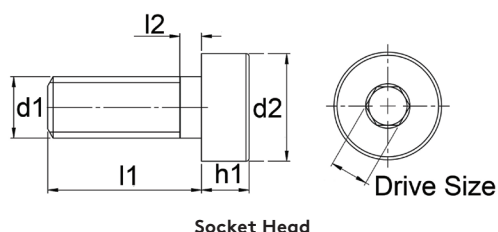

Specifications:

- Material: PEEK
- Color: Beige

Features:

- High-strength, chemically resistant PEEK
- Pan head with Torx drive for even load and high torque
- Reliable performance up to 260°C / 500°F
- Socket head available for broad compatibility

Item No.	d1	l1	d2	l2	h1	Drive Size	Head Type
20834739	M3	12.0	5.5	1.0	2.4	2.0	Socket
20834777	M4	8.0	7.0	1.4	3.1	2.5	Socket
20834784	M4	10.0	7.0	1.4	3.1	2.5	Socket
20834807	M4	16.0	7.0	1.4	3.1	2.5	Socket
20834814	M4	20.0	7.0	1.4	3.1	2.5	Socket
20834821	M4	25.0	7.0	1.4	3.1	2.5	Socket
20834876	M5	20.0	8.5	1.6	3.65	3.0	Socket
20834913	M6	12.0	10.0	2.0	4.4	4.0	Socket
20834920	M6	16.0	10.0	2.0	4.4	4.0	Socket
20834432	M3	6.0	5.5	1.0	2.4	TX-10	Torx
20834449	M3	8.0	5.5	1.0	2.4	TX-10	Torx
20834456	M3	10.0	5.5	1.0	2.4	TX-10	Torx
20834463	M3	12.0	5.5	1.0	2.4	TX-10	Torx
20834470	M3	16.0	5.5	1.0	2.4	TX-10	Torx
20834487	M3	20.0	5.5	1.0	2.4	TX-10	Torx
20834500	M4	8.0	7.0	1.4	3.1	TX-20	Torx
20834517	M4	10.0	7.0	1.4	3.1	TX-20	Torx
20834524	M4	12.0	7.0	1.4	3.1	TX-20	Torx
20834531	M4	16.0	7.0	1.4	3.1	TX-20	Torx
20834548	M4	20.0	7.0	1.4	3.1	TX-20	Torx
20834555	M4	25.0	7.0	1.4	3.1	TX-20	Torx
20834579	M5	10.0	8.5	1.6	3.65	TX-25	Torx
20834586	M5	12.0	8.5	1.6	3.65	TX-25	Torx
20834593	M5	16.0	8.5	1.6	3.65	TX-25	Torx
20834609	M5	20.0	8.5	1.6	3.65	TX-25	Torx
20834623	M5	30.0	8.5	1.6	3.65	TX-25	Torx
20834647	M6	12.0	10.0	2.0	4.4	TX-30	Torx
20834654	M6	16.0	10.0	2.0	4.4	TX-30	Torx
20834661	M6	20.0	10.0	2.0	4.4	TX-30	Torx
20834678	M6	25.0	10.0	2.0	4.4	TX-30	Torx
20834685	M6	30.0	10.0	2.0	4.4	TX-30	Torx
20834692	M6	40.0	10.0	2.0	4.4	TX-30	Torx


PEEK fasteners are ideal for applications that require higher performance plastics, thermal and electrical resistance, and low outgassing for harsh environments, reducing the risk of containment and thermal instability. Essentra's PEEK range offers lightweight and versatile alternatives that securely bridge the gap between nylon fasteners and traditional metal fasteners.

APPLICATIONS & INDUSTRIES

- Fuel Systems
- Aerospace
- Medical Industries
- Electronics
- Ultra-High Vacuums
- Automotive Manufacturing
- Oil & Gas Refining
- Energy Services Equipment

WRCS Series

90° PEEK Countersunk Screws - Torx and Socket Drive

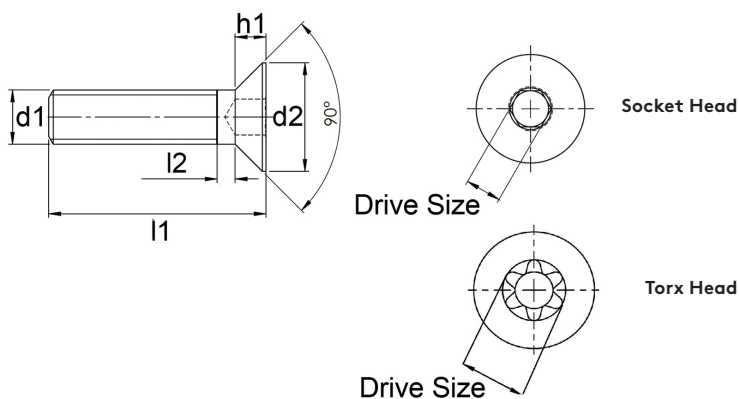Specifications:

- Material: PEEK
- Color: Beige

Features:

- High-strength, chemically resistant PEEK
- Reliable performance up to 260°C / 500°F
- Pan head with Torx drive for even load and high torque
- Socket head available for broad compatibility

Item No.	d1	l1	d2	l2	h1	Drive Size	Head Type
20833817	M3	8.0	6.0	1.0	1.7	2.0	Socket
20833824	M3	10.0	6.0	1.0	1.7	2.0	Socket
20833831	M3	12.0	6.0	1.0	1.7	2.0	Socket
20833848	M3	16.0	6.0	1.0	1.7	2.0	Socket
20833855	M3	20.0	6.0	1.0	1.7	2.0	Socket
20833862	M4	8.0	8.0	1.4	2.3	2.5	Socket
20833879	M4	10.0	8.0	1.4	2.3	2.5	Socket
20833886	M4	12.0	8.0	1.4	2.3	2.5	Socket
20833893	M4	16.0	8.0	1.4	2.3	2.5	Socket
20833909	M4	20.0	8.0	1.4	2.3	2.5	Socket
20833916	M4	25.0	8.0	1.4	2.3	2.5	Socket
20833923	M5	8.0	10.0	1.6	2.8	3.0	Socket
20833930	M5	10.0	10.0	1.6	2.8	3.0	Socket
20833947	M5	12.0	10.0	1.6	2.8	3.0	Socket
20833954	M5	16.0	10.0	1.6	2.8	3.0	Socket
20833961	M5	20.0	10.0	1.6	2.8	3.0	Socket
20833978	M5	25.0	10.0	1.6	2.8	3.0	Socket
20703103	M6	30.0	12.0	2.0	3.3	4.0	Socket
20703172	M6	10.0	12.0	2.0	3.3	4.0	Socket
20834012	M6	16.0	12.0	2.0	3.3	4.0	Socket
20834029	M6	20.0	12.0	2.0	3.3	4.0	Socket
20819767	M3	6.0	6.0	1.0	1.7	TX-10	Torx
20819828	M3	25.0	6.0	1.0	1.7	TX-10	Torx
20819842	M4	6.0	8.0	1.4	2.2	TX-20	Torx

PEEK fasteners are ideal for applications that require higher performance plastics, thermal and electrical resistance, and low outgassing for harsh environments, reducing the risk of containment and thermal instability. Essentra's PEEK range offers lightweight and versatile alternatives that securely bridge the gap between nylon fasteners and traditional metal fasteners.

APPLICATIONS & INDUSTRIES

- Fuel Systems
- Aerospace
- Medical Industries
- Electronics
- Ultra-High Vacuums
- Automotive Manufacturing
- Oil & Gas Refining
- Energy Services Equipment

WRSS Series PEEK Set Screws - Hex Socket




Specifications:

- Material: PEEK
- Color: Beige
- Flammability Standard: UL94 V-0

Features:

- High-strength, chemically resistant PEEK
- Reliable performance up to 260°C / 500°F

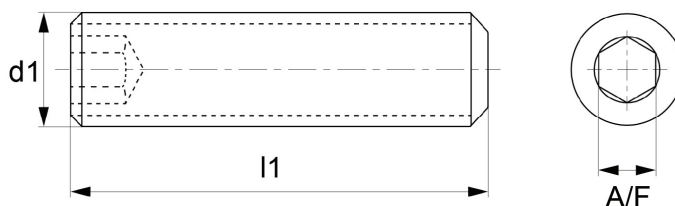

Item No.	d1	l1		A/F
		mm		mm
20767310	M3	4.0		1.5
20767327	M3	6.0		1.5
20767334	M3	8.0		1.5
20767341	M3	10.0		1.5
20767358	M3	12.0		1.5
20767372	M4	6.0		2.0
20767389	M4	8.0		2.0
20767396	M4	10.0		2.0
20767402	M4	12.0		2.0
20767433	M5	6.0		2.5
20767440	M5	8.0		2.5
20767471	M5	15.0		2.5
20767488	M5	20.0		2.5
20767495	M6	6.0		3.0
20767518	M6	10.0		3.0
20767525	M6	12.0		3.0
20767587	M8	15.0		4.0



STOCK2SHIP

— By Essentra —

With over 15,000 of our most popular products readily available for shipping and our stock availability of over 90% for our catalog caps and plugs in our **STOCK2SHIP** Program, we ensure that you'll have what you need when you need it.