

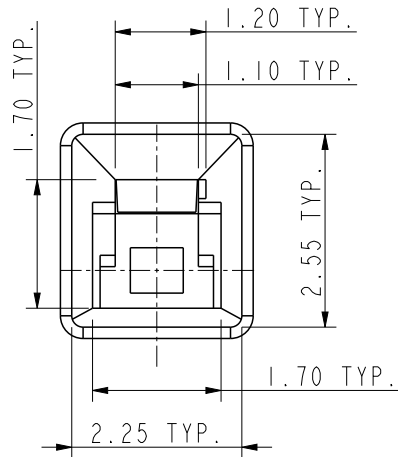
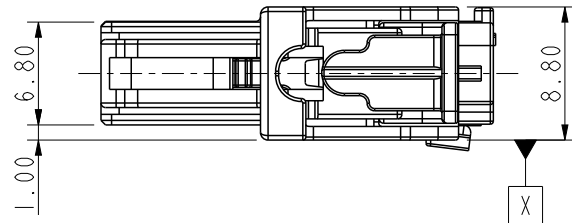
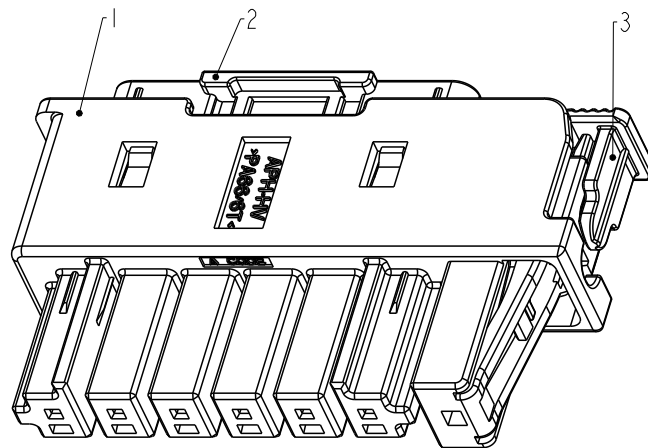
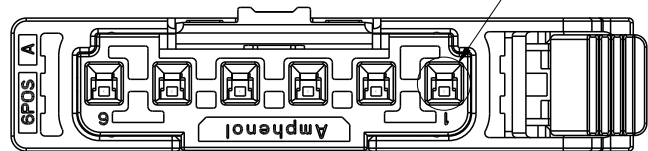
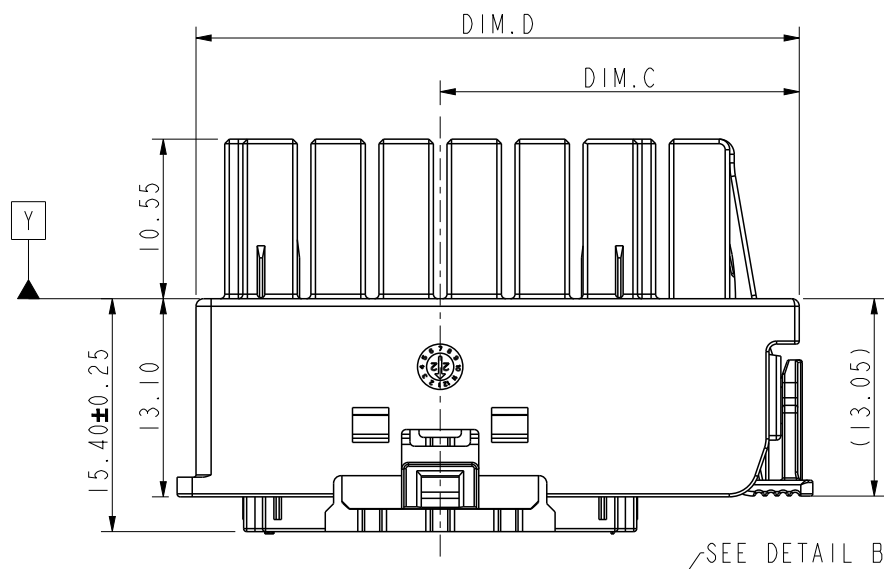


PART NUMBER
10170159-1XXXXLF

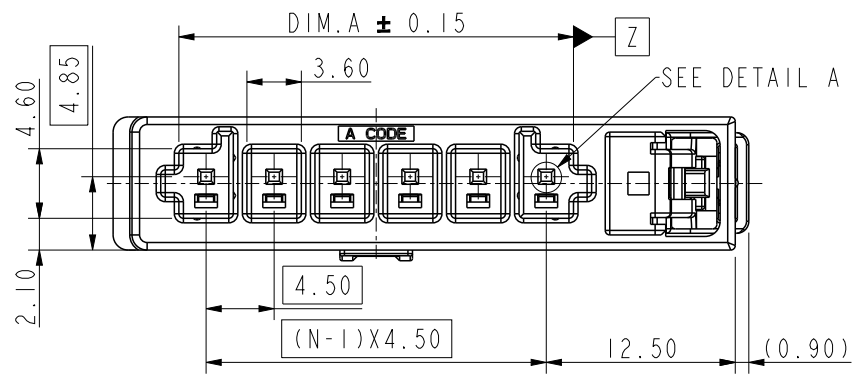


DETAIL B
SCALE 10:1

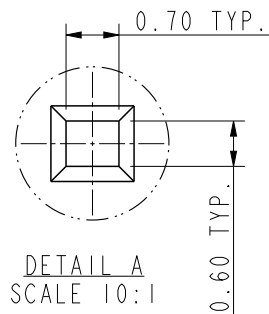


DETAIL A
SCALE 10:1

A CODE / COLOR:ORANGE;COLOR CODE:RAL2008

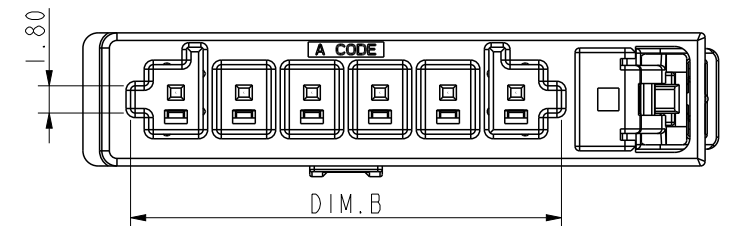

B CODE / COLOR:ORANGE;COLOR CODE:RAL2008

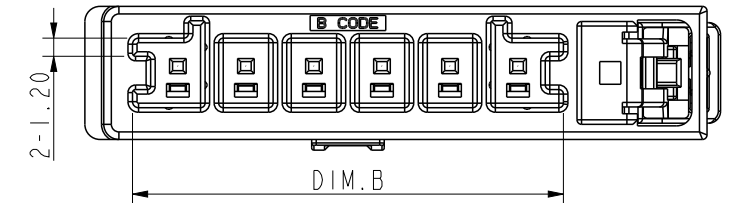

POS.	PART NO.	DIM.A	DIM.B	DIM.C	DIM.D
06	10170159-106XXLF	26.10	28.50	23.75	39.90
07	10170159-107XXLF	30.60	33.00	26.00	44.40
08	10170159-108XXLF	35.10	37.50	28.25	48.90
09	10170159-109XXLF	39.60	42.00	30.50	53.40
10	10170159-110XXLF	44.10	46.50	32.75	57.90

NOTES:

1. MATERIAL:PA66 OR PA6T,THERMOPLASTIC UL94 V-0
COLOR:ORANGE WITH RED CPA
2. PACKAGE SPECITICATION: GS-14-3001.
3. PART NUMBER CODE: 10170159-1 XX X X

NUMBER OF POSITIONS

06 → 6 PINS
07 → 7 PINS

10 → 10 PINS

RoHS COMPATABLE
FOR CUSTOMER CODE

CODE TYPE
A → A CODE
B → B CODE

PACKAGING
K → PE BAG
T → TRAY PACKAGE

3	SIDE LATCH CPA	THERMOPLASTIC UL94 V-0;RED	I	
2	INNER RECEPTACLE HOUSING	THERMOPLASTIC UL94 V-0;ORANGE	I	
1	SIDE LATCH PLR	THERMOPLASTIC UL94 V-0;ORANGE	I	
No.	Components Desicription	Material Specifications	Q'ty	Remarks

spec ref	dr	Jeffrey Huang	2023/07/21	projection	mm	size	A3	scale	2:1
tolerance std	eng	Nick Zhang	2024/09/05	chr	-	ecn no	ELX-N-52752-1	rel level	Released
ISO 406 ISO 1101	appr	Tim Yao	2024/09/10	product family		rel level	Released		
surface	linear	0.X	±0.3	Amphenol FCi	RECEPTACLE KITS,WITH CPA	dwg no	10170159	rev	B
ISO 1302	angular	0°	±2°		HVLock Series Cable Kits				
				cat. no.		Product - Customer Drw		sheet 1 of 1	