


R13-930

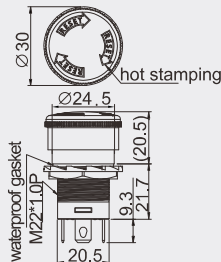

21A 14V DC
10A 28V DC

FEATURES

 
- * MATERIAL: Frame and bottom are nylon. Terminals are silver plated copper.
- * Push button is PC.
- * Waterproof gasket is EPDM.
- * IP56 when supplied with panel sealed.

FUNCTION

 Non-lighted
Push-lock.turn-reset




 Lighted
Push-lock.turn-reset




BUTTON

  S $\varnothing 30$



 M $\varnothing 40$

 

TERMINAL

 0 1 .250" SQ

 1 6 No.4-36 UNC

FRAME COLOR

BUTTON COLOR

LED COLOR

 None

 B Black

 R Red

LIGHT VOLTAGE


 None

 1 12V DC

 2 24V DC


 3 48V DC

Cut-out

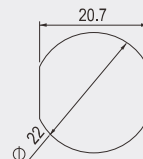

 1.5~5 mm max

R13-930-11 SAFETY HOLDER

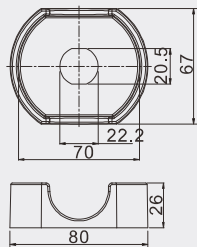

FEATURES

- * MATERIAL: Frame is ABS.
- * Fits SCI switches: R13-930 series

