



FEATURES

- ※Various LED options
- ※300,000 operation life cycles

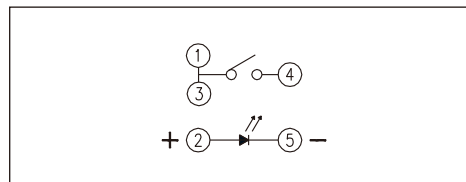
APPLICATION

- ※Automotive
- ※Network equipment
- ※Telecommunications
- ※Medical equipment
- ※Industrial controls

SPECIFICATION

Contact Rating	50mA, 32V DC
Contact Resistance	100mΩ max.
Insulation Resistance	100MΩ min. 100V DC
Dielectric Strength	250V AC/1 minute
Operating Force	400±100gf
Travel	0.45mm
Operating Life	300, 000 cycles
Operating Temp.	-40°C ~ +85°C
Storage Temp.	-55°C ~ +85°C

CIRCUIT



PACKAGE

<Tape & Reel>
650 pcs.

HOW TO ORDER

ML9 - M QR

S.M.T.

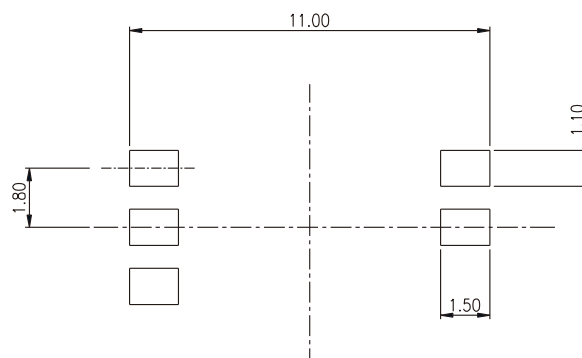
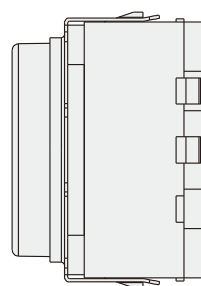
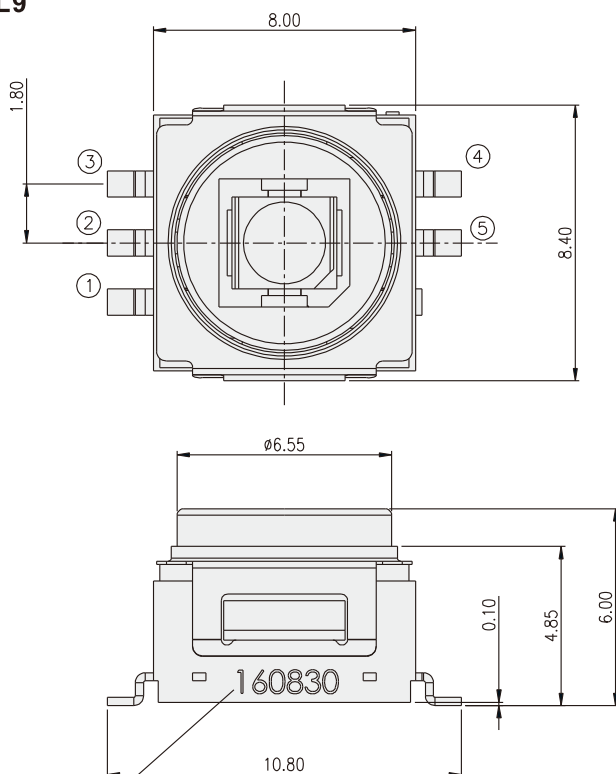
□=Without Post
P=With Post

Operation Force:
4=400gf

- Package:
Tape & Reel

- Halogen Free

LED Color:
☐=Without LED
 B=Blue
 G=Green
 R=Red
 W=White
 O=Orange

ML9

P.C.B. LAYOUT

Date code: YYMMDD