


50P Series Metric Phillips Pan Head Screw

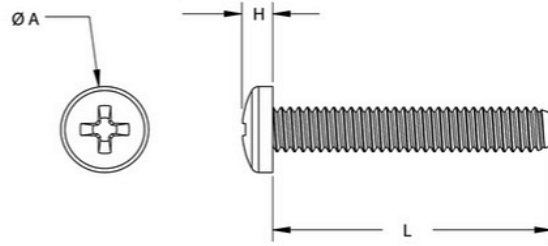

Specifications:

- Material: UL94 V-2 Nylon 6/6
- Color: Natural

Item No.	Thread	L mm	H mm	Ø A mm	Bulk Pack Qty
50M020040P004	M2 x 0.4	4.0	1.4 - 1.6	3.7 - 4.0	1000
50M020040P005	M2 x 0.4	5.0	1.4 - 1.6	3.7 - 4.0	1000
50M020040P006	M2 x 0.4	6.0	1.4 - 1.6	3.7 - 4.0	1000
50M020040P008	M2 x 0.4	8.0	1.4 - 1.6	3.7 - 4.0	1000
50M020040P010	M2 x 0.4	10.0	1.4 - 1.6	3.7 - 4.0	1000
50M020040P012	M2 x 0.4	12.0	1.4 - 1.6	3.7 - 4.0	1000
50M020040P016	M2 x 0.4	16.0	1.4 - 1.6	3.7 - 4.0	1000
50M020040P020	M2 x 0.4	20.0	1.4 - 1.6	3.7 - 4.0	1000
50M020040P025	M2 x 0.4	25.0	1.4 - 1.6	3.7 - 4.0	1000
50M025045P004	M2.5 x 0.45	4.0	1.9 - 2.1	4.7 - 5.0	1000
50M025045P005	M2.5 x 0.45	5.0	1.9 - 2.1	4.7 - 5.0	1000
50M025045P006	M2.5 x 0.45	6.0	1.9 - 2.1	4.7 - 5.0	1000
50M025045P008	M2.5 x 0.45	8.0	1.9 - 2.1	4.7 - 5.0	1000
50M025045P010	M2.5 x 0.45	10.0	1.9 - 2.1	4.7 - 5.0	1000
50M025045P012	M2.5 x 0.45	12.0	1.9 - 2.1	4.7 - 5.0	1000
50M025045P016	M2.5 x 0.45	16.0	1.9 - 2.1	4.7 - 5.0	1000
50M025045P020	M2.5 x 0.45	20.0	1.9 - 2.1	4.7 - 5.0	1000
50M025045P025	M2.5 x 0.45	25.0	1.9 - 2.1	4.7 - 5.0	1000
50M030050P003	M3 x 0.5	3.0	2.2 - 2.4	5.3 - 5.6	1000
50M030050P004	M3 x 0.5	4.0	2.2 - 2.4	5.3 - 5.6	1000
50M030050P005	M3 x 0.5	5.0	2.2 - 2.4	5.3 - 5.6	1000
50M030050P006	M3 x 0.5	6.0	2.2 - 2.4	5.3 - 5.6	1000
50M030050P008	M3 x 0.5	8.0	2.2 - 2.4	5.3 - 5.6	1000
50M030050P010	M3 x 0.5	10.0	2.2 - 2.4	5.3 - 5.6	1000
50M030050P012	M3 x 0.5	12.0	2.2 - 2.4	5.3 - 5.6	1000
50M030050P016	M3 x 0.5	16.0	2.2 - 2.4	5.3 - 5.6	1000
50M030050P020	M3 x 0.5	20.0	2.2 - 2.4	5.3 - 5.6	1000
50M030050P025	M3 x 0.5	25.0	2.2 - 2.4	5.3 - 5.6	1000
50M030050P030	M3 x 0.5	30.0	2.2 - 2.4	5.3 - 5.6	1000
50M030050P035	M3 x 0.5	35.0	2.2 - 2.4	5.3 - 5.6	500
50M030050P042	M3 x 0.5	42.0	2.2 - 2.4	5.3 - 5.6	1000
50M035060P005	M3.5 x 0.6	5.0	2.3 - 2.6	6.6 - 7.0	1000
50M035060P006	M3.5 x 0.6	6.0	2.3 - 2.6	6.6 - 7.0	1000
50M035060P007	M3.5 x 0.6	7.0	2.3 - 2.6	6.6 - 7.0	1000
50M035060P008	M3.5 x 0.6	8.0	2.3 - 2.6	6.6 - 7.0	1000
50M035060P010	M3.5 x 0.6	10.0	2.3 - 2.6	6.6 - 7.0	1000
50M035060P012	M3.5 x 0.6	12.0	2.3 - 2.6	6.6 - 7.0	1000
50M035060P016	M3.5 x 0.6	16.0	2.3 - 2.6	6.6 - 7.0	1000
50M035060P020	M3.5 x 0.6	20.0	2.3 - 2.6	6.6 - 7.0	1000
50M035060P025	M3.5 x 0.6	25.0	2.3 - 2.6	6.6 - 7.0	1000
50M035060P035	M3.5 x 0.6	35.0	2.3 - 2.6	6.6 - 7.0	1000
50M035060P042	M3.5 x 0.6	42.0	2.3 - 2.6	6.6 - 7.0	1000
50M040070P003	M4 x 0.7	3.0	2.8 - 3.1	7.6 - 8.0	1000
50M040070P006	M4 x 0.7	6.0	2.8 - 3.1	7.6 - 8.0	1000
50M040070P008	M4 x 0.7	8.0	2.8 - 3.1	7.6 - 8.0	1000
50M040070P010	M4 x 0.7	10.0	2.8 - 3.1	7.6 - 8.0	1000
50M040070P012	M4 x 0.7	12.0	2.8 - 3.1	7.6 - 8.0	1000
50M040070P016	M4 x 0.7	16.0	2.8 - 3.1	7.6 - 8.0	1000
50M040070P020	M4 x 0.7	20.0	2.8 - 3.1	7.6 - 8.0	1000

Item No.	Thread	L mm	H mm	Ø A mm	Bulk Pack Qty
50M040070P025	M4 x 0.7	25.0	2.8 - 3.1	7.6 - 8.0	1000
50M040070P030	M4 x 0.7	30.0	2.8 - 3.1	7.6 - 8.0	1000
50M040070P035	M4 x 0.7	35.0	2.8 - 3.1	7.6 - 8.0	500
50M040070P040	M4 x 0.7	40.0	2.8 - 3.1	7.6 - 8.0	500
50M050080P006	M5 x 0.8	6.0	3.4 - 3.7	9.1 - 9.5	1000
50M050080P008	M5 x 0.8	8.0	3.4 - 3.7	9.1 - 9.5	1000
50M050080P010	M5 x 0.8	10.0	3.4 - 3.7	9.1 - 9.5	1000
50M050080P012	M5 x 0.8	12.0	3.4 - 3.7	9.1 - 9.5	1000
50M050080P015	M5 x 0.8	15.0	3.4 - 3.7	9.1 - 9.5	1000
50M050080P016	M5 x 0.8	16.0	3.4 - 3.7	9.1 - 9.5	1000
50M050080P020	M5 x 0.8	20.0	3.4 - 3.7	9.1 - 9.5	1000
50M050080P025	M5 x 0.8	25.0	3.4 - 3.7	9.1 - 9.5	500
50M050080P030	M5 x 0.8	30.0	3.4 - 3.7	9.1 - 9.5	500
50M050080P035	M5 x 0.8	35.0	3.4 - 3.7	9.1 - 9.5	500
50M050080P040	M5 x 0.8	40.0	3.4 - 3.7	9.1 - 9.5	500
50M060100P005	M6 x 1.0	5.0	4.3 - 4.6	11.5 - 12.0	1000
50M060100P008	M6 x 1.0	8.0	4.3 - 4.6	11.5 - 12.0	1000
50M060100P010	M6 x 1.0	10.0	4.3 - 4.6	11.5 - 12.0	1000
50M060100P012	M6 x 1.0	12.0	4.3 - 4.6	11.5 - 12.0	500
50M060100P016	M6 x 1.0	16.0	4.3 - 4.6	11.5 - 12.0	500
50M060100P020	M6 x 1.0	20.0	4.3 - 4.6	11.5 - 12.0	500
50M060100P022	M6 x 1.0	22.0	4.3 - 4.6	11.5 - 12.0	500
50M060100P025	M6 x 1.0	25.0	4.3 - 4.6	11.5 - 12.0	500
50M060100P030	M6 x 1.0	30.0	4.3 - 4.6	11.5 - 12.0	500
50M060100P035	M6 x 1.0	35.0	4.3 - 4.6	11.5 - 12.0	1000
50M060100P040	M6 x 1.0	40.0	4.3 - 4.6	11.5 - 12.0	500
50M060100P045	M6 x 1.0	45.0	4.3 - 4.6	11.5 - 12.0	500
50M060100P050	M6 x 1.0	50.0	4.3 - 4.6	11.5 - 12.0	500
50M060100P060	M6 x 1.0	60.0	4.3 - 4.6	11.5 - 12.0	500
50M060100P070	M6 x 1.0	70.0	4.3 - 4.6	11.5 - 12.0	500
50M060100P075	M6 x 1.0	75.0	4.3 - 4.6	11.5 - 12.0	500
50M080125P010	M8 x 1.25	10.0	5.6 - 6.0	15.5 - 16.0	500
50M080125P016	M8 x 1.25	16.0	5.6 - 6.0	15.5 - 16.0	500
50M080125P020	M8 x 1.25	20.0	5.6 - 6.0	15.5 - 16.0	500
50M080125P025	M8 x 1.25	25.0	5.6 - 6.0	15.5 - 16.0	500
50M080125P030	M8 x 1.25	30.0	5.6 - 6.0	15.5 - 16.0	500
50M080125P035	M8 x 1.25	35.0	5.6 - 6.0	15.5 - 16.0	500
50M080125P050	M8 x 1.25	50.0	5.6 - 6.0	15.5 - 16.0	500
50M080125P070	M8 x 1.25	70.0	5.6 - 6.0	15.5 - 16.0	500
50M100150P013	M10 x 1.5	13.0	7.1 - 7.5	19.4 - 20.0	500
50M100150P016	M10 x 1.5	16.0	7.1 - 7.5	19.4 - 20.0	500
50M100150P019	M10 x 1.5	19.0	7.1 - 7.5	19.4 - 20.0	500
50M100150P020	M10 x 1.5	20.0	7.1 - 7.5	19.4 - 20.0	500
50M100150P025	M10 x 1.5	25.0	7.1 - 7.5	19.4 - 20.0	500
50M100150P030	M10 x 1.5	30.0	7.1 - 7.5	19.4 - 20.0	500
50M100150P035	M10 x 1.5	35.0	7.1 - 7.5	19.4 - 20.0	500
50M100150P050	M10 x 1.5	50.0	7.1 - 7.5	19.4 - 20.0	500
50M100150P060	M10 x 1.5	60.0	7.1 - 7.5	19.4 - 20.0	500