


KE 610

6 Digit, Non-Reset Electro-Mechanical Counter

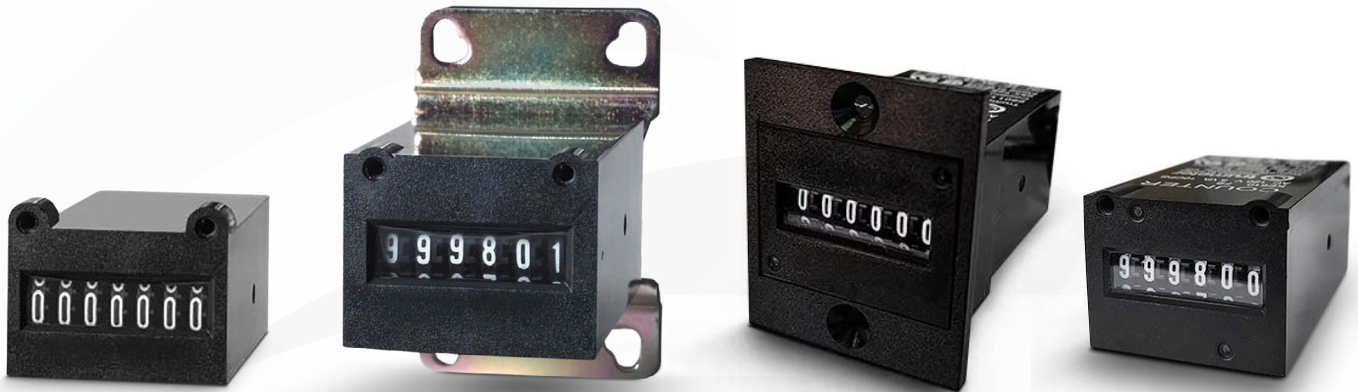

The KE610 electro-mechanical counter features a patented drive mechanism designed to deliver reliable performance with minimal power consumption across a wide temperature range.

It retains count data during power outages or in environments prone to electrical noise, making it ideal for mission-critical or high-usage applications. Available in a range of AC and DC voltages ensures a broad compatibility with different systems. Its compact design and multiple versatile mounting options (including two front flange styles, base flange, behind-panel (front mount), and rear-screw mounting) makes it highly adaptable to a variety of installations.

Key Features


- Economical solution with large quantity discounts
- Patented high-performance mechanism
- UL wire leads
- Rugged, durable plastic housing
- Wide range of voltage options available (AC or DC)
- Long operating life for dependable performance

Applications


- Mail equipment
- Photo processing machines
- Vending machines
- Gaming and amusement machines
- Elevators and lift systems
- Copy machines
- Ticketing machines

Diagrams


FL & F3 Flange Mount

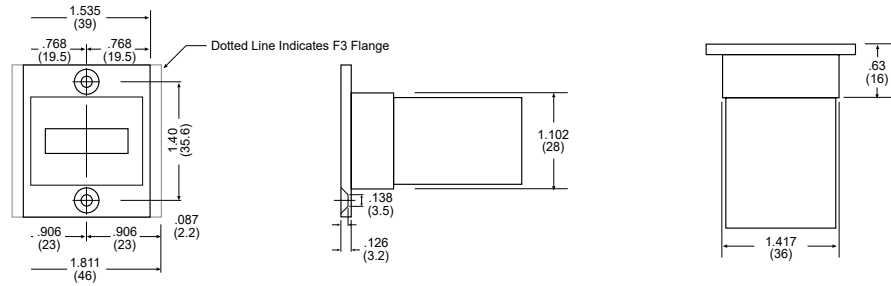


F Front Mount

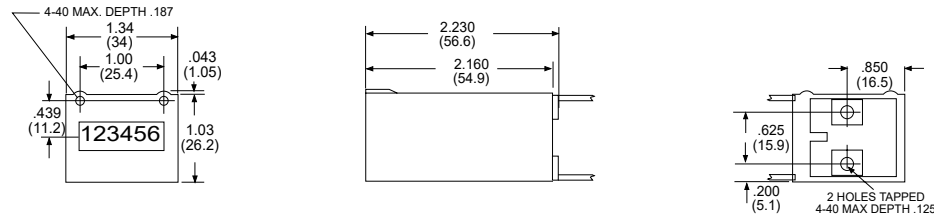


FI Front Insert Mount

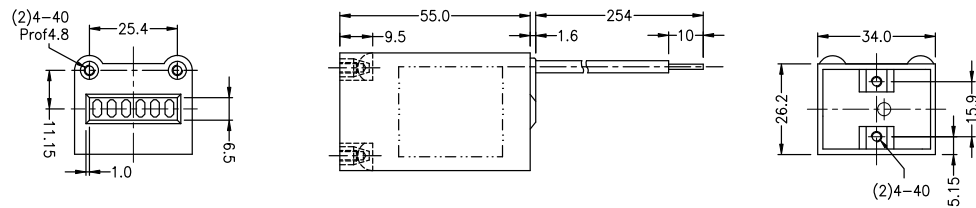


FB Front & Base Mount

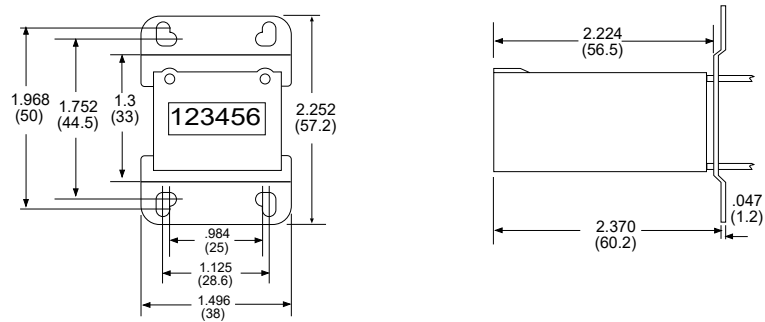

R Rear Mount

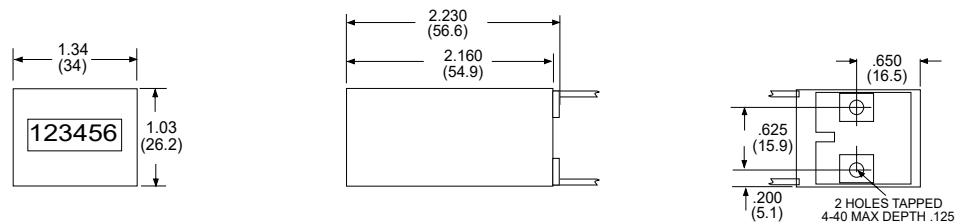

B Base Mount

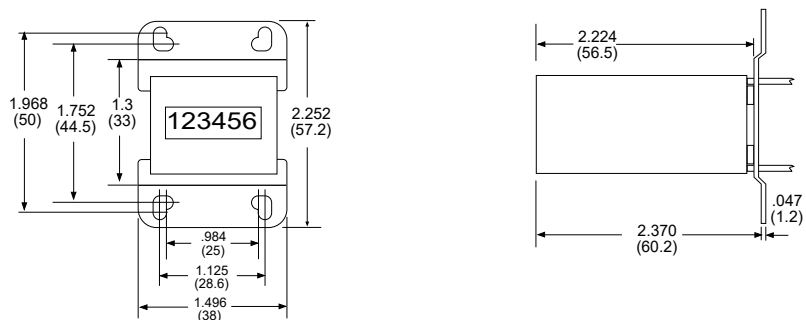

Specifications

Digits:	6
Digit Size:	0.160" white on black. Colors available. <i>Special 0-5-0-5 available.</i>
Operating Voltage $\pm 10\%$:	DC: 4.5, 6, 12, 24, 48, 110 (2W) AC: 24, 48, 120, 220 (5VA)
Reset:	None
Count Speed:	10 CPS, standard. 50/50 ratio on/off.
Max. on Time:	Infinite
Temperature:	<i>Storage:</i> 14°F to 122°F (-10°C to +50°C). <i>Operating:</i> 23°F to 104°F (-5°C to +40°C).
Approvals:	UL# E60420, cUL, CE
Termination:	UL/cUL wire leads, 10" long, standard.
Weight:	4 oz. (113g.)

Part Number Ordering Chart

Example:

KE610 A FB 10 DC 12

Series

KE610 6 Digit

Special Features (Omit if no special feature desired)

A Add Diode Suppression (DC only)

.01 Coin, 2 wheels red on black

.05 Coin, 2 wheels red on black (steps 05, 10, 15 ...)

Mounting

FL Flange Mount 1.535" x 1.811"

F3 Flange Mount 1.811" x 1.811"

F Front

FI Front Mount (4-40) with inserts

FB Front & Base

R Rear Mount

B Base Mount

Count Speed

10 10 CPS (Standard)

Operating Voltage

AC

DC

Voltage Level

DC: 4.5/6, 12, 24, 48, 110 to 120

AC: 24, 48, 120, 220 to 240



Trumeter (The Americas)

6601 Lyons Rd, Suite H-7
Coconut Creek, Florida
FL 33073,
USA
Tel: +1 954 725 6699
Email: sales.usa@trumeter.com

Trumeter (Europe)

Pilot Mill
Alfred Street
Bury,
BL9 9JR
Tel: +44 161 674 0960
Email: sales.uk@trumeter.com

Innovative Design Technologies Sdn. Bhd

Lot 5881, Lorong lks Bukit Minyak 1
Taman Perindustrian lks, 14000 Bukit Tengah
Penang, Malaysia
Web: www.idtworld.com
Tel: + 604 5015700
Email: sales.my@idtworld.com