


EXTreme Power Products

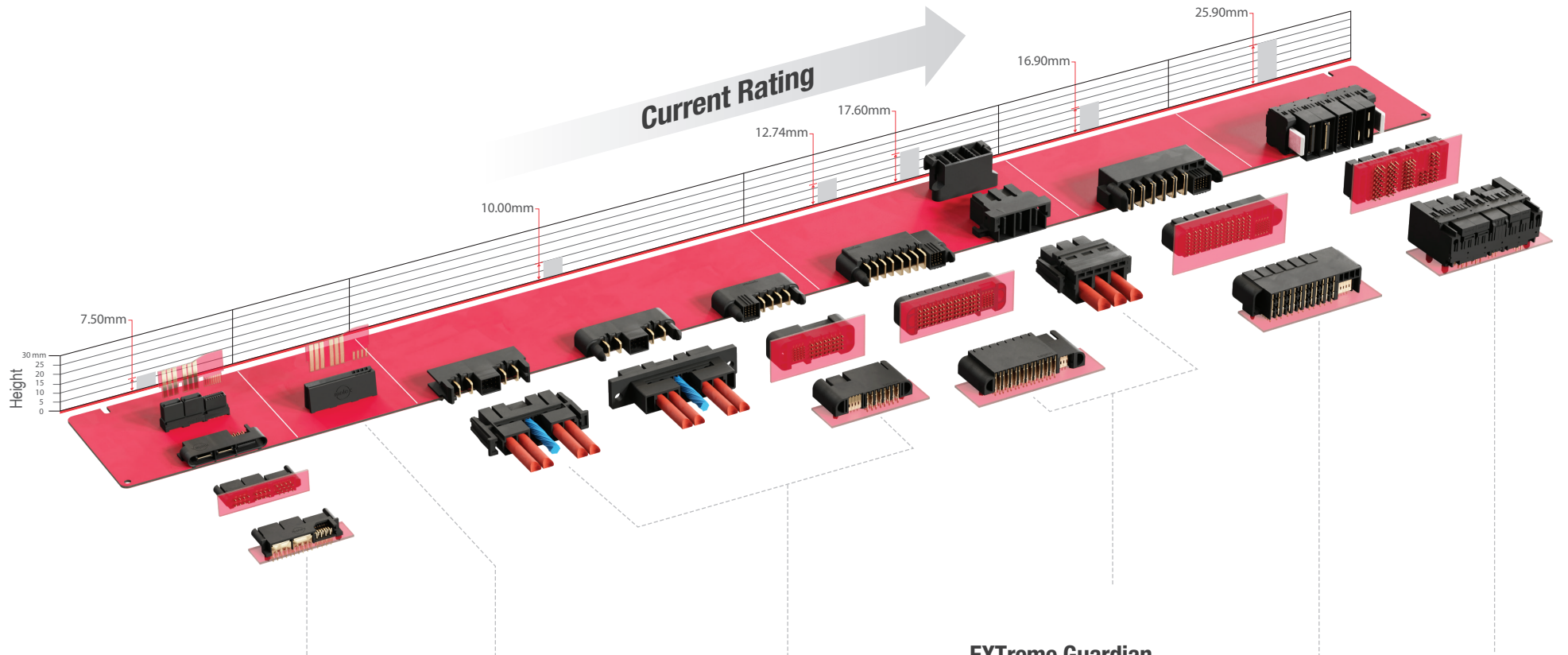

EXTreme LPHPower

Current Rating:
30.0A / Blade
50.0A / cm

Profile Height: 7.50mm
Voltage (max): 250V

EXTreme PowerEdge

Current Rating:
40.0A / Blade
62.0A / cm

Voltage (max): 250V

EXTreme Ten60Power

Current Rating:
60.0A / Blade
109.0A / cm

Profile Height: 10.00mm
Voltage (max): 600V

EXTreme Guardian

Board-to-Board

Current Rating:
80.0A / Blade
155.0A / cm

Profile Height: 12.74mm
Voltage (max): 120V

Wire-to-Board

Current Rating:
80.0A / Blade
73.0A / cm

Profile Height: 17.60mm
Voltage (max): 600V

EXTreme EnergetiC

Current Rating:
100.0A / Blade
130.0A / cm

Profile Height: 16.90mm
Voltage (max): 320V

EXTreme PowerMass

Current Rating:
150.0A / Blade
150.0A / cm

Profile Height: 25.90mm
Voltage (max): 600V