

SCT-XV & SCR-XV Common Mode Choke Coils, 12 – 15 A, High Voltage, AEC-Q200 Automotive Kit

Sample Kit Contents

KEMET Part Number	Rated Voltage AC/DC (V)	Rated Current (A)	Inductance (mH) $\pm 30\%$	DC Resistance/ Line (m Ω) $\pm 13\%$	Temperature Rise (K) Maximum	Quantity	Description
SCT19XV-120-1R2A007JV	1,000	12	0.180	3.99	50	2	Common Mode SCT-XV Coils, Automotive Grade, -40/+150°C
SCT19XV-150-1R3A006JV	1,000	15	0.134	2.91	50	2	Common Mode SCT-XV Coils, Automotive Grade, -40/+150°C
SCT25XV-130-1R5A012JV	1,000	13	1.150	6.33	55	2	Common Mode SCT-XV Coils, Automotive Grade, -40/+150°C
SCT25XV-150-1R6A010JV	1,000	15	0.800	4.62	50	2	Common Mode SCT-XV Coils, Automotive Grade, -40/+150°C
SCT29XV-120-1R6A017JV	1,000	12	0.960	6.43	40	2	Common Mode SCT-XV Coils, Automotive Grade, -40/+150°C
SCT29XV-150-1R7A015JV	1,000	15	0.750	5.04	55	2	Common Mode SCT-XV Coils, Automotive Grade, -40/+150°C
SCR19XV-120-1R2A007JV	1,000	12	0.300	3.99	50	2	Common Mode SCR-XV Coils, Automotive Grade, -40/+120°C
SCR19XV-150-1R3A006JV	1,000	15	0.220	2.91	50	2	Common Mode SCR-XV Coils, Automotive Grade, -40/+120°C
SCR25XV-130-1R5A012JV	1,000	13	1.770	6.33	55	2	Common Mode SCR-XV Coils, Automotive Grade, -40/+120°C
SCR25XV-150-1R6A010JV	1,000	15	1.230	4.62	50	2	Common Mode SCR-XV Coils, Automotive Grade, -40/+120°C
SCR29XV-120-1R6A017JV	1,000	12	1.760	6.43	40	2	Common Mode SCR-XV Coils, Automotive Grade, -40/+120°C
SCR29XV-150-1R7A015JV	1,000	15	1.370	5.04	55	2	Common Mode SCR-XV Coils, Automotive Grade, -40/+120°C
KEMET Part Number	Rated Voltage AC/DC (V)	Rated Current (A)	Inductance (mH) $\pm 30\%$	DC Resistance/ Line (m Ω) $\pm 13\%$	Temperature Rise (K) Maximum	Quantity	Description

Dimensions – Millimeters

Figure 1


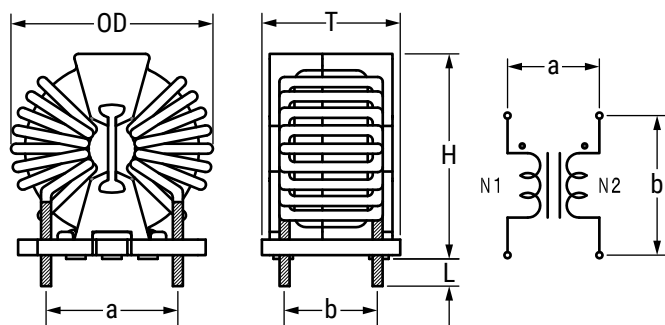


Figure 2

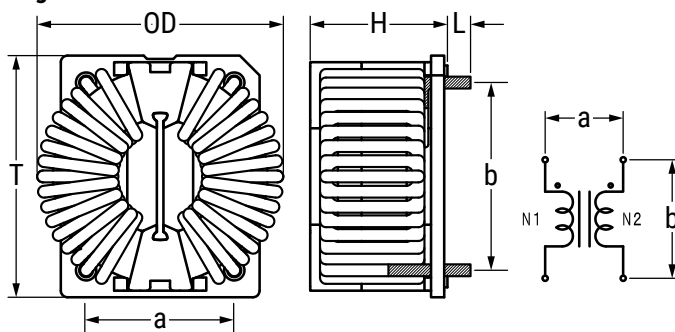

Part Name	Dimensions (mm)				Pin Pitch ¹ (Reference)		Figure
	OD (Maximum)	T (Maximum)	H (Maximum)	L	a	b	
SCR19-JV / SCT19-JV	27.0 / 28.0	18.4	27.5	3.50 ±0.5	17.0	12.0	Fig. 1
SCR25-JV / SCT25-JV	34.0 / 35.5 / 37.5	26.0	33.5	3.50 ±0.5	20.5	18.5	
SCR29-JV / SCT29-JV	39.0 / 40.5 / 41.5	21.4	37.7	3.50 ±0.5	22.5	13.5	
SCR19-JH / SCT19-JH	27.0 / 28.0	27.0	18.9	3.50 ±0.5	17.0	19.0	Fig. 2
SCR25-JH / SCT25-JH	34.0 / 35.5 / 37.5	33.0	26.5	3.50 ±0.5	20.5	24.5	
SCR29-JH / SCT29-JH	39.0 / 40.5 / 41.5	37.2	21.9	3.50 ±0.5	22.5	28.5	

¹ Pin pitch listed above for reference only. Values not guaranteed.