

SCT-XV & SCR-XV Common Mode Choke Coils, 18 – 22 A, High Voltage, AEC-Q200 Automotive Kit

Sample Kit Contents

KEMET Part Number	Rated Voltage AC/DC (V)	Rated Current (A)	Inductance (mH) $\pm 30\%$	DC Resistance/ Line (m Ω) $\pm 13\%$	Temperature Rise (K) Maximum	Quantity	Description
SCT19XV-190-1R5A005JV	1,000	19	0.093	1.89	50	2	Common Mode SCT-XV Coils, Automotive Grade, -40/+150°C
SCT19XV-220-1R6A004JV	1,000	22	0.060	1.38	50	2	Common Mode SCT-XV Coils, Automotive Grade, -40/+150°C
SCT25XV-190-1R8A008JV	1,000	19	0.510	2.98	55	2	Common Mode SCT-XV Coils, Automotive Grade, -40/+150°C
SCT25XV-220-1R9A007JV	1,000	22	0.390	2.35	55	2	Common Mode SCT-XV Coils, Automotive Grade, -40/+150°C
SCT29XV-180-1R8A013JV	1,000	18	0.560	3.99	60	2	Common Mode SCT-XV Coils, Automotive Grade, -40/+150°C
SCT29XV-200-2R0A011JV	1,000	20	0.400	2.73	50	2	Common Mode SCT-XV Coils, Automotive Grade, -40/+150°C
SCR19XV-190-1R5A005JV	1,000	19	0.160	1.89	50	2	Common Mode SCR-XV Coils, Automotive Grade, -40/+120°C
SCR19XV-220-1R6A004JV	1,000	22	0.100	1.38	50	2	Common Mode SCR-XV Coils, Automotive Grade, -40/+120°C
SCR25XV-190-1R8A008JV	1,000	19	0.780	2.98	55	2	Common Mode SCR-XV Coils, Automotive Grade, -40/+120°C
SCR25XV-220-1R9A007JV	1,000	22	0.600	2.35	55	2	Common Mode SCR-XV Coils, Automotive Grade, -40/+120°C
SCR29XV-180-1R8A013JV	1,000	18	1.040	3.99	60	2	Common Mode SCR-XV Coils, Automotive Grade, -40/+120°C
SCR29XV-200-2R0A011JV	1,000	20	0.740	2.73	50	2	Common Mode SCR-XV Coils, Automotive Grade, -40/+120°C
KEMET Part Number	Rated Voltage AC/DC (V)	Rated Current (A)	Inductance (mH) $\pm 30\%$	DC Resistance/ Line (m Ω) $\pm 13\%$	Temperature Rise (K) Maximum	Quantity	Description

Dimensions – Millimeters

Figure 1


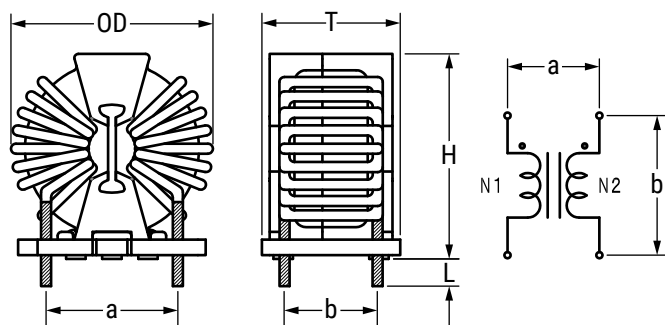


Figure 2

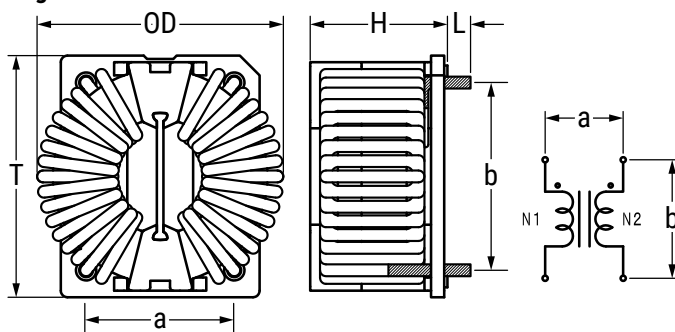

Part Name	Dimensions (mm)				Pin Pitch ¹ (Reference)		Figure
	OD (Maximum)	T (Maximum)	H (Maximum)	L	a	b	
SCR19-JV / SCT19-JV	27.0 / 28.0	18.4	27.5	3.50 ±0.5	17.0	12.0	Fig. 1
SCR25-JV / SCT25-JV	34.0 / 35.5 / 37.5	26.0	33.5	3.50 ±0.5	20.5	18.5	
SCR29-JV / SCT29-JV	39.0 / 40.5 / 41.5	21.4	37.7	3.50 ±0.5	22.5	13.5	
SCR19-JH / SCT19-JH	27.0 / 28.0	27.0	18.9	3.50 ±0.5	17.0	19.0	Fig. 2
SCR25-JH / SCT25-JH	34.0 / 35.5 / 37.5	33.0	26.5	3.50 ±0.5	20.5	24.5	
SCR29-JH / SCT29-JH	39.0 / 40.5 / 41.5	37.2	21.9	3.50 ±0.5	22.5	28.5	

¹ Pin pitch listed above for reference only. Values not guaranteed.