

simpleANT3B-HEL

**Lightweight helical Tripleband + L-band
RTK GNSS antenna (IP67)**


SKU: AS-ANT3B-HEL-L1256-SMA-00



Dimensions: 83x35x35 mm

Antenna

Frequency	GPS L1/L2/L5/L6 GLONASS G1/G2/G3 COMPASS B1/B2/B3 Galileo E1/E5b/E6
Polarization	RHCP
Axial ratio	$\leq 3\text{dB}$
V.S.W.R.	≤ 1.8
Gain	2dBi (Zenith)
Impedance	50 Ω
Horizontal coverage angle	360°

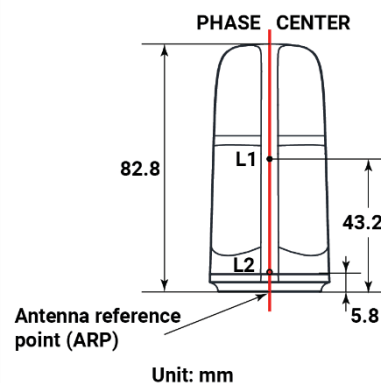

LNA

Gain	35 $\pm$ 2dB
Noise figure	$\leq 1.5\text{dB}$
Passband fluctuation	$\pm 2\text{dB}$
Supply voltage	3.0~16V DC
Current consumption	$\leq 45\text{mA}$
V.S.W.R.	≤ 1.8

Mechanical

Connector	SMA Male
-----------	----------

Environmental

Operating temperature	-40°C~+85°C
Relative humidity	Up to 95%
Ingress protection	IP67
Vibration	10 to 55Hz with 1.5mm amplitude 2 hours
Environmentally friendly	ROHS Compliant