

AI
DATA
CENTER

New Products

AQC20

Innovative Technology

Fastest connection technology for conductors.




Power Point

- ◆ Push-in Direct Locking Technology with Operating Lever.
- ◆ Several clamping units can be held open simultaneously, simplifying the connection of multi-core cables.
- ◆ Ensuring Long-lasting Reliable Connections.
- ◆ Tool-free, quick, and safe wire connection with simple lever action.




Electrical

| | |
|-----------------------|-----------|
| Product Model: | AQC20 |
| Voltage Rating: | 250V |
| Current Rating: | 20A |
| Solid Wire: | 16-14 AWG |
| Stranded Wire: | 16-14 AWG |
| Withstanding Voltage: | 1.6KV |
| Wire Strip Length: | 9-10mm |

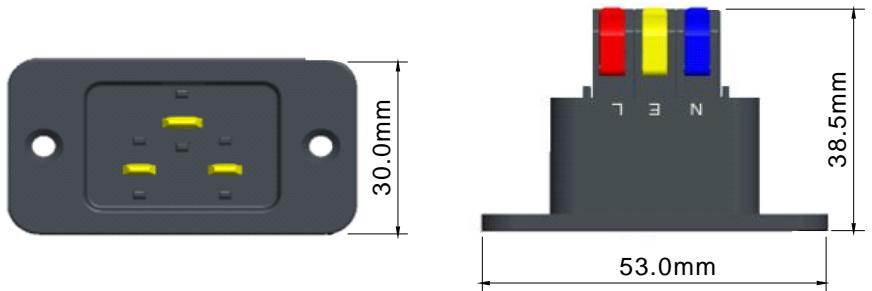

Operation Lever

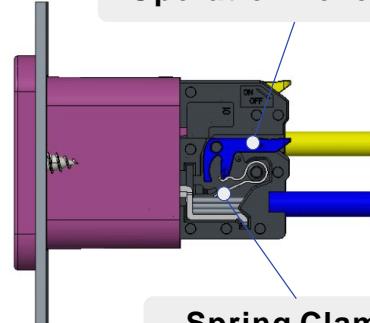

Spring Clamp

| | | | | | | | | | |
|----------------|--|---|---|---|---|---------------------|--|----------|----------|
| AQC | 20 | X | X | X | X | X | X | X | X |
| Main Body type | 0: without flange 1: with flange holes, without nut 2: with flange holes, with nut | 0: without protective cover 1: with protective cover (only for with flange type) | 0: Black 2: Red 3: Orange 4: Yellow 5: Green (RAL 6018/T) 6: Blue 8: Grey (RAL 7035/D) 9: White C: Green (RAL 6018/U) | 0: Black 2: Red 3: Orange 4: Yellow 5: Green (RAL 6018/T) 6: Blue 8: Grey (RAL 7035/D) 9: White C: Green (RAL 6018/U) | 0: Black 2: Red 3: Orange 4: Yellow 5: Green (RAL 6018/T) 6: Blue 8: Grey (RAL 7035/D) 9: White C: Green (RAL 6018/U) | Alphanumeric digits | G ROHS compliant (lead<4%) In copper alloy | | |

Application Field

- Transformer
- Switch Gear
- Gen Set
- Automatic Transfer Switch
- Uninterruptible Power Supply (UPS)
- Liquid & Immersion Cooling
- Rack PDU/ Server Rack
- Remote Power Panel
- HVAC
- Floor PDU
- Power Whip / Busway System

