

Adapters & Power Supplies

Quality Solutions for
Discerning OEMs & ODMs

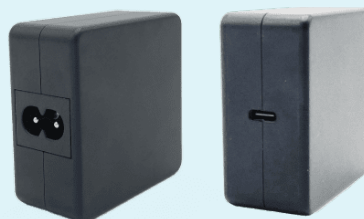


TABLE OF CONTENTS

COMPANY

ABOUT US	3
----------	---

ADAPTERS

WALLMOUNT	4 - 14
DESKTOP	15 - 26
USB C PD 3.0	27 - 28
MEDICAL	29 - 30

POWER SUPPLIES

OPEN-FRAME	31
------------	----

About Phihong

Since 1972, Phihong has been at the forefront of technological innovation in power electronics manufacture and design. By employing the latest in technology and research and development, Phihong's customers have continued to expect and receive the best possible products with on-time delivery and exceeding worldwide standards in efficiency and safety.

With a truly international space covering North America, Europe, and Asia, Phihong has design labs and local sales support centers in California, New York, the Netherlands, China, Japan, and Taiwan; Phihong is a top choice for OEMs serving datacom, telecom, personal electronics, networking, lighting, and industrial markets.

Focusing on engineering excellence, product reliability, and a commitment to customer service, sales have continued to grow proving a continued dominance in the power technology industry with a broad line of cost competitive highly efficient products that comply with international standards.

OEMs also choose Phihong to partner on custom projects to meet the needs of very special programs not satisfied by the standard product offerings. With a long history in both standard and custom power designs, Phihong has one of the market's broadest lines of cost competitive and highly reliable power solutions.



Phihong OEM/ODM Capabilities

Since 1972, Phihong has been the top choice by OEM's and ODM's throughout the world, for customized power solutions. Today over 90% of Phihong's business comes from OEM and ODM customers within the Datacom, Telecom, Networking, Personal Electronics & Industrial markets.

Phihong's OEM and ODM capabilities include:

- Simple rebranding of standard off the shelf Phihong product with customer's logo.
- Electrical modifications to standard off the shelf Phihong product.
- Mechanical modifications to standard off the shelf Phihong product, including customized ID.
- Built to print jobs.
- Complete custom designs.

With over 600 Engineering resources spanning North America, Asia and Europe, Phihong has strong localized design teams ready to solve any power problem that you may have. In addition, each OEM and ODM project has a dedicated local Program Management to act as the liaison between the factory and the customer to provide real time answers to any business issue.

Today, all Phihong manufacturing is done at our own factories in Vietnam and China, providing our OEM and ODM customers with very cost competitive solutions as well as tariff and Geo-Political risk mitigation.

Phihong's global footprint combined with our ability to provide low cost manufacturing and strong localized technical support provides a unique dynamic to our OEM and ODM customers that allows us to provide quality solutions on time, to budget and to schedule.

2.75W Fixed Blade Wallmount Adapters

Product Image	Model	Input Plug Type	Output Voltage	Output Current	Output Connector	Color	Safety Approvals
	AA03A-050A-R	US	5V	0.55A	2.1 x 5.5 x 9.5mm	Black	UL
	AA03A-050A(M)-R	US	5V	0.55A	USB Micro B	Black	UL
	AA03A-075A-R	US	7.5V	0.366A	2.1 x 5.5 x 9.5mm	Black	UL
	AA03A-090A-R	US	9V	0.306A	2.1 x 5.5 x 9.5mm	Black	UL
	AA03A-120A-R	US	12V	0.229A	2.1 x 5.5 x 9.5mm	Black	UL
	AA03C-050A-R	CN	5V	0.55A	2.1 x 5.5 x 9.5mm	Black	CCC
	AA03C-050A(M)-R	CN	5V	0.55A	USB Micro B	Black	CCC
	AA03C-075A-R	CN	7.5V	0.366A	2.1 x 5.5 x 9.5mm	Black	CCC
	AA03C-090A-R	CN	9V	0.306A	2.1 x 5.5 x 9.5mm	Black	CCC
	AA03C-120A-R	CN	12V	0.229A	2.1 x 5.5 x 9.5mm	Black	CCC
	AA03E-050A-R	EU	5V	0.55A	2.1 x 5.5 x 9.5mm	Black	CE
	AA03E-050A(M)-R	EU	5V	0.55A	USB Micro B	Black	CE
	AA03E-075A-R	EU	7.5V	0.366A	2.1 x 5.5 x 9.5mm	Black	CE
	AA03E-090A-R	EU	9V	0.306A	2.1 x 5.5 x 9.5mm	Black	CE
	AA03E-120A-R	EU	12V	0.229A	2.1 x 5.5 x 9.5mm	Black	CE
	AA03K-050A-R	UK	5V	0.55A	2.1 x 5.5 x 9.5mm	Black	UKCA
	AA03K-050A(M)-R	UK	5V	0.55A	USB Micro B	Black	UKCA
	AA03K-075A-R	UK	7.5V	0.366A	2.1 x 5.5 x 9.5mm	Black	UKCA
	AA03K-090A-R	UK	9V	0.306A	2.1 x 5.5 x 9.5mm	Black	UKCA
	AA03K-120A-R	UK	12V	0.229A	2.1 x 5.5 x 9.5mm	Black	UKCA

Product Image	Model	Input Plug Type	Output Voltage	Output Current	Output Connector	Color	Safety Approvals
	AA03S-050A-R	AU	5V	0.55A	2.1 x 5.5 x 9.5mm	Black	RCM
	AA03S-050A(M)-R	AU	5V	0.55A	USB Micro B	Black	RCM
	AA03S-075A-R	AU	7.5V	0.366A	2.1 x 5.5 x 9.5mm	Black	RCM
	AA03S-090A-R	AU	9V	0.306A	2.1 x 5.5 x 9.5mm	Black	RCM
	AA03S-120A-R	AU	12V	0.229A	2.1 x 5.5 x 9.5mm	Black	RCM

2.75W Fixed Blade USB A Wallmount Adapters

Product Image	Model	Input Plug Type	Output Voltage	Output Current	Output Connector	Color	Safety Approvals
	AQ03A-050A-R	US	5V	0.55A	USB A Receptacle	Black	UL
	AQ03A-050AW-R	US	5V	0.55A	USB A Receptacle	White	UL
	AQ03C-050A-R	CN	5V	0.55A	USB A Receptacle	Black	CCC
	AQ03C-050AW-R	CN	5V	0.55A	USB A Receptacle	White	CCC
	AQ03E-050A-R	EU	5V	0.55A	USB A Receptacle	Black	CE
	AQ03E-050AW-R	EU	5V	0.55A	USB A Receptacle	White	CE
	AQ03K-050A-R	UK	5V	0.55A	USB A Receptacle	Black	UKCA
	AQ03K-050AW-R	UK	5V	0.55A	USB A Receptacle	White	UKCA
	AQ03S-050A-R	AU	5V	0.55A	USB A Receptacle	Black	RCM
	AQ03S-050AW-R	AU	5V	0.55A	USB A Receptacle	White	RCM

5W Fixed Blade Wallmount Adapters

Product Image	Model	Input Plug Type	Output Voltage	Output Current	Output Connector	Color	Safety Approvals
	PSAC05A-050L6-R	US	5V	1.0A	2.1 x 5.5 x 10mm	Black	UL
	PSAC05A-050L6M-R	US	5V	1.0A	USB Micro B	Black	UL
	PSAC05A-050L6B-R	US	5V	1.0A	USB Mini B	Black	UL
	PSAC05E-050L6-R	EU	5V	1.0A	2.1 x 5.5 x 10mm	Black	CE
	PSAC05E-050L6M-R	EU	5V	1.0A	USB Micro B	Black	CE
	PSAC05K-050L6-R	UK	5V	1.0A	2.1 x 5.5 x 10mm	Black	UKCA
	PSAC05K-050L6M-R	UK	5V	1.0A	USB Micro B	Black	UKCA

5W Fixed Blade USB A Wallmount Adapters

Product Image	Model	Input Plug Type	Output Voltage	Output Current	Output Connector	Color	Safety Approvals
	PSA05A-050QL6-H	US	5V	1.0A	USB A Receptacle	Black	UL
	PSA05A-050QL6W-H	US	5V	1.0A	USB A Receptacle	White	UL
	PSA05C-050QL6-H	CN	5V	1.0A	USB A Receptacle	Black	CN
	PSA05C-050QL6W-H	CN	5V	1.0A	USB A Receptacle	White	CN
	PSA05E-050QL6-H	EU	5V	1.0A	USB A Receptacle	Black	CE
	PSA05E-050QL6WS-H	EU	5V	1.0A	USB A Receptacle	White	CE
	PSA05K-050QL6-H	UK	5V	1.0A	USB A Receptacle	Black	UKCA
	PSA05K-050QL6WS-H	UK	5V	1.0A	USB A Receptacle	White	UKCA
	PSA05S-050QL6-H	AU	5V	1.0A	USB A Receptacle	Black	RCM
	PSA05S-050QL6WS-H	AU	5V	1.0A	USB A Receptacle	White	RCM

5W Fixed Blade USB A Wallmount Adapters

Product Image	Model	Input Plug Type	Output Voltage	Output Current	Output Connector	Color	Safety Approvals
	PSAA05A-050QL6-R	US	5V	1.0A	USB A Receptacle	Black	UL
	PSAA05A-050QL6W-R	US	5V	1.0A	USB A Receptacle	White	UL
	PSAA05E-050QL6-R	EU	5V	1.0A	USB A Receptacle	Black	CE
	PSAA05E-050QL6W-R	EU	5V	1.0A	USB A Receptacle	White	CE
	PSAA05K-050QL6-R	UK	5V	1.0A	USB A Receptacle	Black	UKCA
	PSAA05K-050QL6W-R	UK	5V	1.0A	USB A Receptacle	White	UKCA
	PSAA05S-050QL6-R	AU	5V	1.0A	USB A Receptacle	Black	RCM
	PSAA05S-050QL6W-R	AU	5V	1.0A	USB A Receptacle	White	RCM

5W Interchangeable Blade Wallmount Adapters

Product Image	Model	Input Plug Type	Output Voltage	Output Current	Output Connector	Color	Safety Approvals
	PSAC05R-050L6M-R	Interchangeable	5V	1.0A	USB Micro B	Black	UL, CE, UKCA, RCM
	PSAC05R-050L6B-R	Interchangeable	5V	1.0A	USB Mini B	Black	UL, CE, UKCA, RCM
	PSAC05R-050L6-R	Interchangeable	5V	1.0A	2.1 x 5.5 x 9.5mm	Black	UL, CE, UKCA, RCM

5W Interchangeable Blade USB A Wallmount Adapters

Product Image	Model	Input Plug Type	Output Voltage	Output Current	Output Connector	Color	Safety Approvals
	PSAI05R-050QL6-R	Interchangeable	5V	1.0A	USB A Receptacle	Black	UL, CE, UKCA, RCM

5W Folding blade + Interchangeable Blade USB A Wallmount Adapters

Product Image	Model	Input Plug Type	Output Voltage	Output Current	Output Connector	Color	Safety Approvals
	PSA05F-050QAL6-H	Folding US + Interchangeable	5V	1.0A	USB A Receptacle	Black	UL, CE, UKCA
	PSA05F-050QAL6D-H	Folding US + Interchangeable	5V	1.0A	USB A Receptacle	Black	UL, CE, UKCA

10W Fixed Blade Wallmount Adapters

Product Image	Model	Input Plug Type	Output Voltage	Output Current	Output Connector	Color	Safety Approvals
	AA10A-050A-R	US	5V	2.0A	2.1 x 5.5 x 9.5mm	Black	UL
	AA10A-050A(M)-R	US	5V	2.0A	USB Micro B	Black	UL
	AA10E-050A-R	EU	5V	2.0A	2.1 x 5.5 x 9.5mm	Black	CE
	AA10E-050A(M)-R	EU	5V	2.0A	USB Micro B	Black	CE
	AA10K-050A-R	UK	5V	2.0A	2.1 x 5.5 x 9.5mm	Black	UKCA
	AA10K-050A(M)-R	UK	5V	2.0A	USB Micro B	Black	UKCA
	AA10S-050A-R	AU	5V	2.0A	2.1 x 5.5 x 9.5mm	Black	RCM
	AA10S-050A(M)-R	AU	5V	2.0A	USB Micro B	Black	RCM

10W Fixed Blade USB A Wallmount Adapters

Product Image	Model	Input Plug Type	Output Voltage	Output Current	Output Connector	Color	Safety Approvals
	AQ10A-050B-H	US	5V	2.0A	USB A Receptacle	Black	UL
	AQ10A-050BP-H	US	5V	2.0A	USB A Receptacle	Black	UL
	AQ10A-050BW-H	US	5V	2.0A	USB A Receptacle	White	UL
	AQ10E-050B-H	EU	5V	2.0A	USB A Receptacle	Black	CE
	AQ10E-050BP-H	EU	5V	2.0A	USB A Receptacle	Black	CE
	AQ10E-050BW-H	EU	5V	2.0A	USB A Receptacle	White	CE
	AQ10K-050B-H	UK	5V	2.0A	USB A Receptacle	Black	UKCA
	AQ10K-050BW-H	UK	5V	2.0A	USB A Receptacle	White	UKCA
	AQ10S-050B-H	AU	5V	2.0A	USB A Receptacle	Black	RCM
	AQ10S-050BW-H	AU	5V	2.0A	USB A Receptacle	White	RCM

10W Fixed Blade Wallmount Adapters

Product Image	Model	Input Plug Type	Output Voltage	Output Current	Output Connector	Color	Safety Approvals
	PSM10A-050A-R	US	5V	2.0A	2.1 x 5.5 x 9.5mm	Black	UL

10W Fixed blade USB A Wallmount Adapters

Product Image	Model	Input Plug Type	Output Voltage	Output Current	Output Connector	Color	Safety Approvals
	PSA10FS-050Q-R	AU	5V	2.0A	USB A Receptacle	Black	RCM
	PSA10FS-050Q(D)-R	AU	5V	2.0A	USB A Receptacle	Black	RCM

10W Interchangeable Blade Wallmount Adapters

Product Image	Model	Input Plug Type	Output Voltage	Output Current	Output Connector	Color	Safety Approvals
	PSM10R-050A-R	Interchangeable	5V	2.0A	2.1 x 5.5 x 9.5mm	Black	UL, CE, UKCA, RCM
	PSM10R-050A(M)-R	Interchangeable	5V	2.0A	USB Micro B	Black	UL, CE, UKCA, RCM

10W Interchangeable Blade USB A Wallmount Adapters

Product Image	Model	Input Plug Type	Output Voltage	Output Current	Output Connector	Color	Safety Approvals
	PSAF10R-050QA-R	Interchangeable	5V	2.0A	USB A Receptacle	Black	UL, CE, UKCA, RCM, PSE, CCC, KC, BSMI, PSB, BIS, EAC

10W Folding Blade + Interchangeable Blade Wallmount Adapters

Product Image	Model	Input Plug Type	Output Voltage	Output Current	Output Connector	Color	Safety Approvals
	PSA10F-050-R	Folding US + Interchangeable	5V	2.0A	USB Micro B	Black	UL, CE, UKCA, PSE
	PSA10F-050(P)-R	Folding US + Interchangeable	5V	2.0A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA, PSE
	PSA10FC-050-R	Folding CN + Interchangeable	5V	2.0A	USB Micro B	Black	CCC

10W Folding Blade + Interchangeable USB A Wallmount Adapters

Product Image	Model	Input Plug Type	Output Voltage	Output Current	Output Connector	Color	Safety Approvals
	PSA10F-050Q-R	Folding US + Interchangeable	5V	2.0A	USB A Receptacle	Black	UL, CE, UKCA, PSB, PSE
	PSA10F-050Q(D)-R	Folding US + Interchangeable	5V	2.0A	USB A Receptacle	Black	UL, CE, UKCA, PSB, PSE
	PSA10F-050Q(S)-R	Folding US + Interchangeable	5V	2.0A	USB A Receptacle	Black	UL, CE, UKCA, PSB, PSE
	PSA10FC-050Q-R	Folding CN + Interchangeable	5V	2.0A	USB A Receptacle	Black	CCC

12W Fixed Blade Wallmount Adapters

Product Image	Model	Input Plug Type	Output Voltage	Output Current	Output Connector	Color	Safety Approvals
	PSAA12A-120L6-R	US	12V	1.0A	2.1 x 5.5 x 9.5mm	Black	UL
	PSAA12E-120L6-R	EU	12V	1.0A	2.1 x 5.5 x 9.5mm	Black	CE
	PSAC12A-050-R	US	5V	2.4A	2.1 x 5.5 x 10mm	Black	UL
	PSAC12A-060-R	US	5.9V	2.0A	2.1 x 5.5 x 10mm	Black	UL
	PSAC12A-075-R	US	7.5V	1.6A	2.1 x 5.5 x 10mm	Black	UL
	PSAC12A-090-R	US	9V	1.33A	2.1 x 5.5 x 10mm	Black	UL
	PSAC12A-120-R	US	12V	1.0A	2.1 x 5.5 x 10mm	Black	UL
	PSAC12A-150-R	US	15V	0.8A	2.1 x 5.5 x 10mm	Black	UL
	PSAC12A-240-R	US	24V	0.5A	2.1 x 5.5 x 10mm	Black	UL
	PSAC12A-480-R	US	48V	0.25A	2.1 x 5.5 x 10mm	Black	UL

12W Interchangeable Blade Wallmount Adapters

Product Image	Model	Input Plug Type	Output Voltage	Output Current	Output Connector	Color	Safety Approvals
	PSAC12R-050-R	Interchangeable	5V	2.4A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA, RCM
	PSAC12R-060-R	Interchangeable	5.9V	2.0A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA, RCM
	PSAC12R-075-R	Interchangeable	7.5V	1.6A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA, RCM
	PSAC12R-090-R	Interchangeable	9V	1.33A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA, RCM
	PSAC12R-120-R	Interchangeable	12V	1.0A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA, RCM
	PSAC12R-150-R	Interchangeable	15V	0.8A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA, RCM
	PSAC12R-240-R	Interchangeable	24V	0.5A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA, RCM
	PSAC12R-480-R	Interchangeable	48V	0.25A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA, RCM

15W Fixed Blade Wallmount Adapters

Product Image	Model	Input Plug Type	Output Voltage	Output Current	Output Connector	Color	Safety Approvals
	PSC15A-050-R	US	5V	3.0A	2.1 x 5.5 x 10mm	Black	UL
	PSC15A-060-R	US	5.9V	2.5A	2.1 x 5.5 x 10mm	Black	UL
	PSC15A-075-R	US	7.5V	2.0A	2.1 x 5.5 x 10mm	Black	UL
	PSC15A-090-R	US	9V	1.67A	2.1 x 5.5 x 10mm	Black	UL
	PSA15A-120P6-R	US	12V	1.25A	2.1 x 5.5 x 10mm	Black	UL
	PSA15A-150P6-R	US	15V	1.0A	2.1 x 5.5 x 10mm	Black	UL
	PSA15A-240P6-R	US	24V	0.625A	2.1 x 5.5 x 10mm	Black	UL
	PSA15A-480P6-R	US	48V	0.31A	2.1 x 5.5 x 10mm	Black	UL

15W Interchangeable Blade Wallmount Adapters

Product Image	Model	Input Plug Type	Output Voltage	Output Current	Output Connector	Color	Safety Approvals
	PSC15R-050-R	Interchangeable	5V	3.0A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA, RCM
	PSC15R-060-R	Interchangeable	5.9V	2.5A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA, RCM
	PSC15R-075-R	Interchangeable	7.5V	2.0A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA, RCM
	PSC15R-090-R	Interchangeable	9V	1.67A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA, RCM
	PSA15R-120P6-R	Interchangeable	12V	1.25A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA, RCM
	PSA15R-150P6-R	Interchangeable	15V	1.0A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA, RCM
	PSA15R-240P6-R	Interchangeable	24V	0.625A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA, RCM
	PSA15R-480P6-R	Interchangeable	48V	0.31A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA, RCM

15W Fixed Blade USB C Wallmount Adapters - 2nd Gen

Product Image	Model	Input Plug Type	Output Voltage	Output Current	Output Connector	Color	Safety Approvals
	AQI5A-050B-H	US	5V	3.0A	USB C Receptacle	Black	UL
	AQI5A-050BW-H	US	5V	3.0A	USB C Receptacle	White	UL
	AQI5E-050B-H	EU	5V	3.0A	USB C Receptacle	Black	CE
	AQI5E-050BW-H	EU	5V	3.0A	USB C Receptacle	White	CE
	AQI5K-050B-H	UK	5V	3.0A	USB C Receptacle	Black	CE, UKCA
	AQI5K-050BW-H	UK	5V	3.0A	USB C Receptacle	White	CE, UKCA

15W Fixed Blade USB C Wallmount Adapters

Product Image	Model	Input Plug Type	Output Voltage	Output Current	Output Connector	Color	Safety Approvals
	AQ15A-050A-H	US	5V	3.0A	USB C Receptacle	Black	UL
	AQ15A-050AW-H	US	5V	3.0A	USB C Receptacle	White	UL
	AQ15E-050A-H	EU	5V	3.0A	USB C Receptacle	Black	CE
	AQ15E-050AW-H	EU	5V	3.0A	USB C Receptacle	White	CE

19.2W Fixed Blade Wallmount Adapters

Product Image	Model	Input Plug Type	Output Voltage	Output Current	Output Connector	Color	Safety Approvals
	PPL18A-120	US	12V	1.6A	2.1 x 5.5 x 9.5mm	Black	UL

20W Interchangeable Blade Wallmount Adapters

Product Image	Model	Input Plug Type	Output Voltage	Output Current	Output Connector	Color	Safety Approvals
	PSAA20R-050L6-R	Interchangeable	5V	4.0A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA, RCM
	AA20R-120A-R	Interchangeable	12V	1.67A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA, RCM
	AA20R-240A-R	Interchangeable	24V	0.83A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA, RCM
	AA20R-480A-R	Interchangeable	48V	0.42A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA, RCM

24W Fixed Blade Wallmount Adapter

Product Image	Model	Input Plug Type	Output Voltage	Output Current	Output Connector	Color	Safety Approvals
	PPL24A-120	US	12V	2.0A	2.1 x 5.5 x 10mm	Black	UL

30W Interchangeable Blade Wallmount Adapter

Product Image	Model	Input Plug Type	Output Voltage	Output Current	Output Connector	Color	Safety Approvals
	PSAA30R-120-R	Interchangeable	12V	2.5A	2.1 x 5.5 x 9.5mm	Black	UL, CE, UKCA, RCM
	PSAA30R-150-R	Interchangeable	15V	2.0A	2.1 x 5.5 x 9.5mm	Black	UL, CE, UKCA, RCM
	PSAA30R-240-R	Interchangeable	24V	1.25A	2.1 x 5.5 x 9.5mm	Black	UL, CE, UKCA, RCM

36W Fixed Blade Wallmount Adapters

Product Image	Model	Input Plug Type	Output Voltage	Output Current	Output Connector	Color	Safety Approvals
	PPL36A-050	US	5V	5.0A	2.1 x 5.5 x 10mm	Black	UL
	PPL36A-075	US	7.5V	4.0A	2.1 x 5.5 x 10mm	Black	UL
	PPL36A-085	US	8.5V	3.52A	2.1 x 5.5 x 10mm	Black	UL
	PPL36A-090	US	9V	3.34A	2.1 x 5.5 x 10mm	Black	UL
	PPL36A-120L6	US	12V	3.0A	2.1 x 5.5 x 10mm	Black	UL
	PPL36A-120	US	12V	3.0A	2.1 x 5.5 x 10mm	Black	UL
	PPL36A-135	US	13.5V	2.66A	2.1 x 5.5 x 10mm	Black	UL
	PPL36A-150	US	15V	2.4A	2.1 x 5.5 x 10mm	Black	UL
	PPL36A-160	US	16V	2.25A	2.1 x 5.5 x 10mm	Black	UL
	PPL36A-180	US	18V	2.0A	2.1 x 5.5 x 10mm	Black	UL
	PPL36A-240	US	24V	1.5A	2.1 x 5.5 x 10mm	Black	UL
	PPL36A-480	US	48V	0.75A	2.1 x 5.5 x 10mm	Black	UL

15W to 19W Desktop Adapters - C6, C14, C8

Product Image	Model	Input Plug Type	Output Voltage	Output Current	Output Connector	Color	Safety Approvals
	PPL18M-050L6	IEC 320 C6	5V	3.0A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA
	PPL18M-050	IEC 320 C6	5V	3.0A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA
	PPL18M-060L6	IEC 320 C6	5.9V	3.0A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA
	PPL18M-060	IEC 320 C6	5.9V	3.0A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA
	PPL18M-070	IEC 320 C6	7V	2.5A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA
	PPL18M-075	IEC 320 C6	7.5V	2.5A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA
	PPL18M-090	IEC 320 C6	9V	2.2A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA
	PPL18M-100L6	IEC 320 C6	10V	1.9A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA
	PPL18M-100	IEC 320 C6	10V	1.9A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA
	PPL18M-110L6	IEC 320 C6	11V	1.6A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA
	PPL18M-110	IEC 320 C6	11V	1.6A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA
	PPL18M-120	IEC 320 C6	12V	1.6A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA
	PPL18M-150	IEC 320 C6	15V	1.3A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA
	PPL18M-160	IEC 320 C6	16V	1.2A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA
	PPL18M-180	IEC 320 C6	18V	1.1A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA
	PPL18M-240	IEC 320 C6	24V	0.8A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA
	PPL18U-050L6	IEC 320 C14	5V	3.0A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA
	PPL18U-050	IEC 320 C14	5V	3.0A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA
	PPL18U-060L6	IEC 320 C14	5.9V	3.0A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA
	PPL18U-060	IEC 320 C14	5.9V	3.0A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA
	PPL18U-070	IEC 320 C14	7V	2.5A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA
	PPL18U-075	IEC 320 C14	7.5V	2.5A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA
	PPL18U-090	IEC 320 C14	9V	2.2A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA

Product Image	Model	Input Plug Type	Output Voltage	Output Current	Output Connector	Color	Safety Approvals
	PPL18U-100L6	IEC 320 C14	10V	1.9A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA
	PPL18U-100	IEC 320 C14	10V	1.9A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA
	PPL18U-110L6	IEC 320 C14	11V	1.6A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA
	PPL18U-110	IEC 320 C14	11V	1.6A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA
	PPL18U-120	IEC 320 C14	12V	1.6A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA
	PPL18U-150	IEC 320 C14	15V	1.3A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA
	PPL18U-160	IEC 320 C14	16V	1.2A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA
	PPL18U-180	IEC 320 C14	18V	1.1A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA
	PPL18U-240	IEC 320 C14	24V	0.8A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA
	PPL18W-050L6	IEC 320 C8	5V	3.0A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA
	PPL18W-050	IEC 320 C8	5V	3.0A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA
	PPL18W-060L6	IEC 320 C8	5.9V	3.0A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA
	PPL18W-060	IEC 320 C8	5.9V	3.0A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA
	PPL18W-070	IEC 320 C8	7V	2.5A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA
	PPL18W-075	IEC 320 C8	7.5V	2.5A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA
	PPL18W-090	IEC 320 C8	9V	2.2A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA
	PPL18W-100L6	IEC 320 C8	10V	1.9A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA
	PPL18W-100	IEC 320 C8	10V	1.9A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA
	PPL18W-110L6	IEC 320 C8	11V	1.6A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA
	PPL18W-110	IEC 320 C8	11V	1.6A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA
	PPL18W-120	IEC 320 C8	12V	1.6A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA
	PPL18W-150	IEC 320 C8	15V	1.3A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA
	PPL18W-160	IEC 320 C8	16V	1.2A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA
	PPL18W-180	IEC 320 C8	18V	1.1A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA
	PPL18W-240	IEC 320 C8	24V	0.8A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA

20W to 24W Desktop Adapters - C6, C14, C8

Product Image	Model	Input Plug Type	Output Voltage	Output Current	Output Connector	Color	Safety Approvals
	PPL24M-050	IEC 320 C6	5V	4.0A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA
	PPL24M-059	IEC 320 C6	5.9V	3.5A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA
	PPL24M-060	IEC 320 C6	5.9V	4.0A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA
	PPL24M-070	IEC 320 C6	7V	3.0A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA
	PPL24M-075	IEC 320 C6	7.5V	3.0A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA
	PPL24M-090	IEC 320 C6	9V	2.5A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA
	PPL24M-120	IEC 320 C6	12V	2.0A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA
	PPL24M-150	IEC 320 C6	15V	1.6A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA
	PPL24M-240	IEC 320 C6	24V	1.0A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA
	PPL24M-480	IEC 320 C6	48V	0.5A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA
	PPL24U-050	IEC 320 C14	5V	4.0A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA
	PPL24U-059	IEC 320 C14	5.9V	3.5A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA
	PPL24U-060	IEC 320 C14	5.9V	4.0A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA
	PPL24U-070	IEC 320 C14	7V	3.0A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA
	PPL24U-075	IEC 320 C14	7.5V	3.0A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA
	PPL24U-090	IEC 320 C14	9V	2.5A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA
	PPL24U-120	IEC 320 C14	12V	2.0A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA
	PPL24U-150	IEC 320 C14	15V	1.6A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA
	PPL24U-240	IEC 320 C14	24V	1.0A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA
	PPL24U-480	IEC 320 C14	48V	0.5A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA
	PPL24W-050	IEC 320 C8	5V	4.0A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA
	PPL24W-059	IEC 320 C8	5.9V	3.5A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA
	PPL24W-060	IEC 320 C8	5.9V	4.0A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA

20W to 24W Desktop Adapters - C8

Product Image	Model	Input Plug Type	Output Voltage	Output Current	Output Connector	Color	Safety Approvals
	PPL24W-070	IEC 320 C8	7V	3.0A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA
	PPL24W-075	IEC 320 C8	7.5V	3.0A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA
	PPL24W-090	IEC 320 C8	9V	2.5A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA
	PPL24W-120	IEC 320 C8	12V	2.0A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA
	PPL24W-150	IEC 320 C8	15V	1.6A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA
	PPL24W-240	IEC 320 C8	24V	1.0A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA
	PPL24W-480	IEC 320 C8	48V	0.5A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA

25W to 36W Desktop Adapters - C14

Product Image	Model	Input Plug Type	Output Voltage	Output Current	Output Connector	Color	Safety Approvals
	PPL36U-050	IEC 320 C14	5V	5.0A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA
	PPL36U-075	IEC 320 C14	7.5V	4.0A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA
	PPL36U-085	IEC 320 C14	8.5V	3.52A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA
	PPL36U-090	IEC 320 C14	9V	3.34A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA
	PPL36U-120L6	IEC 320 C14	12V	3.0A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA
	PPL36U-120	IEC 320 C14	12V	3.0A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA
	PPL36U-135	IEC 320 C14	13.5V	2.66A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA
	PPL36U-150	IEC 320 C14	15V	2.4A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA
	PPL36U-160	IEC 320 C14	16V	2.25A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA
	PPL36U-180	IEC 320 C14	18V	2.0A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA
	PPL36U-240	IEC 320 C14	24V	1.5A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA
	PPL36U-480	IEC 320 C14	48V	0.75A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA

25W to 36W Desktop Adapters - C8

Product Image	Model	Input Plug Type	Output Voltage	Output Current	Output Connector	Color	Safety Approvals
	PPL36W-050	IEC 320 C8	5V	5.0A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA
	PPL36W-075	IEC 320 C8	7.5V	4.0A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA
	PPL36W-085	IEC 320 C8	8.5V	3.52A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA
	PPL36W-090	IEC 320 C8	9V	3.34A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA
	PPL36W-120L6	IEC 320 C8	12V	3.0A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA
	PPL36W-120	IEC 320 C8	12V	3.0A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA
	PPL36W-135	IEC 320 C8	13.5V	2.66A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA
	PPL36W-150	IEC 320 C8	15V	2.4A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA
	PPL36W-160	IEC 320 C8	16V	2.25A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA
	PPL36W-180	IEC 320 C8	18V	2.0A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA
	PPL36W-240	IEC 320 C8	24V	1.5A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA
	PPL36W-480	IEC 320 C8	48V	0.75A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA

30W Desktop Adapters - C14

Product Image	Model	Input Plug Type	Output Voltage	Output Current	Output Connector	Color	Safety Approvals
	PSAC30U-120L6-R	IEC 320 C14	12V	2.5A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA
	PSAC30U-240L6-R	IEC 320 C14	24V	1.25A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA

36W Desktop Adapters - C14

Product Image	Model	Input Plug Type	Output Voltage	Output Current	Output Connector	Color	Safety Approvals
	AA36U-120B-R	IEC 320 C14	12V	3.0A	2.1 x 5.5 x 10mm	Black	PENDING
	AA36U-240B-R	IEC 320 C14	24V	1.5A	2.1 x 5.5 x 10mm	Black	PENDING

65W Desktop Adapters - C6, C14, C8

Product Image	Model	Input Plug Type	Output Voltage	Output Current	Output Connector	Color	Safety Approvals
	AA65M-120A-R	IEC 320 C6	12V	5.41A	2.1 x 5.5 x 9.5mm	Black	UL, CE, UKCA
	AA65M-180A-R	IEC 320 C6	18V	3.61A	2.1 x 5.5 x 9.5mm	Black	UL, CE, UKCA
	AA65M-190A-R	IEC 320 C6	19V	3.42A	2.1 x 5.5 x 9.5mm	Black	UL, CE, UKCA
	AA65M-240A-R	IEC 320 C6	24V	2.7A	2.1 x 5.5 x 9.5mm	Black	UL, CE, UKCA
	AA65M-480A-R	IEC 320 C6	48V	1.35A	2.1 x 5.5 x 9.5mm	Black	UL, CE, UKCA
	AA65M-540A-R	IEC 320 C6	54V	1.2A	2.1 x 5.5 x 9.5mm	Black	UL, CE, UKCA
	AA65U-120A-R	IEC 320 C14	12V	5.41A	2.1 x 5.5 x 9.5mm	Black	UL, CE, UKCA
	AA65U-180A-R	IEC 320 C14	18V	3.61A	2.1 x 5.5 x 9.5mm	Black	UL, CE, UKCA
	AA65U-190A-R	IEC 320 C14	19V	3.42A	2.1 x 5.5 x 9.5mm	Black	UL, CE, UKCA
	AA65U-240A-R	IEC 320 C14	24V	2.7A	2.1 x 5.5 x 9.5mm	Black	UL, CE, UKCA
	AA65U-480A-R	IEC 320 C14	48V	1.35A	2.1 x 5.5 x 9.5mm	Black	UL, CE, UKCA
	AA65U-540A-R	IEC 320 C14	54V	1.2A	2.1 x 5.5 x 9.5mm	Black	UL, CE, UKCA
	AA65W-120A-R	IEC 320 C8	12V	5.41A	2.1 x 5.5 x 9.5mm	Black	UL, CE, UKCA
	AA65W-180A-R	IEC 320 C8	18V	3.61A	2.1 x 5.5 x 9.5mm	Black	UL, CE, UKCA
	AA65W-190A-R	IEC 320 C8	19V	3.42A	2.1 x 5.5 x 9.5mm	Black	UL, CE, UKCA
	AA65W-240A-R	IEC 320 C8	24V	2.7A	2.1 x 5.5 x 9.5mm	Black	UL, CE, UKCA
	AA65W-480A-R	IEC 320 C8	48V	1.35A	2.1 x 5.5 x 9.5mm	Black	UL, CE, UKCA
	AA65W-540A-R	IEC 320 C8	54V	1.2A	2.1 x 5.5 x 9.5mm	Black	UL, CE, UKCA

60W to 65W Desktop Adapters - C6, C14

Product Image	Model	Input Plug Type	Output Voltage	Output Current	Output Connector	Color	Safety Approvals
	PPL65M-120	IEC 320 C6	12V	5.0A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA
	PPL65M-135	IEC 320 C6	13.5V	4.82A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA
	PPL65M-150	IEC 320 C6	15V	4.34A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA
	PPL65M-160	IEC 320 C6	16V	4.07A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA
	PPL65M-180	IEC 320 C6	18V	3.62A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA
	PPL65M-190	IEC 320 C6	19V	3.43A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA
	PPL65M-200	IEC 320 C6	20V	3.25A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA
	PPL65M-240	IEC 320 C6	24V	2.71A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA
	PPL65M-300	IEC 320 C6	30V	2.17A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA
	PPL65M-320	IEC 320 C6	32V	2.04A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA
	PPL65M-480	IEC 320 C6	48V	1.36A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA
	PPL65M-560	IEC 320 C6	56V	1.17A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA
	PPL65U-120	IEC 320 C14	12V	5.0A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA
	PPL65U-135	IEC 320 C14	13.5V	4.82A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA
	PPL65U-150	IEC 320 C14	15V	4.34A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA
	PPL65U-160	IEC 320 C14	16V	4.07A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA
	PPL65U-180	IEC 320 C14	18V	3.62A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA
	PPL65U-190	IEC 320 C14	19V	3.43A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA
	PPL65U-200	IEC 320 C14	20V	3.25A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA
	PPL65U-240	IEC 320 C14	24V	2.71A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA
	PPL65U-300	IEC 320 C14	30V	2.17A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA
	PPL65U-320	IEC 320 C14	32V	2.04A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA
	PPL65U-480	IEC 320 C14	48V	1.36A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA
	PPL65U-560	IEC 320 C14	56V	1.17A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA

60W to 65W Desktop Adapters - C8

Product Image	Model	Input Plug Type	Output Voltage	Output Current	Output Connector	Color	Safety Approvals
	PPL65W-120	IEC 320 C8	12V	5.0A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA
	PPL65W-135	IEC 320 C8	13.5V	4.82A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA
	PPL65W-150	IEC 320 C8	15V	4.34A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA
	PPL65W-160	IEC 320 C8	16V	4.07A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA
	PPL65W-180	IEC 320 C8	18V	3.62A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA
	PPL65W-190	IEC 320 C8	19V	3.43A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA
	PPL65W-200	IEC 320 C8	20V	3.25A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA
	PPL65W-240	IEC 320 C8	24V	2.71A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA
	PPL65W-300	IEC 320 C8	30V	2.17A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA
	PPL65W-320	IEC 320 C8	32V	2.04A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA
	PPL65W-480	IEC 320 C8	48V	1.36A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA
	PPL65W-560	IEC 320 C8	56V	1.17A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA

84W to 90W Desktop Adapters - C6

Product Image	Model	Input Plug Type	Output Voltage	Output Current	Output Connector	Color	Safety Approvals
	PPL90M-120	IEC 320 C6	12V	7.0A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA
	PPL90M-150	IEC 320 C6	15V	6.0A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA
	PPL90M-160	IEC 320 C6	16V	5.63A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA
	PPL90M-180	IEC 320 C6	18V	5.0A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA
	PPL90M-190	IEC 320 C6	19V	4.74A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA
	PPL90M-200	IEC 320 C6	20V	4.5A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA
	PPL90M-240	IEC 320 C6	24V	3.75A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA
	PPL90M-300	IEC 320 C6	30V	3.0A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA

84W to 90W Desktop Adapters - C6, C14

Product Image	Model	Input Plug Type	Output Voltage	Output Current	Output Connector	Color	Safety Approvals
	PPL90M-480	IEC 320 C6	48V	1.88A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA
	PPL90M-560	IEC 320 C6	56V	1.6A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA
	PPL90U-120	IEC 320 C14	12V	7.0A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA
	PPL90U-150	IEC 320 C14	15V	6.0A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA
	PPL90U-160	IEC 320 C14	16V	5.63A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA
	PPL90U-180	IEC 320 C14	18V	5.0A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA
	PPL90U-190	IEC 320 C14	19V	4.74A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA
	PPL90U-200	IEC 320 C14	20V	4.5A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA
	PPL90U-240	IEC 320 C14	24V	3.75A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA
	PPL90U-300	IEC 320 C14	30V	3.0A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA
	PPL90U-480	IEC 320 C14	48V	1.88A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA
	PPL90U-560	IEC 320 C14	56V	1.6A	2.1 x 5.5 x 10mm	Black	UL, CE, UKCA

90W Desktop Adapters - C14, C8

Product Image	Model	Input Plug Type	Output Voltage	Output Current	Output Connector	Color	Safety Approvals
	AA90U-120B-R	IEC 320 C14	12V	7.5A	2.1 x 5.5 x 9.5mm	Black	UL, CE, UKCA
	AA90U-190B-R	IEC 320 C14	19V	4.74A	2.1 x 5.5 x 9.5mm	Black	UL, CE, UKCA
	AA90U-240B-R	IEC 320 C14	24V	3.75A	2.1 x 5.5 x 9.5mm	Black	UL, CE, UKCA
	AA90U-480B-R	IEC 320 C14	48V	1.87A	2.1 x 5.5 x 9.5mm	Black	UL, CE, UKCA
	AA90U-540B-R	IEC 320 C14	54V	1.67A	2.1 x 5.5 x 9.5mm	Black	UL, CE, UKCA
	AA90W-120B-R	IEC 320 C8	12V	7.5A	2.1 x 5.5 x 9.5mm	Black	UL, CE, UKCA
	AA90W-190B-R	IEC 320 C8	19V	4.74A	2.1 x 5.5 x 9.5mm	Black	UL, CE, UKCA
	AA90W-240B-R	IEC 320 C8	24V	3.75A	2.1 x 5.5 x 9.5mm	Black	UL, CE, UKCA

Product Image	Model	Input Plug Type	Output Voltage	Output Current	Output Connector	Color	Safety Approvals
	AA90W-480B-R	IEC 320 C8	48V	1.87A	2.1 x 5.5 x 9.5mm	Black	UL, CE, UKCA
	AA90W-540B-R	IEC 320 C8	54V	1.67A	2.1 x 5.5 x 9.5mm	Black	UL, CE, UKCA

108W to 120W Desktop Adapters - C14

Product Image	Model	Input Plug Type	Output Voltage	Output Current	Output Connector	Color	Safety Approvals
	PSA120U-120L6-R	IEC 320 C14	12V	9.0A	4 Pin DIN	Black	UL, CE, UKCA
	PSA120U-240L6-R	IEC 320 C14	24V	5.0A	2.5 x 5.5 x 10mm	Black	UL, CE, UKCA
	PSA120U-480L6-R	IEC 320 C14	48V	2.5A	2.5 x 5.5 x 10mm	Black	UL, CE, UKCA

120W Desktop Adapters - C14

Product Image	Model	Input Plug Type	Output Voltage	Output Current	Output Connector	Color	Safety Approvals
	AA120U-120B-R	IEC 320 C14	12V	9.0A	4 Pin DIN	Black	UL, CE, UKCA
	AA120U-120B1-R	IEC 320 C14	12V	10.0A	4 Pin DIN	Black	UL, CE, UKCA
	AA120U-240B-R	IEC 320 C14	24V	5.0A	2.5 x 5.5 x 10mm	Black	UL, CE, UKCA
	AA120U-480B-R	IEC 320 C14	48V	2.5A	2.5 x 5.5 x 10mm	Black	UL, CE, UKCA
	AA120U-540B-R	IEC 320 C14	54V	2.22A	2.5 x 5.5 x 10mm	Black	UL, CE, UKCA

150W Desktop Adapters - C6

Product Image	Model	Input Plug Type	Output Voltage	Output Current	Output Connector	Color	Safety Approvals
	AAI50M-190B-R	IEC 320 C6	19V	7.9A	2.5 x 5.5 x 11mm	Black	UL, CE, UKCA
	AAI50M-240B-R	IEC 320 C6	24V	6.25A	2.5 x 5.5 x 11mm	Black	UL, CE, UKCA
	AAI50M-480B-R	IEC 320 C6	48V	3.12A	2.5 x 5.5 x 11mm	Black	UL, CE, UKCA
	AAI50M-540B-R	IEC 320 C6	54V	2.78A	2.5 x 5.5 x 11mm	Black	UL, CE, UKCA

150W to 160W Desktop Adapters - C6, C14

Product Image	Model	Input Plug Type	Output Voltage	Output Current	Output Connector	Color	Safety Approvals
	PPL160M-120	IEC 320 C6	12V	12.5A	4 Pin DIN	Black	UL, CE, UKCA
	PPL160M-150	IEC 320 C6	15V	10.0A	4 Pin DIN	Black	UL, CE, UKCA
	PPL160M-190	IEC 320 C6	19V	8.4A	4 Pin DIN	Black	UL, CE, UKCA
	PPL160M-240	IEC 320 C6	24V	6.6A	4 Pin DIN	Black	UL, CE, UKCA
	PPL160M-480	IEC 320 C6	48V	3.3A	4 Pin DIN	Black	UL, CE, UKCA
	PPL160M-560	IEC 320 C6	56V	2.86A	4 Pin DIN	Black	UL, CE, UKCA
	PPL160U-120	IEC 320 C14	12V	12.5A	4 Pin DIN	Black	UL, CE, UKCA
	PPL160U-150	IEC 320 C14	15V	10.0A	4 Pin DIN	Black	UL, CE, UKCA
	PPL160U-190	IEC 320 C14	19V	8.4A	4 Pin DIN	Black	UL, CE, UKCA
	PPL160U-240	IEC 320 C14	24V	6.6A	4 Pin DIN	Black	UL, CE, UKCA
	PPL160U-480	IEC 320 C14	48V	3.3A	4 Pin DIN	Black	UL, CE, UKCA
	PPL160U-560	IEC 320 C14	56V	2.86A	4 Pin DIN	Black	UL, CE, UKCA

192W to 200W Desktop Adapters - C14

Product Image	Model	Input Plug Type	Output Voltage	Output Current	Output Connector	Color	Safety Approvals
	PPL200U-120	IEC 320 C14	12V	16.0A	4 Pin DIN	Black	UL, CE, UKCA
	PPL200U-135	IEC 320 C14	13.5V	14.0A	4 Pin DIN	Black	UL, CE, UKCA
	PPL200U-190	IEC 320 C14	19.5V	10.5A	4 Pin DIN	Black	UL, CE, UKCA
	PPL200U-240	IEC 320 C14	24V	8.3A	4 Pin DIN	Black	UL, CE, UKCA
	PPL200U-480	IEC 320 C14	48V	4.17A	4 Pin DIN	Black	UL, CE, UKCA
	PPL200U-560	IEC 320 C14	56V	3.58A	4 Pin DIN	Black	UL, CE, UKCA

240W to 250W Desktop Adapters - C14

Product Image	Model	Input Plug Type	Output Voltage	Output Current	Output Connector	Color	Safety Approvals
	PPL250U-120L6	IEC 320 C14	12V	20.0A	6 Position Molex	Black	UL, CE, UKCA
	PPL250U-190L6	IEC 320 C14	19V	13.2A	6 Position Molex	Black	UL, CE, UKCA
	PPL250U-240L6	IEC 320 C14	24V	10.4A	6 Position Molex	Black	UL, CE, UKCA
	PPL250U-480L6	IEC 320 C14	48V	5.2A	6 Position Molex	Black	UL, CE, UKCA
	PPL250U-560L6	IEC 320 C14	56V	4.48A	6 Position Molex	Black	UL, CE, UKCA

288W to 300W Desktop Adapters - C14

Product Image	Model	Input Plug Type	Output Voltage	Output Current	Output Connector	Color	Safety Approvals
	PPL300U-120	IEC 320 C14	12V	24.0A	6 Position Molex	Black	UL, CE, UKCA
	PPL300U-190	IEC 320 C14	19V	15.75A	6 Position Molex	Black	UL, CE, UKCA
	PPL300U-240	IEC 320 C14	24V	12.5A	6 Position Molex	Black	UL, CE, UKCA
	PPL300U-480	IEC 320 C14	48V	6.25A	6 Position Molex	Black	UL, CE, UKCA
	PPL300U-560	IEC 320 C14	56V	5.36A	6 Position Molex	Black	UL, CE, UKCA

18W Fixed Blade USB C PD3.0 Wallmount Adapters

Product Image	Model	Input Plug Type	Output Voltage	Output Current	Output Connector	Color	Safety Approvals
	AQ18A-59A-H	US	5V/9V	3.0A/2.0A	USB C Receptacle	Black	UL
	AQ18A-59CFA-H	US	5V/9V/ 12V/15V	3.0A/2.0A/ 1.5A/1.2A	USB C Receptacle	Black	UL
	AQ18E-59A-H	EU	5V/9V	3.0A/2.0A	USB C Receptacle	Black	CE
	AQ18E-59CFA-H	EU	5V/9V/ 12V/15V	3.0A/2.0A/ 1.5A/1.2A	USB C Receptacle	Black	CE
	AQ18K-59A-H	UK	5V/9V	3.0A/2.0A	USB C Receptacle	Black	UKCA
	AQ18K-59CFA-H	UK	5V/9V/ 12V/15V	3.0A/2.0A/ 1.5A/1.2A	USB C Receptacle	Black	UKCA

18W Interchangeable Blade USB C PD3.0 Wallmount Adapters

Product Image	Model	Input Plug Type	Output Voltage	Output Current	Output Connector	Color	Safety Approvals
	AN18V-59CFAA-H	Interchangeable	5V/9V/ 12V/15V	3.0A/2.0A/ 1.5A/1.2A	USB C Receptacle	Black	UL, CE, UKCA, RCM, PSE, KC, CCC, BIS

27W Fixed Blade USB C PD3.0 Wallmount Adapters

Product Image	Model	Input Plug Type	Output Voltage	Output Current	Output Connector	Color	Safety Approvals
	AQ27A-59A-H	US	5V/9V	3.0A/3.0A	USB C Receptacle	Black	UL
	AQ27A-59CFA-H	US	5V/9V/ 12V/15V	3.0A/3.0A/ 2.25A/1.8A	USB C Receptacle	Black	UL
	AQ27E-59A-H	EU	5V/9V	3.0A/3.0A	USB C Receptacle	Black	CE
	AQ27E-59CFA-H	EU	5V/9V/ 12V/15V	3.0A/3.0A/ 2.25A/1.8A	USB C Receptacle	Black	CE
	AQ27K-59A-H	UK	5V/9V	3.0A/3.0A	USB C Receptacle	Black	UKCA
	AQ27K-59CFA-H	UK	5V/9V/ 12V/15V	3.0A/3.0A/ 2.25A/1.8A	USB C Receptacle	Black	UKCA

45W Fixed Blade USB C PD3.0 Wallmount Adapters

Product Image	Model	Input Plug Type	Output Voltage	Output Current	Output Connector	Color	Safety Approvals
	AA45A-59FKE-R	US	5V/9V/ 15V/20V	3.0A/3.0A/ 3.0A/2.25A	USB C	Black	PENDING
	AA45E-59FKE-R	EU	5V/9V/ 15V/20V	3.0A/3.0A/ 3.0A/2.25A	USB C	Black	PENDING
	AA45K-59FKE-R	UK	5V/9V/ 15V/20V	3.0A/3.0A/ 3.0A/2.25A	USB C	Black	PENDING

60W USB C PD3.0 Desktop Adapters

Product Image	Model	Input Plug Type	Output Voltage	Output Current	Output Connector	Color	Safety Approvals
	AA60M-59FKA-R	IEC 320 C6	5V/9V/ 15V/20V	3.0A/3.0A/ 3.0A/3.0A	USB C	Black	UL, CE, UKCA
	AA60W-59FKA-R	IEC 320 C8	5V/9V/ 15V/20V	3.0A/3.0A/ 3.0A/3.0A	USB C	Black	UL, CE, UKCA
	AQ60W-59FKKA-R	IEC 320 C8	5V/9V/ 15V/20V	3.0A/3.0A/ 3.0A/3.0A	USB C Receptacle	Black	UL, CE, UKCA

65W Fixed Blade USB C PD3.0 Wallmount Adapters

Product Image	Model	Input Plug Type	Output Voltage	Output Current	Output Connector	Color	Safety Approvals
	AA65A-59FKF-R	US	5V/9V/ 15V/20V	3.0A/3.0A/ 3.0A/3.25A	USB C	Black	PENDING
	AA65E-59FKF-R	EU	5V/9V/ 15V/20V	3.0A/3.0A/ 3.0A/3.25A	USB C	Black	PENDING
	AA65K-59FKF-R	UK	5V/9V/ 15V/20V	3.0A/3.0A/ 3.0A/3.25A	USB C	Black	PENDING

65W USB C PD3.0 Desktop Adapters

Product Image	Model	Input Plug Type	Output Voltage	Output Current	Output Connector	Color	Safety Approvals
	AA65M-59FKA-R	IEC 320 C6	5V/9V/ 15V/20V	3.0A/3.0A/ 3.0A/3.25A	USB C	Black	UL, CE, UKCA
	AA65W-59FKA-R	IEC 320 C8	5V/9V/ 15V/20V	3.0A/3.0A/ 3.0A/3.25A	USB C	Black	UL, CE, UKCA

5W Medical Fixed Blade USB A Wallmount Adapters

Product Image	Model	Input Plug Type	Output Voltage	Output Current	Output Connector	Color	Means of Protection	Safety Approvals
	MQ05A-050A-H	US	5V	1.0A	USB A	Black	MOOP	ANSI/AAMI ES 60601-1, IEC 60601-1, IEC60601-1-II
	MQ05A-050AW-H	US	5V	1.0A	USB A	White	MOOP	ANSI/AAMI ES 60601-1, IEC 60601-1, IEC60601-1-II
	MQ05A-050B-H	US	5V	1.0A	USB A	Black	MOOP	ANSI/AAMI ES 60601-1, IEC 60601-1, IEC60601-1-II
	MQ05A-050BW-H	US	5V	1.0A	USB A	White	MOOP	ANSI/AAMI ES 60601-1, IEC 60601-1, IEC60601-1-II
	MQ05E-050B-H	EU	5V	1.0A	USB A	Black	MOOP	IEC 60601-1, IEC60601-1-II
	MQ05E-050BW-H	EU	5V	1.0A	USB A	White	MOOP	IEC 60601-1, IEC60601-1-II
	MQ05K-050B-H	UK	5V	1.0A	USB A	Black	MOOP	IEC 60601-1, IEC60601-1-II
	MQ05K-050BW-H	UK	5V	1.0A	USB A	White	MOOP	IEC 60601-1, IEC60601-1-II
	MQ05S-050B-H	AU	5V	1.0A	USB A	Black	MOOP	AS/NZS 62368-1, IEC 60601-1, IEC60601-1-II
	MQ05S-050BW-H	AU	5V	1.0A	USB A	White	MOOP	AS/NZS 62368-1, IEC 60601-1, IEC60601-1-II

9W Medical Interchangeable Blade Wallmount Adapters

Product Image	Model	Input Plug Type	Output Voltage	Output Current	Output Connector	Color	Means of Protection	Safety Approvals
	PMA09R-060A-R	Interchangeable	6V	1.5A	2.1 x 5.5 x 10mm	Black	MOPP	ANSI/AAMI ES 60601-1, IEC 60601-1, IEC60601-1-II
	PMA09R-090A-R	Interchangeable	9V	1.0A	2.1 x 5.5 x 10mm	Black	MOPP	ANSI/AAMI ES 60601-1, IEC 60601-1, IEC60601-1-II


10W Medical Interchangeable Blade Wallmount Adapters

Product Image	Model	Input Plug Type	Output Voltage	Output Current	Output Connector	Color	Means of Protection	Safety Approvals
	PMA10R-050A-R	Interchangeable	5V	2.0A	2.1 x 5.5 x 10mm	Black	MOPP	ANSI/AAMI ES 60601-1, IEC 60601-1, IEC60601-1-11
	PMA10R-050AW-R	Interchangeable	5V	2.0A	2.1 x 5.5 x 10mm	White	MOPP	ANSI/AAMI ES 60601-1, IEC 60601-1, IEC60601-1-11

18W Medical Fixed Blade Wallmount Adapters

Product Image	Model	Input Plug Type	Output Voltage	Output Current	Output Connector	Color	Means of Protection	Safety Approvals
	PMA18A-120PHW-R	US	12V	1.5A	2.1 x 5.5 x 10mm	White	MOPP	ANSI/AAMI ES 60601-1, IEC 60601-1, IEC60601-1-11
	PMA18E-120PHW-R	EU	12V	1.5A	2.1 x 5.5 x 10mm	White	MOPP	IEC 60601-1, IEC60601-1-11
	PMA18K-120PHW-R	UK	12V	1.5A	2.1 x 5.5 x 10mm	White	MOPP	IEC 60601-1, IEC60601-1-11
	PMA18S-120PHW-R	AU	12V	1.5A	2.1 x 5.5 x 10mm	White	MOPP	IEC 60601-1, IEC60601-1-11
	PMA18A-240-R	US	24V	0.75A	2.1 x 5.5 x 10mm	White	MOPP	ANSI/AAMI ES 60601-1, IEC 60601-1, IEC60601-1-11
	PMA18E-240-R	EU	24V	0.75A	2.1 x 5.5 x 10mm	White	MOPP	IEC 60601-1, IEC60601-1-11
	PMA18K-240-R	UK	24V	0.75A	2.1 x 5.5 x 10mm	White	MOPP	IEC 60601-1, IEC60601-1-11

60W to 65W 2 x 4" Medical Open-Frame Power Supplies

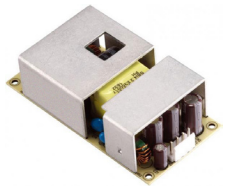Product Image	Model	Output Voltage	Output Current	Size	Safety Approvals
	PML065-120	12V	5.0A	2 x 4 x 1.12"	ANSI/AAMI ES 60601-1, IEC 60601-1
	PML065-150	15V	4.34A	2 x 4 x 1.12"	ANSI/AAMI ES 60601-1, IEC 60601-1
	PML065-180	18V	3.62A	2 x 4 x 1.12"	ANSI/AAMI ES 60601-1, IEC 60601-1
	PML065-190	19V	3.43A	2 x 4 x 1.12"	ANSI/AAMI ES 60601-1, IEC 60601-1
	PML065-240	24V	2.71A	2 x 4 x 1.12"	ANSI/AAMI ES 60601-1, IEC 60601-1
	PML065-480	48V	1.36A	2 x 4 x 1.12"	ANSI/AAMI ES 60601-1, IEC 60601-1

150W Convection Cooled Industrial Open-Frame Power Supply

Product Image	Model	Output Voltage	Output Current	Size	Safety Approvals
	BI150-240A-4	24V	6.3A	2.95 x 6.3 x 1.46"	UL 62368-1 IEC 62368-1

240W Convection Cooled Industrial Open-Frame Power Supply

Product Image	Model	Output Voltage	Output Current	Size	Safety Approvals
	BI240-240A-4	24V	10.A	3.3 x 7.09 x 1.65"	UL 62368-1 IEC 62368-1



Phihong Technology Co., Ltd
Taiwan Headquarters

No. 568, Fusing 3rd Rd
Gueishan District
Taoyuan City (33383), Taiwan
Tel: +886-3-3277288
Fax: +886-3-3277622
phsales@phihong.com.tw
www.phihong.com.tw



Phihong USA
Corporate Office

47800 Fremont Blvd
Fremont, CA 94538, USA
Tel: +1-510-445-0100
Fax: +1-510-445-1678
usasales@phihongusa.com
www.phihong.com



Contact your local Phihong sales office today to learn more:

North America - usasales@phihongusa.com
Asia - phsales@phihong.com.tw