


| EXACT12 WITH CABLE


EXACT 12 distribution boxes offer solutions for an array of applications.

Space saving and maintenance friendly, they offer up to a 40% cost reduction compared to junction boxes and can be installed in less than a quarter of the time.

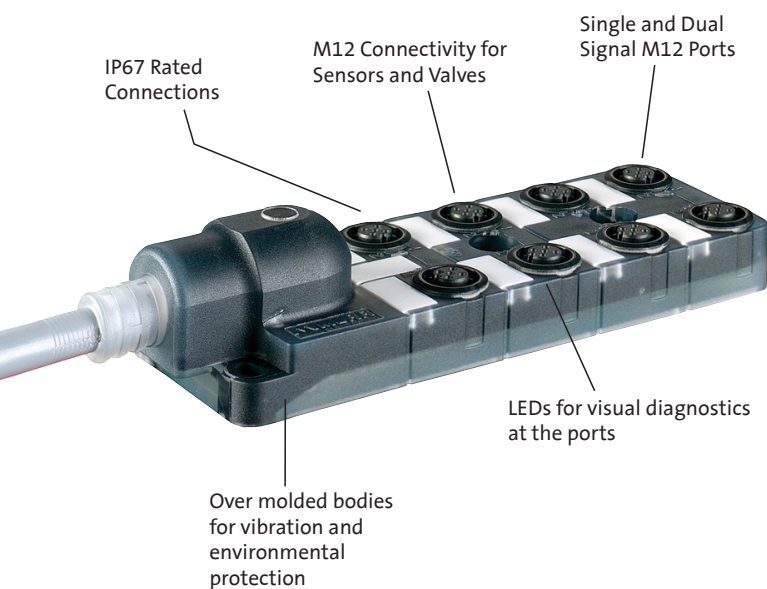


| PIN ASSIGNMENTS

| 4-POLE & 5-POLE VERSIONS

 

1. Brown (+24)
3. Blue (-)
4. Black Signal 1
5. Green/Yellow - Earth Ground

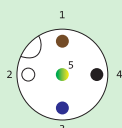

1. Brown (+24)
2. White Signal 2
3. Blue (-)
4. Black Signal 1
5. Green/Yellow - Earth Ground

| SIGNAL SELECTION

- PNP or NPN
- With or without LED
- 4 or 8 Port
- 24V DC or 125V AC/DC

MURRELEKTRONIK Related Products

IDC



M12



Exact8



Receptacles



T-Coupler



| INTEGRATED CABLE



			4-port		8-port	
LED	Cable	Length	4-pole (1 Signal)	5-pole (2 Signal)	4-pole (1 Signal)	5-pole (2 Signal)
PNP	PUR/PVC	3m	8000-84410-3330300	8000-84510-3630300	8000-88410-3620300	8000-88510-3980300
		5m	8000-84410-3330500	8000-84510-3630500	8000-88410-3620500	8000-88510-3980500
		10m	8000-84410-3331000	8000-84510-3631000	8000-88410-3621000	8000-88510-3981000
	PUR	5m		8000-84510-4480500	8000-88410-4470500	8000-88510-4520500
		10m		8000-84510-4481000	8000-88410-4471000	8000-88510-4521000
NPN	PUR/PVC	5m	8000-84411-3330500	8000-84511-3630500	8000-88411-3620500	8000-88511-3980500
		10m	8000-84411-3331000	8000-84511-3631000	8000-88411-3621000	8000-88511-3981000
	PUR	5m		8000-84511-4480500	8000-88411-4470500	8000-88511-4520500
		10m		8000-84511-4481000	8000-88411-4471000	8000-88511-4521000
w/o LED (125V AC/DC)	PUR/PVC	5m	8000-84412-3330500	8000-84512-3630500	8000-88412-3620500	8000-88512-3980500
		10m	8000-84412-3331000	8000-84512-3631000	8000-88412-3621000	8000-88512-3981000
	PUR	5m		8000-84512-4480500	8000-88412-4470500	8000-88512-4520500
		10m		8000-84512-4481000	8000-88412-4471000	8000-88512-4521000

| PLUGGABLE - BASE MODULE



	4-port		8-port	
LED	4-pole (1 Signal)	5-pole (2 Signal)	4-pole (1 Signal)	5-pole (2 Signal)
PNP	8000-84400-0000000	8000-84500-0000000	8000-88400-0000000	8000-88500-0000000
PNP w/Cap	8000-84450-0000000	8000-84550-0000000	8000-88450-0000000	8000-88550-0000000
NPN	8000-84401-0000000	8000-84501-0000000	8000-88401-0000000	8000-88501-0000000
w/o LED	8000-84402-0000000	8000-84502-0000000	8000-88402-0000000	8000-88502-0000000

| PLUGGABLE - CAP MODULE



			4-port		8-port	
Terminal	Cable	Length	4-pole (1 Signal)	5-pole (2 Signal)	4-pole (1 Signal)	5-pole (2 Signal)
Spring	Without		8000-88549-0000000			
Screw	Without		8000-88559-0000000			
	PUR/PVC	3m	8000-84459-3330300	8000-84559-3630300	8000-88459-3620300	8000-88559-3980300
		5m	8000-84459-3330500	8000-84559-3630500	8000-88459-3620500	8000-88559-3980500
		10m	8000-84459-3331000	8000-84559-3631000	8000-88459-3621000	8000-88559-3981000
	PUR	3m		8000-84559-4480300	8000-88459-4470300	8000-88559-4520300
		5m		8000-84559-4480500	8000-88459-4470500	8000-88559-4520500
		10m		8000-84559-4481000	8000-88459-4471000	8000-88559-4521000