


Discrete LED Package

ISO 9001:2015 | IATF 16949:2016 | ISO 14001:2015

American Bright offers one of the most comprehensive product families of LED packages including SMT, LED lamps, PLCC, segment and dot matrix display. Our bar-setting innovation and adventurous approach to seek new opportunities make us the first choice for the supply of creative, cost-effective indicator and lighting solutions.


THROUGH HOLE LED

- Emitting Color: White / Blue / Green / Yellow-Green / Yellow (Amber) / Orange / Red
- Lens Shape: Round / Cylindrical / Rectangular / Oval / Tower / Triangular
- Lens Appearance: Color Diffused / White Diffused / Water Clear / Color Transparent / Hi-Efficient Red Diffused / Hi-Efficient Red Transparent
- Binning Option:
 - » -AT (Intensity binning)
 - » -AA (Intensity & Color binning)
 - » -AV (Intensity & Vf binning)
 - » -AA-AV (Intensity & Color & Vf binning)

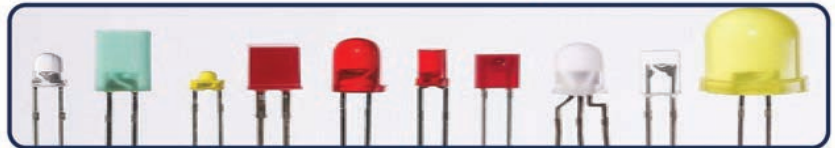

SMT CHIP LED

- Emitting Color: White / Blue / Green / Yellow-Green / Yellow (Amber) / Orange / Red
- Color Option: Mono Color / Bi-Color / Tri-Color
- Package Type: 0402 / 0404 / 0603 / 0605 / 0805 / 1204 / 1206 / 1210 / Right Angle / Reverse Mount

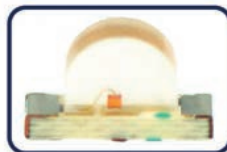

PLCC/ EMC/ Ceramic-based LED

- Emitting Color: White / Blue / Green / Yellow / Amber / Orange / Red
- Color Option: Mono Color / Bi-Color / RGW / RGBW / RGB with IC built-In
- Package Type:
 - » Top View: 2016 / 3020 / 3528 / 5050 / 3014 / 2835 / 3030 / 5630
 - » Side View: 4010 / 4020
 - » High Power: 3535 / 5050

