


Features

- Onboard 12th Gen Intel® Core™ i7/i5/i3 processors
- 2x DDR4-3200 SO-DIMM sockets, Max. 64GB
- Onboard 2.5 GbE
- Supports 3x independent displays from HDMI / DP / VGA / LVDS or eDP
- 4x USB 3.2, 8x USB 2.0, 2x SATA III, 2x COM
- 1x PCI-E(x16), 1x PCI-E(x4), 4x PCI-E(x1) to carrier board
- Digital I/O, TPM (2.0), Watchdog timer

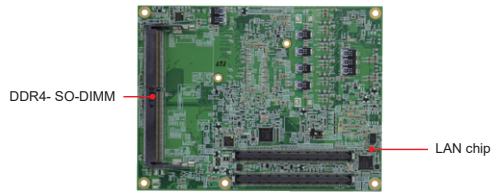

Specifications

CPU	BGA1744 for 12th Gen Intel® Core™ i7/i5/i3 processors
Memory	2x DDR4-3200 SO-DIMM sockets, Max. 64GB, ECC compatible
BIOS	AMI
Watchdog Timer	256 levels
H/W Monitor	Yes
Storage Device Interface	N/A
Expansion Slots	1x PCI-E(x16), 1x PCI-E(x4), 4x PCI-E(x1) to carrier board
Graphics Controller	12th Gen Intel® Core™ P-series processor integrated graphics
Video Output	HDMI, DisplayPort, VGA, LVDS or eDP on carrier board
Ethernet	Intel® I226LM 2.5 GbE RJ45 on carrier board
I/O Chip	Fintek F81804U-I onboard
Serial Port	2x COM ports (Tx/Rx only)
USB 2.0	8x USB2.0 via carrier board
USB 3.X	4x USB3.2 (10bps) via carrier board
Serial ATA	2x SATA III via carrier board
Audio	Built-in HD Audio controller
TPM	TPM (2.0)
Others	Digital I/O (4-in/4-out) , Watchdog timer
Dimensions (L X W)	125mm x 95mm (4.92" x 3.74")
Power Consumption	TBD
Operating Temperature	0°C~60°C (32°F~140°F)
Storage Temperature	-20°C~80°C (-4°F~176°F)
Relative Humidity	90% (non-condensing @60)

Ordering Information

ET980LV-I7U	COM Express (Type 6) CPU Module w/ Intel® Core™ i7-1265UE onboard, support LVDS
ET980LV-I7P	COM Express (Type 6) CPU Module w/ Intel® Core™ i7-1270PE onboard, support LVDS
ET980LV-I5U	COM Express (Type 6) CPU Module w/ Intel® Core™ i5-1245UE onboard, support LVDS
ET980-I5U	COM Express (Type 6) CPU Module w/ Intel® Core™ i5-1245UE onboard, support eDP
ET980LV-I5P	COM Express (Type 6) CPU Module w/ Intel® Core™ i5-1250PE onboard, support LVDS
ET980LV-I3P	COM Express (Type 6) CPU Module w/ Intel® Core™ i3-1220PE onboard, support LVDS

Dimensions and Drawing

