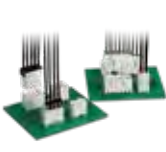
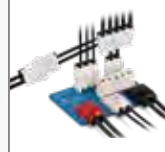


Features

		DF33C	DF63	DF63W	DF63SF	DF22	DF60
Series							
Pitch		3.3mm	3.96mm 7.92mm ^{*1}	3.96×4.4mm	3.96mm 7.92mm ^{*1}	7.92mm	10.16mm
No. of Pos.	Single-row	2, 3, 4, 5, 6	1, 2, 3, 4, 5, 6	2	2, 3	1, 2, 3, 4, 5	1, 2, 3, 4, 5, 6
	Double-row	4, 6, 8, 10, 12	—	3, 4	—	4 (In-line Type Only)	—
Connection Type	Straight	●	●	—	●	●	●
	Right Angle	—	●	—	—	● (2, 3, 4, 5pos. Only)	●
	In-line	—	●	●	—	● (1, 2, 3pos. Only)	●
Rating	Rated Current	5A Max.	15A Max.	14A Max.	12A Max.	30A Max.	65A Max. ^{*2}
	Rated Voltage	500V AC/DC	630V AC/DC	630V AC/DC	630V AC/DC	1,000V AC/DC	1,000V AC/DC
	Operating Temperature Range	-35 to +85℃	-55 to +105℃	-40 to +105℃	-55 to +105℃	-55 to +85℃	-55 to +105℃
	Storage Temperature Range	-10 to +60℃	-10 to +60℃	-10 to +60℃	-10 to +60℃	-10 to +60℃	-10 to +60℃
Safety Standard	UL	—	●	●	●	●	●
	C-UL	—	●	●	●	●	●
	TÜV	—	●	●	●	●	●
	Glow Wire Capable	●	—	●	●	●	●
Additional Features	Mating Guide Key	●	●	—	—	●	●
	Resin Sealing	●	●	—	—	●	—
	Multi-point Contact	—	●	●	●	●	●
	Center Lock	●	●	●	●	●	●
	Waterproof	—	—	●	—	—	—
	Vertical-mating with Lateral Cable Design	—	—	—	●	—	—
Applicable Cable		20 - 22 AWG	16 - 22 AWG	16 - 22 AWG	16 - 18 AWG	10 - 16 AWG	8 - 12 AWG

*1 : Without Pins *2 : UL Standard Only