


EUA1200

1080p Full HD USB Camera



Features

- 1080p progressive scan CMOS sensor
- 3.6mm / 6mm fixed lens (selectable)
- Supports USB2.0 OTG
- Support free driver: USB Video Class (UVC)
- Support Windows and Linux

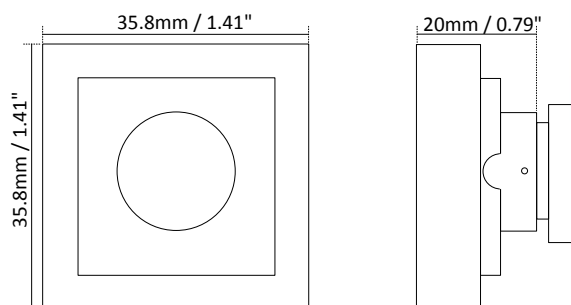

Specifications

Model No.	EUA1200		
Pickup Device	1080p CMOS sensor	Focus Range	30CM -∞
System Format	60Hz / 50Hz	S/N Ratio	38.6 dB
Effective Pixels	1920 (H) x 1080 (V)	Power Source	5VDC
Scanning System	Progressive Scan	Operating Temp.	0°C ~ 50°C / 32°F ~ 122°F
Sensitivity	23k e ⁻ /lux.sec	Humidity	Less than 95%
Video Format	MJPEG / YUV2	Dimensions (W x H x D)	35.8 x 35.8 x 20mm / 1.41" x 1.41" x 0.79" (without bracket and lens)
Frame Rate	MJPEG: 1920x1080/30FPS ; 1280x720/30FPS; 640x480/30FPS YUV2: 1920x1080/5FPS ; 1280x720/8FPS ; 640x480/30FPS	OS	Win7 / Win8 / Win10 / Win11 / Linux2.6 or Above (Linux requires driver)
Lens Type	3.6mm / 6mm fixed lens, F2.0	Free Driver	USB Video Class (UVC)
FOV (H x V x D)	3.6mm: 87.4° x 47° x 104° 6mm: 48° x 29° x 63°	Cable Length	1m / 3.28ft.
Interface	USB 2.0 OTG	Weight	75g / 0.165lb
White Balance	Auto	Certificates	CE, FCC, RoHS
Exposure	Auto		

*All images presented in this document are for example only. Product models may vary in different countries. Please visit EverFocus regional Websites for detailed ordering information.

*Information contained in this document is subject to change without notice.

Find Out More At:

EverFocus Taiwan HQ:
TEL: +886 2 2662 2338
www.everfocus.com.tw
marketing@everfocus.com.tw

EverFocus USA - California:
TEL: +1 626 844 8888
www.everfocus.com
sales@everfocus.com

International Branch Offices:
China, Japan