


Sample Kit Contents

KEMET Part Number	Series	Thickness	Tape Thickness	Magnetic Permeability	Effective Frequency	Resistance	Specific Gravity	Surface Resistivity
		mm	mm	at 13.56 MHz	Mhz	MOhms	Typical	Ω/sq. Typical
RM4A(01)-185X70T0800	RM4A	0.1	0.03	50	13.56 MHz	10 MOhms	3.6	1.0 x 10 ⁷
RM4A(02)-185X70T0800	RM4A	0.2	0.03	50	13.56 MHz	10 MOhms	3.6	1.0 x 10 ⁷
RM4A(025)-185X70T0800	RM4A	0.25	0.03	50	13.56 MHz	10 MOhms	3.6	1.0 x 10 ⁷
RM4A(03)-185X70T0800	RM4A	0.3	0.03	50	13.56 MHz	10 MOhms	3.6	1.0 x 10 ⁷
M4(100)-185X70T0800	M4	0.1	0.03	40	13.56 MHz	10 MOhms	3.1	1.0 x 10 ⁷
M4(200)-185X70T0800	M4	0.2	0.03	40	13.56 MHz	10 MOhms	3.1	1.0 x 10 ⁷
M4(300)-185X70T0800	M4	0.3	0.03	40	13.56 MHz	10 MOhms	3.1	1.0 x 10 ⁷

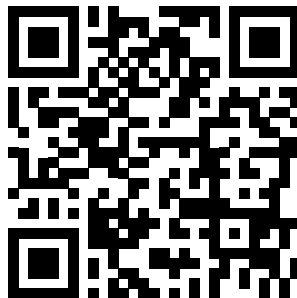

www.kemet.com/FlexSuppressorRFID