

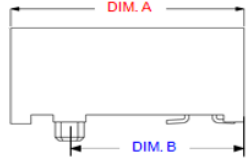



- CN120 Series QSFP Connectors & Mechanical units Supports 100 ~ 400Gbps Ethernet
- Compliant with SFF-8436 (QSFP+), SFF-8662 (QSFP28 Style A), SFF-8672 (QSFP28 Style B), SFF TA-1027(QSFP112)
- Transmission Speed: 56~ 112Gbps
- Style A & B Cage Accessories Available
- Supports 100 ~ 400 Gbe Interface & Infiniband EDR/FDR/QDR/HDR/NDR

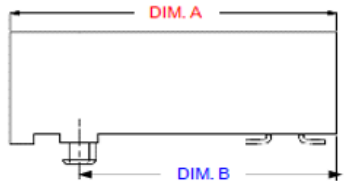

Connector P/N	Transmission Speed	DIM.A(mm)	DIM.B(mm)	Connector compatible with	Cage compatible with	Drawing
CN120-038-0001	56Gbps	11.50	8.6	SFF-8672 Specification for QSFP+ 4X 28 Gb/s Connector (Style B)	SFF-8683 QSFP+ Cage	
CN120-038-2001	112Gbps	13.69	10.79	SFF-8662 Specification for QSFP+ 4X 28 Gb/s Connector (Style A)	SFF-8663 QSFP+ 28 Gb/s Cage (Style A)	
CN120-038-3002	112Gbps	14.69	11.79	SFF TA-1027 QSFP2 Connector, Cage, & Module Specification		

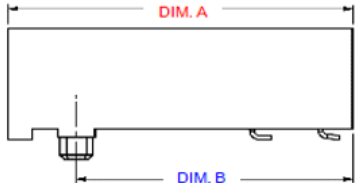

Insertion Loss

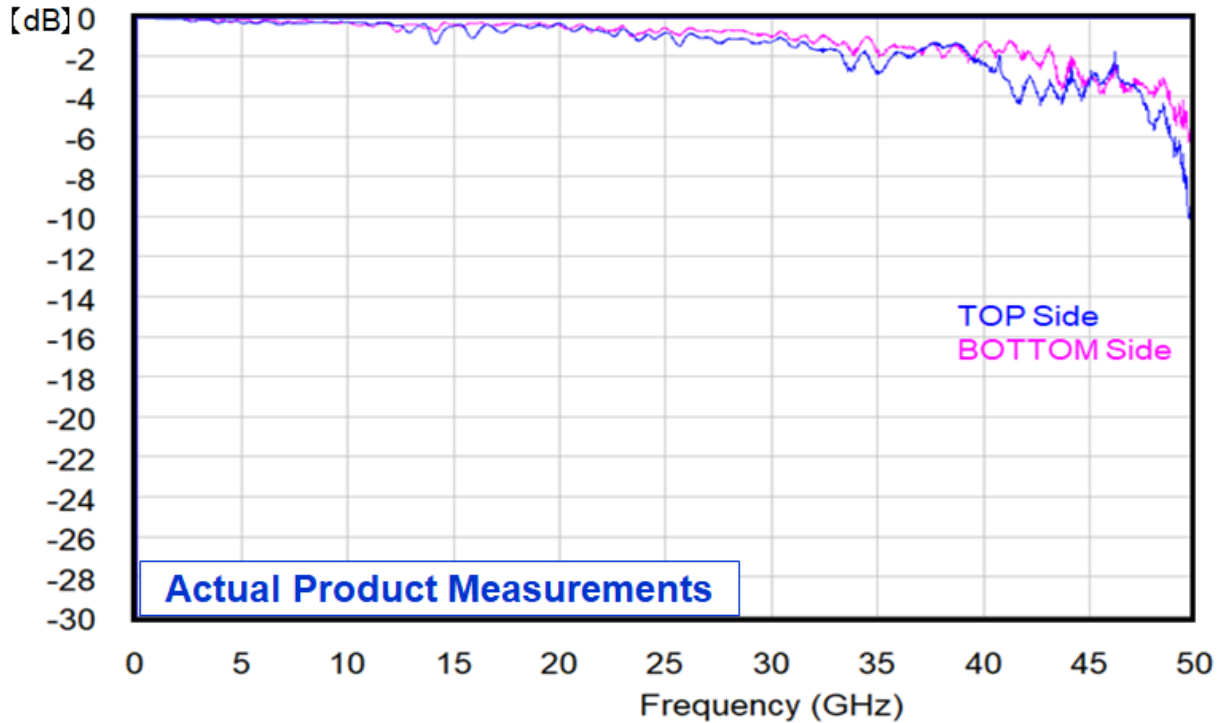

Connector P/N	Port	Applicable Cage Product	Cage Type	Heat Sink Option (PCB Base to HS Top)	Light Pipe (L)
CN120-038-0001	1X1	CNU120A-10-**-**	Bezel	PCI (12.88mm) SAN (15. 10mm) Networking (22.10mm)	No Light Pipe Single Light Pipe Dual Light Pipes Quad Light Pipes
	1X1	CNU120A-11****-0001	EMI Spring Finger		
	1X2	CNU120A-12****-0001			
	1X1	CNU120A-11****-0002	EMI Elastomeric Gasket		
	1X2	CNU120A-12****-0002			
CN120-038-2001 CN120-038-3002	1X1	CNU120A-11****-0001-A	EMI Spring Finger		
	1X2	CNU120A-12****-0001-A			

