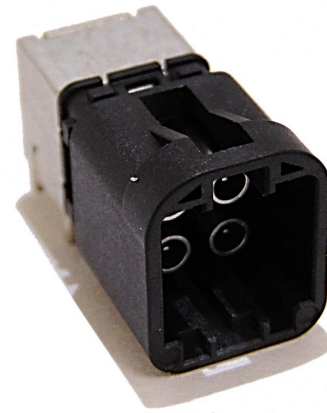


Mini FAKRA Connectors

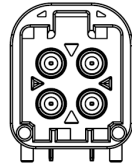
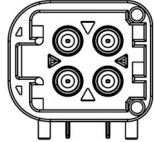
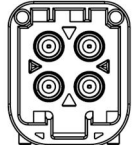
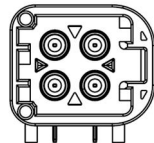
Y-MFC Series

Product Overview

- Supports 5 Key Config.: **A, B, C, E, F**
- Miniaturized FAKRA I/O solution to save critical design space
- Offering 4 different mating orientations
- Product SPEC data:
 - Operating Frequency: Up to 9 GHz
 - Rated Voltage: 60V DC
 - Impedance: 50 Ω
 - Operating Temperature: -40°C ~ +105°C



Yamaichi Y-MFC Mini FAKRA Connector

Part Number	Key Code	Color Code	Orientation
Y-MFC-4PT-A*-VL-REDC	A	JET BLACK	 * = Nothing – Standard Orientation
Y-MFC-4PT-B*-VL-REDC	B	PURE WHITE	 * = 1 – 90° Orientation
Y-MFC-4PT-C*-VL-REDC	C	LIGHT BLUE	 * = 2 – 180° Orientation
Y-MFC-4PT-E*-VL-REDC	E	MAY GREEN	 * = 3 – 270° Orientation
Y-MFC-4PT-F*-VL-REDC	F	NUT BROWN	