

High Speed Copper Cables

Product Features:


- Ideal for Data center, high-end servers, and wiring closet switch
- Available Interface: **QSFP28, SFP28, QSFP28-4xSFP28, QSFP28-2xQSFP28**
- Transmission Speed: 25 to 28 Gbps / Lane.
- Supports **100-Gigabit Ethernet (100GBASE-CR4)** standards and complies with **IEEE 802.3bj** and **EDR** requirements



CAU120-038 QSFP28 Cable

Product Performance Overview


Example: CAU120 QSFP28 3 M/AWG26 Cable tested with IEEE 802.3bj 100GBASE-CR4 requirements

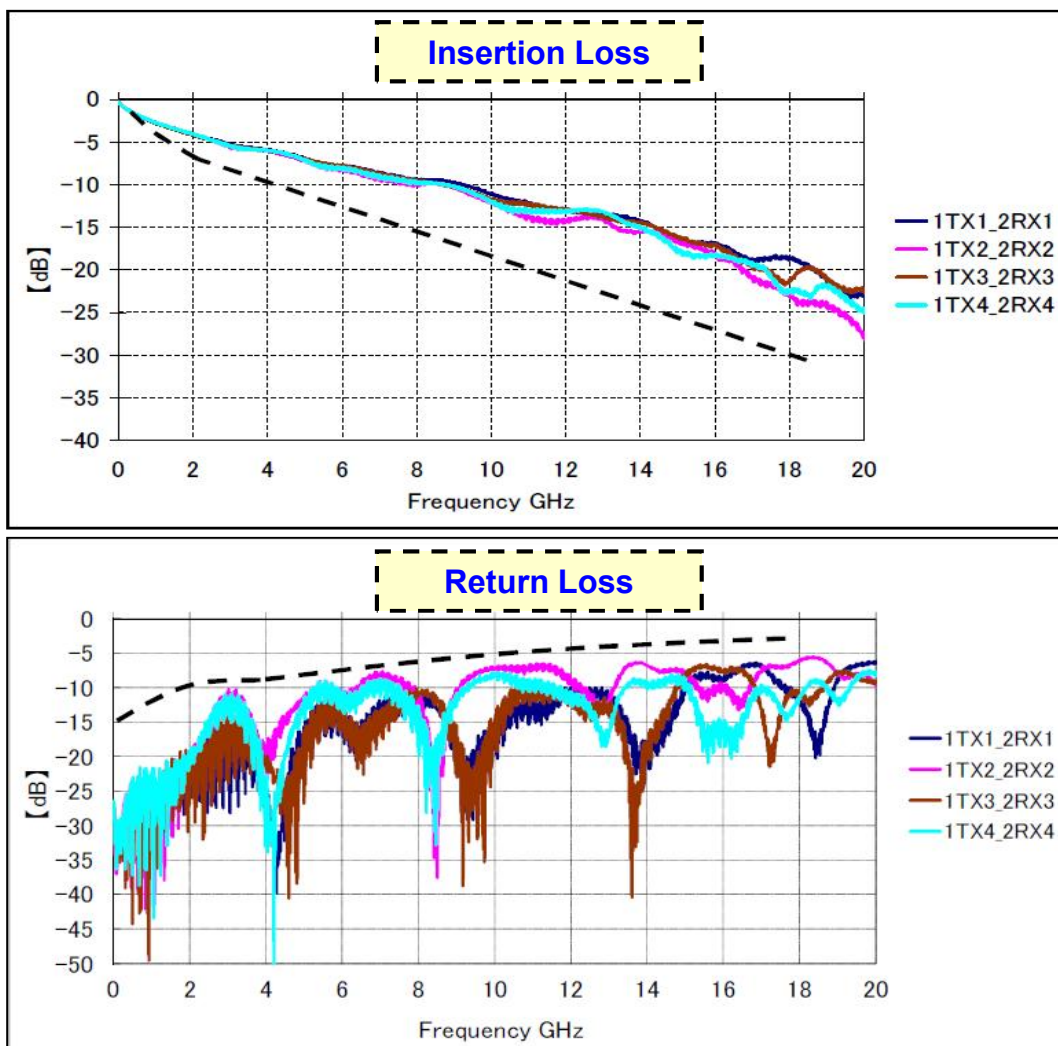


High Speed Copper Cables

Cable Product Configuration Index


CAU120-038 QSFP28-QSFP28 Series

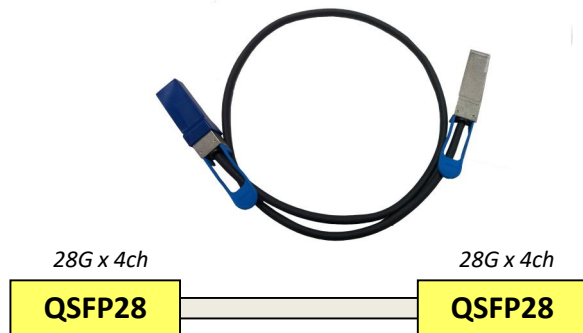


CAU017-0001 SFP28 Series

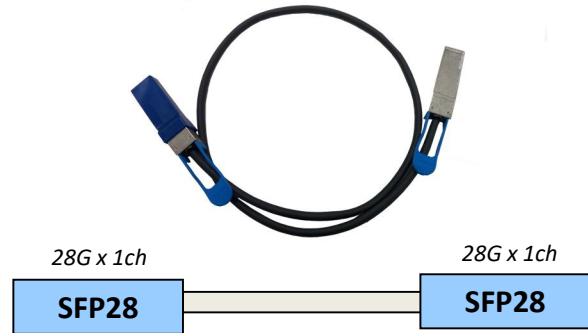

CAU016 QSFP28-4xSFP28 Series

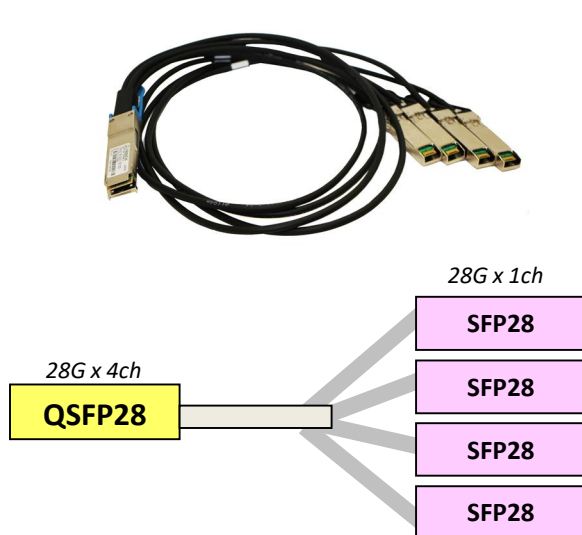

CAU019-0001 QSFP28-2xQSFP28 Series

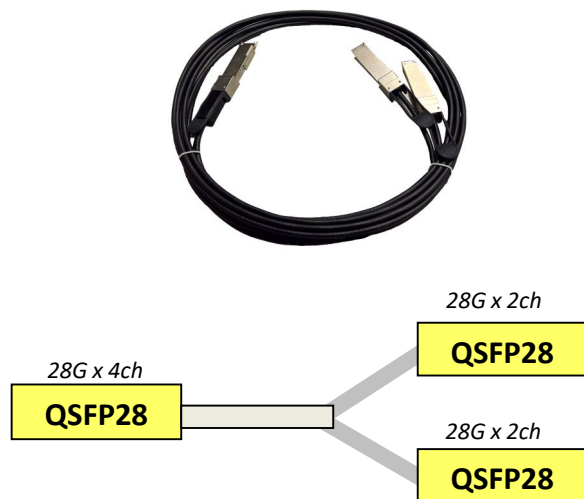

Complete Cable Product Line-Up

Part Number	Cable Type	Support Cable size	Support Cable Length
CAU120-038 Series	QSFP28-QSFP28 Passive Cu Cable	AWG 30 AWG 26	0.5 meter – 5.0 meters
CAU016-0001 Series	QSFP28-4xSFP28 Passive Cu Cable	AWG 30 AWG 26	1.0 meter – 5.0 meters
CAU019-0001 Series	QSFP28-2xQSFP28 Passive Cu Cable	AWG 30 AWG 26	1.0 meter – 5.0 meters
CAU017-0001 Series	SFP28-SFP28 Passive Cu Cable	AWG 30 AWG 26	0.5 meter – 5.0 meters