


# SMA Extender Assembly — IP67, IP68 & IP69K

## key features

- IP67, IP68 & IP69K rated
- IP rated - mated and unmated, front face & cable entry
- Gold plated brass, SUS304 & SUS316 stainless steel options

The CAB606, 613, and 616 series of SMA extender cables meet IP67, IP68, and IP69K standards at the interface and cable side - mated and unmated. This patented solution allows for a reliable fit-and-forget installation, preventing liquid and dust ingress without extra protection. Offered in SMA jack-jack, jack-plug, and plug-plug configurations, these cables support frequencies from DC to 6GHz and come in different lengths for your needs. Stainless steel variants are also available for harsh environments.

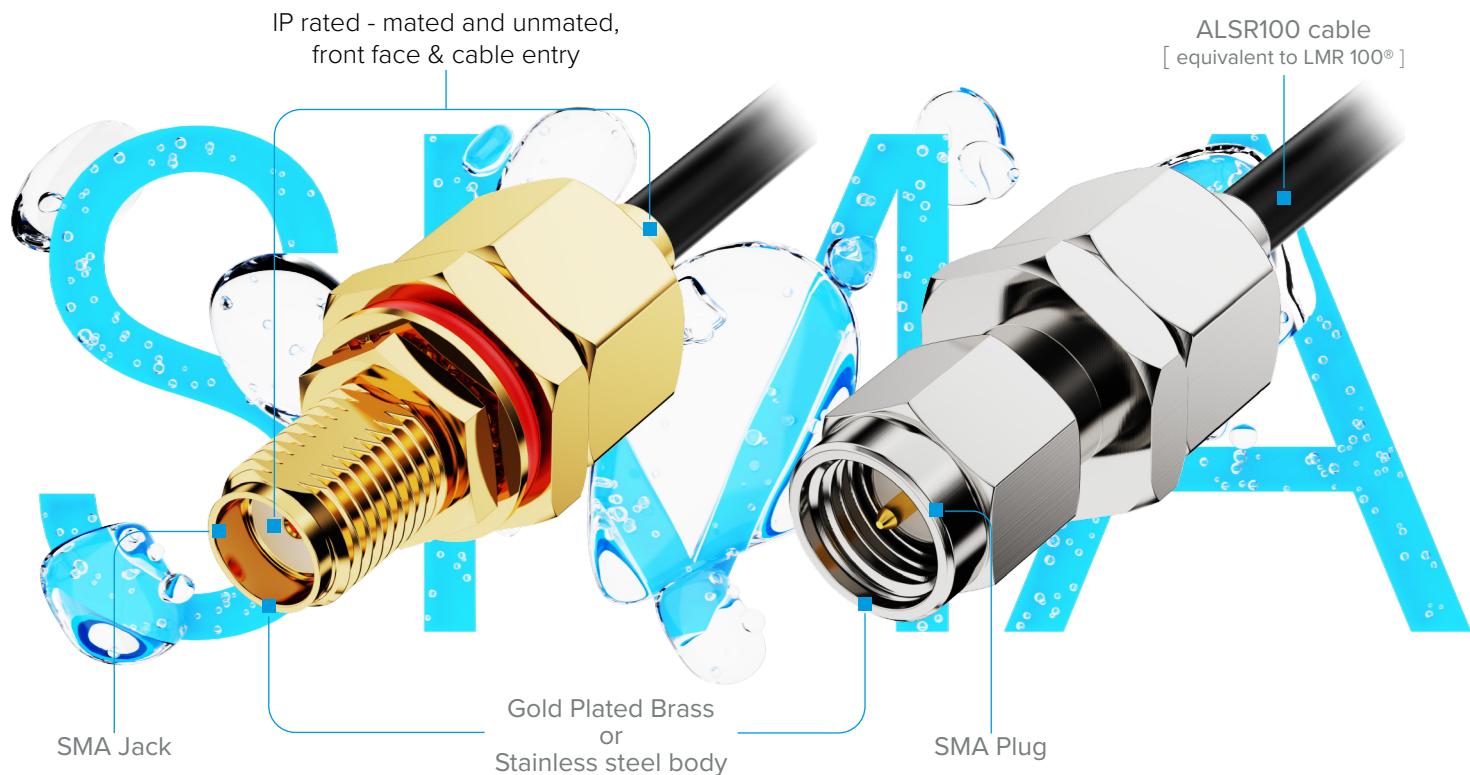

## Product Specifications

Interface	Frequency	Impedance	IP Rating	Temp Range	Cable Type
SMA jack or plug	DC to 6GHz	50Ω	IP67, IP68, IP69K	-40°C to +85°C	ALSR100 - Black*

\*equivalent to LMR 100®

## Application

