





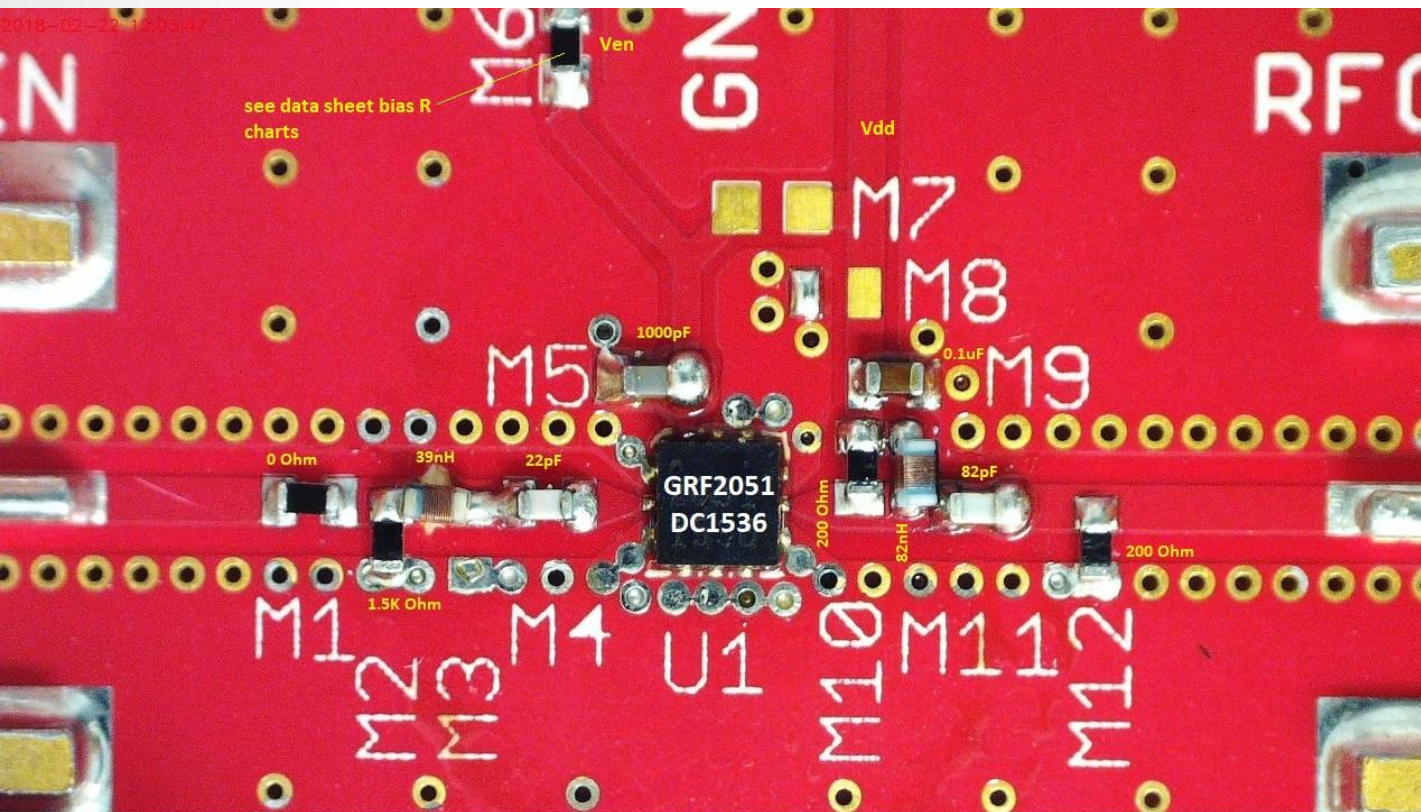


GRF2051 (350 - 450 MHz)


GRF2051 Schematic:



GRF2051 Response:

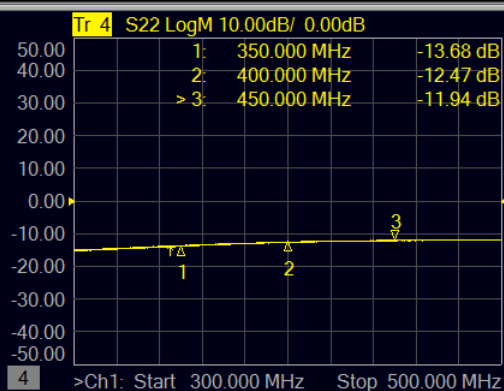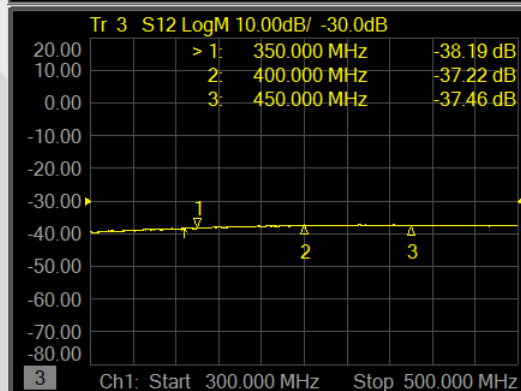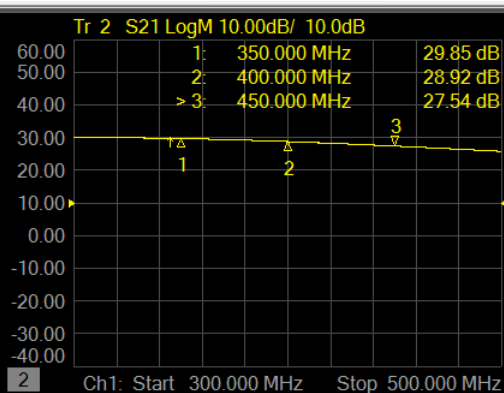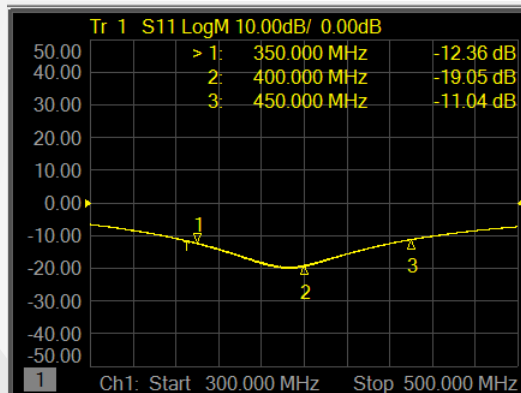

GRF2051 Stability Mu Factor:

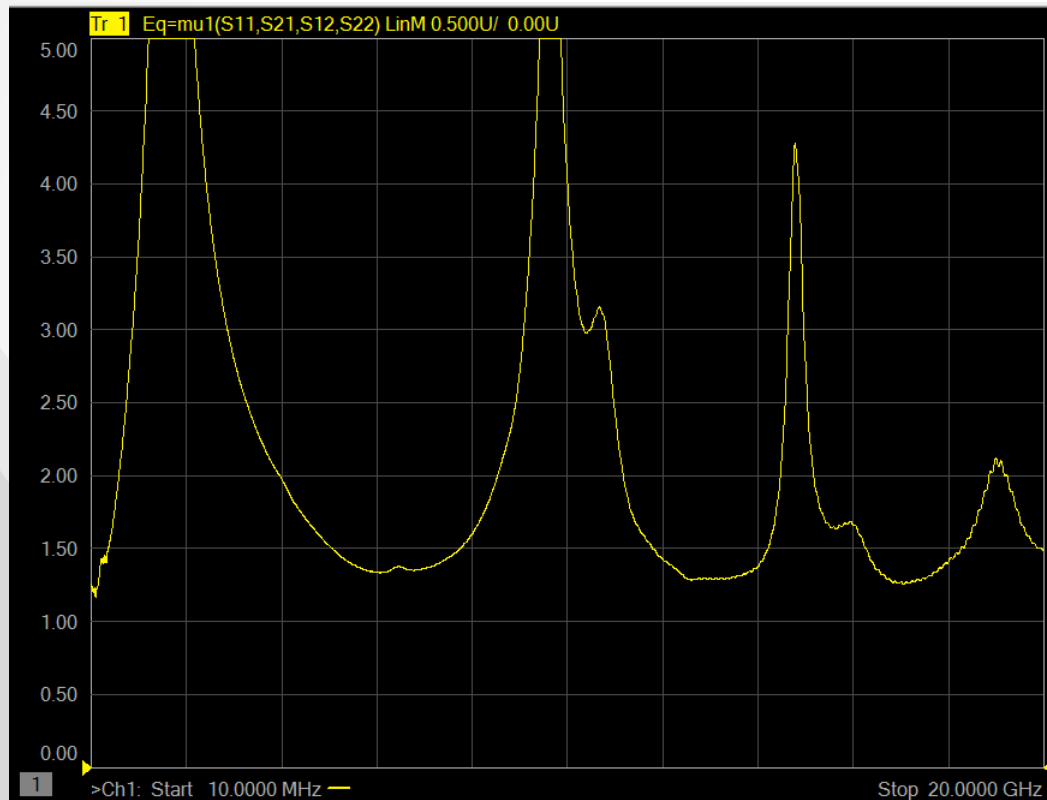

GRF2051 Data:

Descriptor	Freq MHz	Vdd	Iddq mA	Pout/Ptone dBm	Gain dB	IIP3 dBm	OIP3 dBm	IP1dB dBm	OP1dB dBm	EVB NF
GRF2051 3.3V/50mA	350	3.3	49.3	0	29.2936	-1.4926	27.801	-12.7	15.381	0.79
GRF2051 3.3V/50mA	400	3.3	49.3	0	28.6056	0.47095	29.0765	-11	16.527	0.84
GRF2051 3.3V/50mA	450	3.3	49.3	0	27.2125	3.6625	30.875	-8.9	17.251	0.88



Jeff Broxson

Vice President - Sales

Phone (336) 339-9314

jbroxson@guerrilla-rf.com

Alan Ake

Vice President - Applications/Technical Marketing

Phone (336) 708-4581

aake@guerrilla-rf.com

Guerrilla RF

1196 Pleasant Ridge Road, Suite 5
Greensboro, NC 27409

Phone: (336) 510-7840

www.guerrilla-rf.com