

Pluggable Type Terminal Block


New Products



HU Series

Electrical

Product Model	HU
Pitch	5.08mm
Poles	2P~8P
Rated Parameters	cULus
Voltage Rating	300V / 300V
Current Rating	15A / 10A
Solid Wire	12-26 AWG
Stranded Wire	16-26 AWG
Torque	0.6Nm
Screw	M3
Withstanding Voltage	1.6KV
Operating Temperature	-40°C to +115°C
Safety Approval	cULus

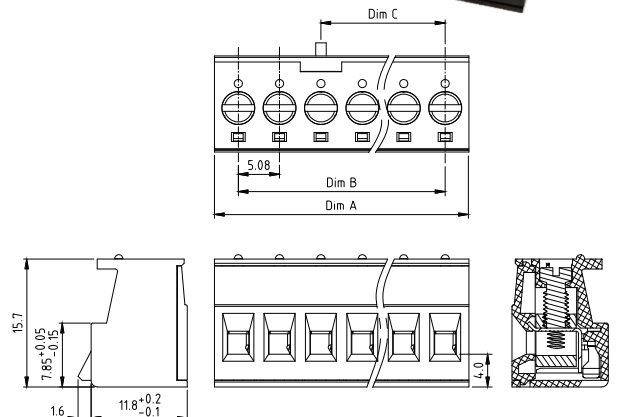


PF Series



Electrical




Product Model	PF
Pitch	5.08mm
Poles	2P~8P
Rated Parameters	cULus
Voltage Rating	300V / 300V
Current Rating	15A / 10A
Withstanding Voltage	1.6KV
Operating Temperature	-40°C to +120°C
Safety Approval	

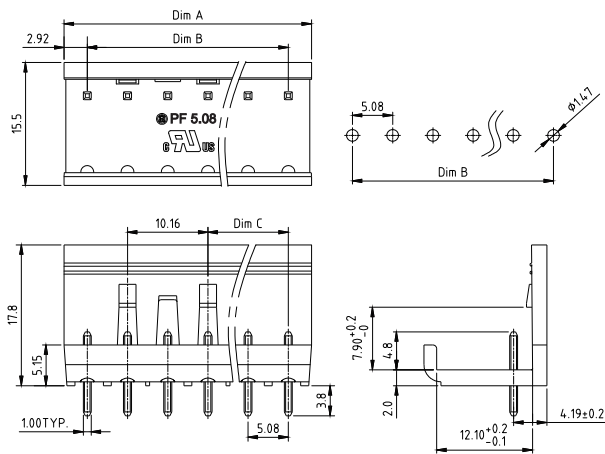

Operating Instructions

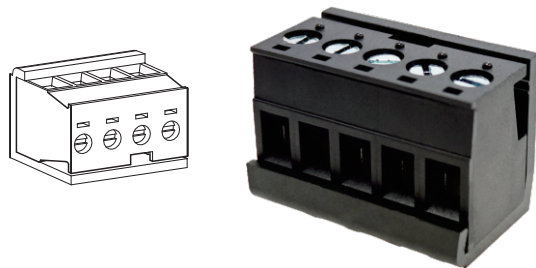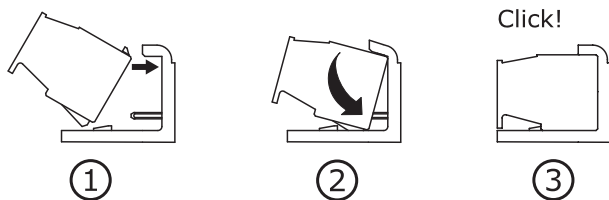


Installing Terminal Block

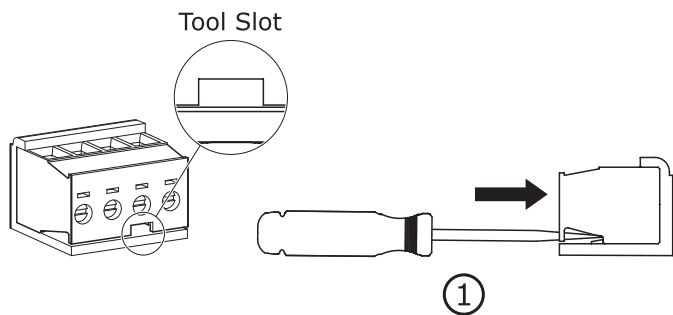


Removing Terminal Block

Product Applications

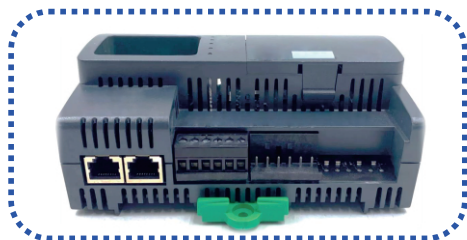

Building Automation and Control(BAC)

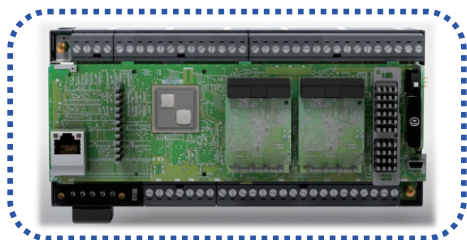

PLC Programmable Logic Controllers