

Warehouse
and Factory
Automation



Power
Distribution



Data
Center



Industrial Automation & Infrastructure

Cable management designed for the entire lifecycle
of automation environments

MADE FOR REAL 

Industrial Automation

Still using general-purpose cable mounts and fasteners on your advanced automation systems? **It's time to simplify and speed things up.**

HellermannTyton's industrial automation-specific cable and tube management products **instantly adapt to your installation strategy** – and they streamline maintenance, too.

Go beyond ties and sticky backs

We make them, we love them. But depending on the application, they're not always your most efficient choice. Or even the most cost effective. Check out the variety of solutions we've developed for faster installs – such as our **EZ Feed** technology – that perform better, too.

Replace less often


Technical materials and superior engineering – they're at the heart of HellermannTyton installation products. Downtime is costly – more costly than an optimized cable routing and mounting system.

Safer maintenance

A simple task like cutting off cable ties can result in nicking cables and adding hours to the work. Exclusive features like our patent-pending **CutZone** make maintenance faster and less risky.

Faster. Easier. Longer lasting.

One look through this industrial automation product guide is all you need. There's no better unified solution for your unique installations than cable management from HellermannTyton.

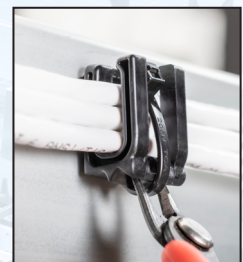

WAREHOUSE AND
FACTORY AUTOMATION



POWER DISTRIBUTION



DATA CENTER

Power Distribution



CABLE TIE MOUNTS



Cradle Mount (Adhesive)

Fast cable routing with peel & stick simplicity. Easy to insert and remove cables while staging. No cable tie needed to hold routings in place.

Part No.: 151-04727

Applications: Interior cabinet wire routing



Wire Rail

Replaces multiple adhesive mounts, providing one, clean line of attachment points. Allows adjustment of cable tie locations.

Part No.: 151-04574

Applications: Circuit breaker panel wiring, traditional sticky backs replacement, quick-mount HMI and/or push-button wiring




Anchor Mount

Built-in radius control navigates bends and door-to-cabinet transitions. Faster to deploy than multiple adhesive mounts.

Part No.: 151-04681

Applications: Door wiring

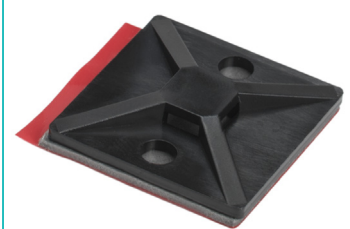

Adhesive Mount

Acrylic adhesive is stronger and longer lasting than common rubber-based adhesive. Four-way cable tie entry.

Part No.: 151-01632

Applications: Lack of pre-drilled holes

CABLE TIE MOUNTS



Saddle Mount

Accommodates heavy duty ties. Route single or dual bundles with separation option utilizing integrated saddles.

Part No.: 151-04487

Applications: Cable mounting / routing



Magnetic Mount

Route bundles by securing to steel surfaces without the need for a mounting hole. Reuse and reposition them for ultimate flexibility.

Part No.: 151-04020

Applications: Cable mounting / routing



Standard Cable Ties

Cable ties come in a variety of sizes to accommodate wire and cable bundles in a range of applications.

Part No.: T18R9M4, T50R9M4

Applications: Cable securing



Heavy Duty Cable Ties

Heavy duty cable ties are available in longer lengths, 8" - 52", for securing larger bundles.

Part No.: T120R0H4

Applications: Heavy duty cable securing



Cable Tie with Edge Clip

Bundle and route with this two-piece part. Edge clip easily pushes on to a panel edge without tools and holds tight.

Part No.: 156-02226, -02228

Applications: Wire harness mounting

CABLE TIES

Power Distribution



CLIPS AND CLAMPS



Locking Clamp with Edge Clip

High-performance clamp secures multi-diameter bundles and tubes. Edge clip easily pushes on to a panel edge without tools and holds tight.

Part No.: 151-03865

Applications: Wire harness mounting



MOC Clips to MOC Clips

Dual clip comes in a range of sizes for a perfect fit and fast installs. Delivers the best tube retention performance in the industry.

Part No.: 156-02355

Applications: Tube and power-rated cable separation



Safety Labels

Colored headers and safety icons get attention. You need only add your message in black print. Long lasting and chemical resistant.

Part No.: 558-00381, 596-00646

Applications: UV-rated warning labels

IDENTIFICATION




ShrinkTrak

Heat shrinkable wire markers designed for easy printing using a thermal transfer printer. Slit in side allows insertion of wire.

Part No.: 553-55022, -50019

Applications: Wire markers

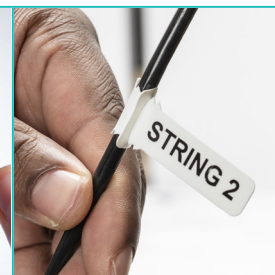


LoopTags

Printable plastic tags wrap around bundles and lock in place by threading tail through T-slot. No cable ties or adhesive needed.

Part No.: TAGPU12X74-LOOP

Applications: Wire markers

ROUTING AND PROTECTION

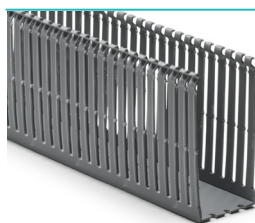

Wiring Duct

Smooth edges protect installers' hands. Easy finger break-offs simplify branch-outs.

Part No.: SLHD2X4, SL2X4

Applications: Organize / route cables in high-density environments



Wiring Duct Covers

Protective covers resist sliding under vibration.

Part Type: TC1, TC2, TC3, TC4

Applications: Organize / route cables in high-density environments



Heladuct

Highly flexible routing well suited for confined spaces. Overlapping fingers retain wire without separate cover and make insertion and removal easy.

Part No.: 164-31108

Applications: Organize / route cables in high-density environments



Helawrap

Flexible routing and protection. Installs with a "zipper-like" motion using included tool. Guards against abrasion and motion-related stress.

Part No.: 161-64507

Applications: Cable abrasion protection




Spiralwrap

Protective sheathing provides cable protection and flexible routing. Shields and organizes cables.

Part No.: 2FRP9M

Applications: Cable abrasion protection

SCAN CODE FOR
FULL PART LISTING

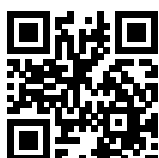

Warehouse and Factory Automation



CABLE TIE MOUNTS



Cable Stacker

Conveyor installers can easily separate power and signal, achieving ultra-organized cable runs from planning to completion.

Part No.: 151-04218

Applications: Cable routing and mounting



Sensor Mount

A proximity sensor mount that installs faster and can take the abuse of a constantly moving industrial environment.

Part No.: 151-04215

Applications: Sensor mounting



Cradle Mount (Frame)

Fast cable routing with twist-on simplicity. Easy to reposition. No cable tie needed to hold routings in place.

Part No.: 151-04482

Applications: T-slot frame mounting



WireRail

Replaces multiple adhesive mounts, providing one, clean line of attachment points. Allows adjustment of cable tie locations.

Part No.: 151-04657

Applications: Circuit breaker panel wiring, traditional sticky backs replacement



Anchor Mount

Built-in radius control navigates bends and door-to-cabinet transitions. Faster to deploy than multiple adhesive mounts.

Part No.: 151-04681

Applications: Door wiring

CABLE TIES



Standard Cable Ties

Cable ties come in a variety of sizes to accommodate wire and cable bundles in a range of applications.

Part No.: T18ROM4, T50ROM4

Applications: Cable securing



Grip Tie Strap

One-piece fastening device constructed of a hook and loop design featuring quick release for repetitive access. Available in pre-cut versions and rolls.

Part No.: GT.375X1800, GT.50X80C2

Applications: Soft cable management



Flat Ribbon Clamps

Secure flat ribbon cables without damage. Adjusts to different cable heights. Releasable when access is necessary. Arrowhead for easy mounting.

Part No.: 151-04767

Applications: Snap-in side-channel cable management



Ratchet Clamps

Exclusive, robust clamp design adjusts to multiple sized routings. One-piece, fully enclosed solution can be reopened for bundle servicing.

Part No.: 151-03548 (EMT)

Applications: Air pipe mounting, EMT mounting




Self-laminating Label

Contain a white printable surface followed by a clear tail that laminates the printed text when applied to a wire or cable.

Part No.: TAG3T3-100B

Applications: Marking cable or wire

ROUTING AND PROTECTION

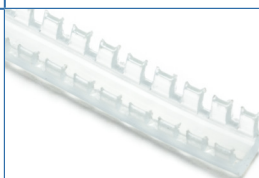

Grommet Edging

Flexible protection prevents abrasion to routings that must pass through sharp panel holes.

Part No.: FHC, FPD

Applications: Cable abrasion protection

SCAN CODE FOR FULL PART LISTING



Data Center

SCAN CODE FOR
FULL PART LISTING



CABLE TIE MOUNTS



WireRail

Replaces multiple adhesive mounts, providing one, clean line of attachment points. Allows adjustment of cable tie locations.

Part No.: 151-04574

Applications: Traditional sticky backs replacement



Adhesive Mount

Acrylic adhesive is stronger and longer lasting than common rubber-based adhesive mounts. Four-way cable tie entry.

Part No.: MB4A0A2H4

Applications: Lack of pre-drilled holes



Anchor Mount

Built-in radius control navigates bends and door-to-cabinet transitions. Faster to deploy than multiple adhesive mounts.

Part No.: 151-04563

Applications: Door wiring



Standard Cable Ties

Cable ties come in a variety of sizes to accommodate wire and cable bundles in a range of applications.

Part No.: T18R0M4, T50R0M4

Applications: Cable securing



Heavy Duty Cable Ties

Heavy duty cable ties are available in longer lengths, 8" - 52", for securing larger bundles.

Part No.: T120R0H4

Applications: Heavy duty cable securing



Grip Tie Strap

One-piece fastening device constructed of a hook and loop design featuring quick release for repetitive access. Available in multiple color choices.

Part No.: GT.375X1800, GT.50X80C2

Applications: Sensitive cable management

ROUTING AND PROTECTION




Wiring Duct and Covers

Smooth edges protect installers' hands. Easy finger break-offs simplify branch-outs. Protective covers won't slide.

Part No.: SLHD2X4, SL2X4, TC1, TC

Applications: Organize / route cables in high-density environments

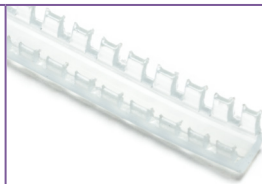

Grommet Edging

Flexible protection prevents abrasion to routings that must pass through sharp panel holes.

Part No.: FHC, FPD

Applications: Cable abrasion protection



FlagTags

Ideal for cable groups. Large print area manages lots of data and can be viewed more easily in cramped spaces.

Part No.: 596-97003

Applications: Server rack identification



BundleTags

Adhesive-backed, printable label that displays your cable bundle's tracking data. Wraps around cables to replace twist ties.

Part No.: 596-97007

Applications: High-density wire identification



CIJ4800 Printer

Create full-color, photo-quality labels and signs in a single pass. Pigment-based inks for maximum resistance to chemicals and solvents.

Part No.: CIJ4800

Applications: Interior signage labeling

HellermannTyton North American Corporate Headquarters

7930 N. Faulkner Rd, PO Box 245017

Milwaukee, WI 53224-9517

Phone: (414) 355-1130, (800) 537-1512

Fax: (414) 355-7341, (800) 848-9866

email: corp@htamericas.com

www.hellermann.tyton.com

IATF 16949, AS9100, ISO 9001 and ISO14001 certified

HellermannTyton Canada

Unit #4, 205 Industrial Parkway North

Aurora, Ontario L4G 4C4 Canada

Phone: (800) 661-2461

Fax: (800) 390-3904

email: sales@hellermannntyton.ca

HellermannTyton

HellermannTyton Mexico

Anillo Periferico Sur 7980 Edificio 6A

Parque Industrial Tecnologico II

Santa Maria Tequepexpan

Tlaquepaque, Jalisco, Mexico 45601

Phone: 011-52-33-3-133-9880

Fax: 011-52-33-3-133-9861

email: info-mx@hellermannntyton.com

ISO 9001 certified

Warranty Policy – HellermannTyton products are warranted to be free from defects in material and workmanship at the time sold by us; but our obligation under this warranty and that of the seller is limited to the replacement of the product, and neither we nor the seller are bound by any other warranty, expressed, implied or statutory. Under no circumstances are we or the seller liable for any loss, damage, expenses or consequential damages of any kind arising out of the use or inability to use these products. All are sold with the understanding that the user will test them in actual use and determine their adaptability for the intended uses.